

NTE[®]
ELECTRONICS, INC.

ECG[®]

WIRELESS

INSPECTION CAMERAS



**With Removable
Color LCD Monitor!**

WIC-100™
DELUXE EDITION

Includes 3.5" color LCD monitor,
9mm camera head and records to
removable 2GB SD card.

Applications:

- HVAC Inspection
- Automotive Inspection
- Cable Routing
- Electrical
- General Contracting
- Home Theater Installation
- Plumbing Inspection
- Much more!



ECG[®]

WIRELESS

INSPECTION CAMERAS

The ECG Wireless Inspection Cameras allow for easy visual inspections in hard-to-reach areas, even in total darkness with super bright LEDs! Lightweight, handheld design helps you easily find, diagnose, and solve problems.



WIC-1[™] : INSPECTION CAMERA

- 2.4" removable color LCD monitor
- Waterproof camera and shaft (IP67)
- Video out for recording
- Includes mirror, hook, and magnet tips
- Includes magnetic monitor base
- One year warranty
- FCC compliant



WIC-1[™] SPECIFICATIONS

CAMERA		MONITOR	
Imaging Sensor:	CMOS	Screen Type:	2.36" LCD
Total Pixels:	712 x 486	Effective Pixels:	480 x 240
Horizontal View Angle:	50°	Video System:	NTSC
Transmission Frequency:	2468 MHz	Transmission Frequency:	2468 MHz
Modulation Type:	FM	Exterior Supply Voltage:	8VDC
Bandwidth:	18 MHz	Consumption Current (Max.):	450 mA
Power Supply:	4 x AA Batteries	Video Output Level:	0.9 - 1.3V P-P @ 75 ohm
Weight (With Shaft):	1.17 lbs.	Dimensions (W x D x H) (inches):	3.94 x 2.76 x 1.18
Operating Temperature:	14°F ~ 122°F	Weight:	0.31 lbs.
Operating Humidity:	15 ~ 85% RH	Operating Temperature:	14°F ~ 122°F
Diameter (mm/inches)	15.9 / 0.63	Operating Humidity:	15 ~ 85% RH
		Power Supply:	Rechargeable Lithium-ion Battery



Removable Color LCD Monitor

ECG Wireless Inspection Cameras stand apart from the rest... literally... because they feature a removable color LCD monitor that displays crystal clear video images for accurate visual inspection. This unique wireless feature allows you to put the camera where you need it... and the monitor where you can see it... up to 30 ft. away - affording you a whole new level of convenience.



WIC-100™ : DELUXE INSPECTION CAMERA

- 3.5" removable color LCD monitor
- Waterproof camera and shaft (IP67)
- Records to removable 2GB SD card (included)
- Includes mirror, hook, and magnet tips
- One year warranty
- FCC compliant
- Includes magnetic monitor base
- Smaller 9mm camera head



WIC-100™ SPECIFICATIONS

CAMERA

Imaging Sensor:	CMOS
Total Pixels:	640 x 480
Horizontal View Angle:	45°
Transmission Frequency:	2468 MHz
Modulation Type:	FM
Bandwidth:	18 MHz
Power Supply:	4 x AA Batteries
Weight (With Shaft):	1.17 lbs.
Operating Temperature:	14°F ~ 122°F
Operating Humidity:	15 ~ 85% RH
Diameter (mm/inches)	9/0.35

MONITOR

Screen Type:	3.5" TFT-LCD
Effective Pixels:	320 (RGB) x 240
Video System:	PAL/NTSC
Transmission Frequency:	2468 MHz
Exterior Supply Voltage:	5 VDC
Consumption Current (Max.):	500 mA
Video Output Level:	0.9 - 1.3V P-P @ 75 ohm
Dimensions (W x D x H) (inches):	4 x 2.7 x 1
Weight:	0.31 lbs.
Operating Temperature:	14°F ~ 122°F
Operating Humidity:	15 ~ 85% RH
Power Supply:	Rechargeable Lithium-ion Battery



ECG[®]

WIRELESS

INSPECTION CAMERA ACCESSORIES

CHECK OUT OUR VIDEO ON


YouTube



Simply go to
www.YouTube.com/NTEElectronics



WIC-3
Magnetic Monitor
Mounting Base

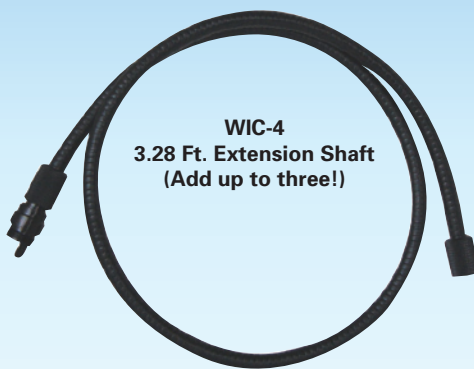

WIC-4
3.28 Ft. Extension Shaft
(Add up to three!)



WIC-7
15.9mm Camera/Shaft
(Waterproof)



WIC-10
9mm Camera
with 7.5mm Shaft
(Waterproof)

*For other accessories
and replacement parts, visit
www.WirelessInspectionCamera.com*

NTE[®]
ELECTRONICS, INC.

NTE Electronics, Inc.
44 Farrand Street
Bloomfield, NJ 07003
www.nteinc.com

Distributed by:



EL75-02 02/10

www.WirelessInspectionCamera.com