


26A1349A Product Details

[Live Product Chat](#)

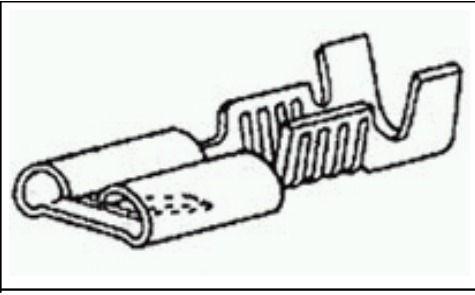

26A1349A

TE Part Number: 2 - 1393310 - 1

[Superseded](#)

[Add to Part List](#)

[Search for Replacement Parts](#)

Multiple Circuit Housings with Tabs & Receptacles Including FASTIN - FASTON

[Always ELV Compliant](#) ([Find RoHS Compliant Alternates](#) / [Statement of Compliance](#))

Product Highlights:

- ? Receptacle
- ? Tab Fit = 6.35 x 0.81 mm
- ? Wire Range = 1.25 - 3.00 ² [16 - 12] mm [AWG]
- ? Insulation Diameter = 4.06 - 5.33 [.160 - .210] mm [in]
- ? Receptacle Style = Straight

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

<p>Product Drawings:</p> <ul style="list-style-type: none"> ? None Available <p>Catalog Pages/Data Sheets:</p> <ul style="list-style-type: none"> ? None Available <p>Product Specifications:</p> <ul style="list-style-type: none"> ? None Available <p>Application Specifications:</p> <ul style="list-style-type: none"> ? None Available <p>Instruction Sheets:</p> <ul style="list-style-type: none"> ? None Available <p>CAD Files:</p> <ul style="list-style-type: none"> ? None Available 	<p>Additional Information:</p> <ul style="list-style-type: none"> ? Product Line Information <p>Related Products:</p> <ul style="list-style-type: none"> ? Tooling
---	--

Product Features (Please use the Product Drawing for all design activity)

<p>Product Type Features:</p> <ul style="list-style-type: none"> ? Product Type = Receptacle ? Tab Fit (mm [in]) = 6.35 x 0.81 [.250 x .032] ? Insulation Diameter (mm [in]) = 4.06 - 5.33 [.160 - .210] ? Receptacle Style = Straight ? Wire/Cable Type = Regular Wire ? Finish = None ? Material = Brass ? Insertion Force = Normal ? Insulation Support = With ? Crimp Type = F -Crimp ? FASTON = Yes ? For Housing Type = Single ? CSA Certified = Yes 	<p>Body Related Features:</p> <ul style="list-style-type: none"> ? Wire Range (mm [AWG]) = 1.25 - 3.00 ² [16 - 12] ? Stock Thickness (mm [in]) = 0.41 [0.016] ? UL Rating = Recognized <p>Industry Standards:</p> <ul style="list-style-type: none"> ? RoHS/ELV Compliance = ELV compliant ? Lead Free Solder Processes = Not reviewed for lead free solder process ? RoHS/ELV Compliance History = Always was ELV compliant <p>Packaging Related Features:</p> <ul style="list-style-type: none"> ? Packaging Method = Strip <p>Other:</p> <ul style="list-style-type: none"> ? Line = FASTIN -FASTON .250 ? Brand = Tyco Electronics
--	---