

Flat gasket - CES-B10-WRG-BK - 0801725

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Flat gasket made of NBR, size B10



The photo shows size B16



Key Commercial Data

Packing unit	1 pc
Minimum order quantity	10 pc
Weight per Piece (excluding packing)	2.0 g
Custom tariff number	40169300
Country of origin	Germany

Technical data

Ambient conditions

Ambient temperature (operation)	-20 °C ... 80 °C
---------------------------------	------------------

General

Material	NBR
Color	black
Installation instructions	For IP54 protection class. For mounting between sealing frame and snap frame/sealing frame and mounting panel.

Classifications

eCl@ss

eCl@ss 4.0	27081002
eCl@ss 4.1	27081002
eCl@ss 5.0	27081002
eCl@ss 5.1	27081002

Flat gasket - CES-B10-WRG-BK - 0801725

Classifications

eCl@ss

eCl@ss 6.0	27081002
eCl@ss 7.0	27081002
eCl@ss 8.0	27439218
eCl@ss 9.0	27430319

ETIM

ETIM 3.0	EC002317
ETIM 4.0	EC002498
ETIM 5.0	EC001181

UNSPSC

UNSPSC 6.01	30212109
UNSPSC 7.0901	39121708
UNSPSC 11	39121708
UNSPSC 12.01	39121708
UNSPSC 13.2	39121708

Approvals

Approvals

Approvals

GL

Ex Approvals

Approvals submitted


Approval details

GL

Drawings

Flat gasket - CES-B10-WRG-BK - 0801725

Dimensional drawing

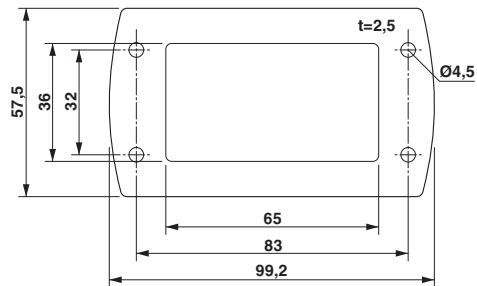

Dimensional drawing