

## Flat gasket - CES-B24-WRG-BK - 0801727


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Flat gasket made of NBR, size B24



### Key Commercial Data

|                                      |   |
|--------------------------------------|---|
| Packing unit                         | 1 pc  |
| Minimum order quantity               | 10 pc   |
| GTIN                                 | <br>4 046356 675260 |
| GTIN                                 | 4046356675260   |
| Weight per Piece (excluding packing) | 4.000 g   |
| Custom tariff number                 | 40169300  |
| Country of origin                    | Germany   |

### Technical data

#### Dimensions

|        |         |
|--------|---------|
| Length | 147 mm  |
| Width  | 57.5 mm |
| Height | 2.5 mm  |

#### Ambient conditions

|                                 |                           |
|---------------------------------|---------------------------|
| Ambient temperature (operation) | -20 °C ... 80 °C (static) |
|---------------------------------|---------------------------|

#### General

|          |       |
|----------|-------|
| Material | NBR   |
| Color    | black |

### Environmental Product Compliance

# Flat gasket - CES-B24-WRG-BK - 0801727


## Technical data

### Environmental Product Compliance

|            |   |
|------------|---|
| China RoHS | Environmentally friendly use period: unlimited = EFUP-e |
|            | No hazardous substances above threshold values          |

## Drawings

Dimensional drawing

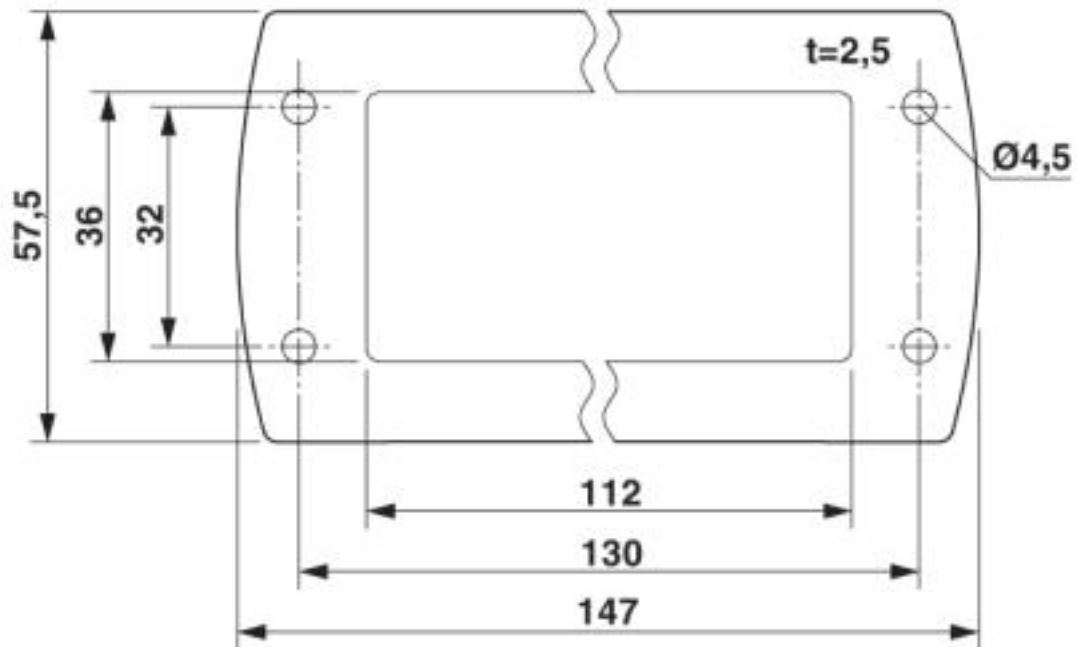

Dimensional drawing

## Classifications

eCl@ss

|               |          |
|---------------|----------|
| eCl@ss 10.0.1 | 23071590 |
| eCl@ss 4.0    | 27081000 |
| eCl@ss 4.1    | 27081000 |
| eCl@ss 5.0    | 27081000 |
| eCl@ss 5.1    | 27081000 |
| eCl@ss 6.0    | 23071500 |
| eCl@ss 7.0    | 23071590 |
| eCl@ss 8.0    | 23071590 |
| eCl@ss 9.0    | 23071590 |

# Flat gasket - CES-B24-WRG-BK - 0801727

## Classifications

### ETIM

|          |          |
|----------|----------|
| ETIM 3.0 | EC002317 |
| ETIM 4.0 | EC002498 |
| ETIM 5.0 | EC001181 |
| ETIM 6.0 | EC001181 |
| ETIM 7.0 | EC001181 |

### UNSPSC

|               |          |
|---------------|----------|
| UNSPSC 6.01   | 30212109 |
| UNSPSC 7.0901 | 39121708 |
| UNSPSC 11     | 39121708 |
| UNSPSC 12.01  | 39121708 |
| UNSPSC 13.2   | 39131608 |
| UNSPSC 18.0   | 31401601 |
| UNSPSC 19.0   | 31401601 |
| UNSPSC 20.0   | 31401601 |
| UNSPSC 21.0   | 31401601 |

## Approvals

### Approvals

---

Approvals

GL

---

Ex Approvals

---

### Approval details

|    |   |   |            |
|----|---|---|------------|
| GL |  | <a href="https://approvalfinder.dnvgi.com/">https://approvalfinder.dnvgi.com/</a> | 1391415 HH |
|----|---|---|------------|

---