

Female connector - V-RC/TGUM 11/KVD 11/LBL 12 - 1000041

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



M23 socket, 12-pos., straight, freely configurable, with solder connection, for external cable diameter of 8 mm ... 12 mm



Key Commercial Data

Packing unit	1 pc
Weight per Piece (excluding packing)	100.3 g
Custom tariff number	85366990
Country of origin	Germany

Technical data

General

Rated voltage	150 V
Total rated current	8 A (with 1 mm ² conductor cross section)
Number of positions	12
Flammability rating according to UL 94	V0
Note	The connector is designed for use on sensor/actuator boxes with an M23 plug-in connection.

Ambient conditions

Degree of protection	IP65
	IP67
Ambient temperature (operation)	-20 °C ... 80 °C

Master cable data/connection data

Connection method	M23 screw locking
Conductor cross section max. (signal)	1 mm ²
Conductor cross section max. (energy)	1 mm ²
External cable diameter min.	8 mm

Female connector - V-RC/TGUM 11/KVD 11/LBL 12 - 1000041

Technical data

Master cable data/connection data

External cable diameter max.	12 mm
------------------------------	-------

Insulation material

Housing material	GD-Zn
Housing surface material	Nickel-plated
Contact material	CuZn
Contact surface material	Gold-plated
Contact carrier material	PBT

Connection assignment

Slot/position = pin = conductor color	1 / 4 (A) = 1 = WH
	2 / 4 (A) = 2 = GN
	3 / 4 (A) = 3 = YE
	4 / 4 (A) = 4 = GY
	5 / 4 (A) = 5 = PK
	6 / 4 (A) = 6 = RD
	7 / 4 (A) = 7 = BK
	8 / 4 (A) = 8 = VT
	1-8 / 1 (+ 120 V) = 11 = BN
	1-8 / 3 (0 V) = 9+10 = BU
	1-8 / 5 (PE) = 12 = GN/YE

Standards and Regulations

Flammability rating according to UL 94	V0
--	----

Classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27061801
eCl@ss 7.0	27061801
eCl@ss 8.0	27440102

ETIM

ETIM 2.0	EC000437
ETIM 3.0	EC001121

Female connector - V-RC/TGUM 11/KVD 11/LBL 12 - 1000041

Classifications

ETIM

ETIM 4.0	EC001121
ETIM 5.0	EC002635

UNSPSC

UNSPSC 6.01	31261502
UNSPSC 7.0901	31261502
UNSPSC 11	31261502
UNSPSC 12.01	31261502
UNSPSC 13.2	31261502

Approvals

Approvals

Approvals

EAC

Ex Approvals


Approvals submitted

Approval details

EAC

Drawings

Schematic diagram

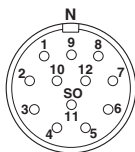

Pin assignment M23 socket, 12-pos., female side view

Dimensional drawing

