

## Crimping pliers - CRIMPFOX 6 - 1212034


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Crimping pliers, for ferrules without insulating collar according to DIN 46228 Part 1 and ferrules with insulating collar according to DIN 46228 Part 4, 0.25 mm<sup>2</sup> ... 6.0 mm<sup>2</sup>, lateral entry, trapezoidal crimp

### Product Features

- Comprehensive range of crimping pliers
- All ferrules can be optimally crimped with a minimum amount of effort even in the case of large conductor cross sections
- Consistently high crimping quality
- Marked die stations for precise processing of corresponding cross sections
- Unlockable pressure lock

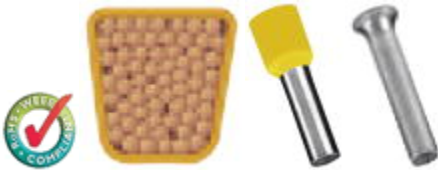

### Key Commercial Data

Packing unit	1 pc
Weight per Piece (excluding packing)	450.0 g
Custom tariff number	82032000
Country of origin	Sweden

### Technical data

#### Dimensions

Length (b)	198 mm
Width (a)	18 mm
Height	59 mm

#### General

Color	black
Compression	Trapezoidal crimp
Type of contact	Insulated and uninsulated ferrules

## Crimping pliers - CRIMPFOX 6 - 1212034

### Technical data

#### General

Designation	Crimping position 1
Min. cross section	0.25 mm <sup>2</sup>
Max. cross section	0.75 mm <sup>2</sup>
AWG min	24
AWG max	20
Designation	Crimping position 2
Min. cross section	1 mm <sup>2</sup>
Max. cross section	1.5 mm <sup>2</sup>
AWG min	18
AWG max	16
Designation	Crimping position 3
Max. cross section	2.5 mm <sup>2</sup>
AWG max	14
Die station	Crimping position 4
Max. cross section	4 mm <sup>2</sup>
AWG max	12
Die station	Crimping position 5
Max. cross section	6 mm <sup>2</sup>
AWG max	10

### Classifications

#### eCl@ss

eCl@ss 4.0	21040301
eCl@ss 4.1	21040301
eCl@ss 5.0	21040301
eCl@ss 5.1	21040301
eCl@ss 6.0	21043811
eCl@ss 7.0	21043811
eCl@ss 8.0	21049090

#### ETIM

ETIM 2.0	EC001186
ETIM 3.0	EC001186
ETIM 4.0	EC001186
ETIM 5.0	EC000168

# Crimping pliers - CRIMPFOX 6 - 1212034

## Classifications

### UNSPSC

UNSPSC 6.01	27112118
UNSPSC 7.0901	27111518
UNSPSC 11	23171604
UNSPSC 12.01	27111518
UNSPSC 13.2	27111518

## Approvals

### Approvals

---

### Approvals

EAC

---

### Ex Approvals

---

### Approvals submitted

---

## Approval details

EAC
-----

## Drawings

Product drawing

