

## Network cable - VS-IP67-IP20-93E-LI/3,7 - 1403655

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Assembled Ethernet cable, CAT5e, shielded, 2-pair, 26 AWG stranded (7-wire), RAL 5021 (water blue), RJ45 plug/IP67, gray to RJ45 plug/IP20, line, length: 3.7 m



### Key Commercial Data

Packing unit	1 pc
Minimum order quantity	50 pc
Weight per Piece (excluding packing)	200.0 g
Custom tariff number	85444210
Country of origin	Poland

### Classifications

#### eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27060307
eCl@ss 6.0	27061801
eCl@ss 7.0	27061801
eCl@ss 8.0	27060308

#### ETIM

ETIM 3.0	EC001262
ETIM 4.0	EC001262
ETIM 5.0	EC002599

#### UNSPSC

UNSPSC 6.01	26121616
UNSPSC 7.0901	26121616

# Network cable - VS-IP67-IP20-93E-LI/3,7 - 1403655

## Classifications

### UNSPSC


UNSPSC 11	26121604
UNSPSC 12.01	31261501
UNSPSC 13.2	26121616

## Drawings

Cable cross section




Circuit diagram

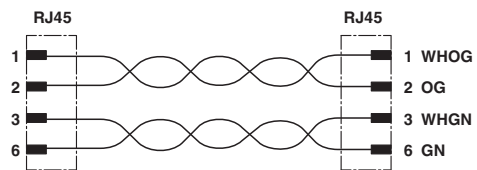

PUR ETHERNET 2x2 FLEX [93E]

Dimensional drawing

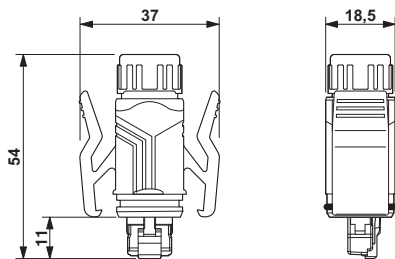

Dimensional drawing

