

Cable gland - HC-B-G-M20-PLRBK - 1407669

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



EVO plastic cable gland with bayonet locking, for housing series B, size M20, cable diameter: 7 ... 13 mm

Product Description

Plastic cable gland



Key Commercial Data

Packing unit	1 pc
Weight per Piece (excluding packing)	35.0 g
Custom tariff number	39269097
Country of origin	Poland

Technical data

Dimensions

Wrench size, union nut	22 mm
External cable diameter	7 mm ... 13 mm

Ambient conditions

Degree of protection	IP66 (DIN IEC 60529)
	4 (UL50e / NEMA 250)
	4X (UL50e / NEMA 250)
	12 (UL50e / NEMA 250)
Ambient temperature (operation)	-40 °C ... 100 °C

General

Type of the screw connection	M20
No. of conductors	1
Material	PA
Cable gland material	Polyamide

Cable gland - HC-B-G-M20-PLRBK - 1407669

Technical data

General

Material, pressure screw	PBT
Seal material	NBR
Cable seal material	NBR
Shielded	No
Thread type on connection side	Bayonet B plastic
Tightening torque, union nut	5.00 Nm
Flammability rating according to UL 94	V0 / V2

Standards and Regulations

Flammability rating according to UL 94	V0 / V2
--	---------

Classifications

eCl@ss

eCl@ss 4.0	27141209
eCl@ss 4.1	27141209
eCl@ss 5.0	27149109
eCl@ss 5.1	27143424
eCl@ss 6.0	27149109
eCl@ss 7.0	27149109
eCl@ss 8.0	27149109

ETIM

ETIM 3.0	EC000441
ETIM 4.0	EC000441
ETIM 5.0	EC000441

UNSPSC

UNSPSC 6.01	31261502
UNSPSC 7.0901	31261502
UNSPSC 11	31261502
UNSPSC 12.01	31261502
UNSPSC 13.2	31261502

Approvals

Approvals

Cable gland - HC-B-G-M20-PLRBK - 1407669

Approvals

Approvals

EAC

Ex Approvals


Approvals submitted

Approval details

EAC

Drawings

Dimensional drawing

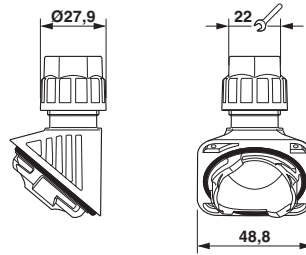

Dimensional drawing
