

Contact insert module - HC-M-00 - 1414353

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON dummy module, for unused slots in the module carrier frame



Key Commercial Data

| | |
|--------------------------------------|---|
| Packing unit | 1 STK |
| Minimum order quantity | 5 STK |
| GTIN |  4 055626 024660 |
| GTIN | 4055626024660 |
| Weight per Piece (excluding packing) | 4.000 g |
| Custom tariff number | 85389099 |
| Country of origin | Poland |

Technical data

Dimensions

| | |
|--------|---------|
| Height | 16.8 mm |
| Width | 34.2 mm |
| Length | 14.6 mm |

Ambient conditions

| | |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -40 °C ... 125 °C |
|---------------------------------|-------------------|

General

| | |
|------------------------|------------|
| Series | HC-M-00 |
| Color | light gray |
| Number of module slots | 1 |

Contact insert module - HC-M-00 - 1414353

Technical data

General


| | |
|--|----|
| Flammability rating according to UL 94 | V0 |
|--|----|

Standards and Regulations

| | |
|--|----|
| Flammability rating according to UL 94 | V0 |
|--|----|

Drawings

Dimensional drawing

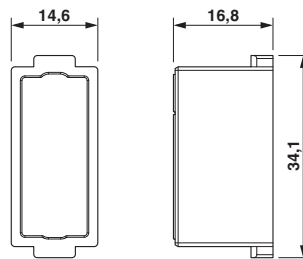

HC-M-00

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

| | | |
|-----|--|---------------------|
| EAC | | 7500651.22.01.00246 |
|-----|--|---------------------|