


Nut - A-INL-PG9-P-LG - 1424549

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Nut, PA 6 GF 30, Connecting thread: Pg9, Color: lightgrey RAL 7035



Key Commercial Data

Packing unit	1
GTIN	 4 055626 374536
GTIN	4055626374536
Custom tariff number	73181639

Technical data

Dimensions

Length	5 mm
Connecting thread diameter	15.2 mm
Wrench size, counter nut	22 mm
Hexagon angular dimension	24 mm

Ambient conditions

Ambient temperature (operation)	-20 °C ... 100 °C
---------------------------------	-------------------

General

Material	PA 6 GF 30
Thread type on connection side	Pg9
Flammability rating according to UL 94	V2
Color	lightgrey RAL 7035

Standards and Regulations

Nut - A-INL-PG9-P-LG - 1424549


Technical data

Standards and Regulations

Flammability rating according to UL 94	V2
--	----

Drawings

Dimensional drawing

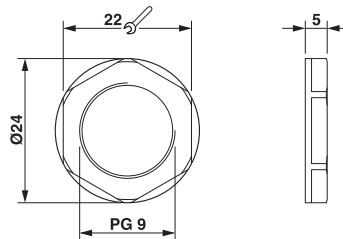

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		EAC-Zulassung
-----	--	---------------