

Nut - A-INL-PG11-P-BK - 1424560


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Nut, PA 6 GF 30, Connecting thread: Pg11, Color: jet black RAL 9005



RoHS

Key Commercial Data

Packing unit	1
GTIN	 4 055626 374642
GTIN	4055626374642
Custom tariff number	39269097

Technical data

Dimensions

Length	5 mm
Connecting thread diameter	18.6 mm
Wrench size, counter nut	24 mm
Hexagon angular dimension	26 mm

Ambient conditions

Ambient temperature (operation)	-20 °C ... 100 °C
---------------------------------	-------------------

General

Material	PA 6 GF 30
Thread type on connection side	Pg11
Flammability rating according to UL 94	V2
Color	jet black RAL 9005

Standards and Regulations

Nut - A-INL-PG11-P-BK - 1424560


Technical data

Standards and Regulations

Flammability rating according to UL 94	V2
--	----

Drawings

Dimensional drawing

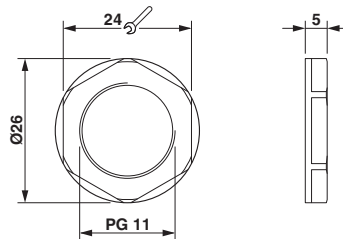

Classifications

eCl@ss

eCl@ss 5.1	27149109
eCl@ss 6.0	27149109
eCl@ss 8.0	27069219
eCl@ss 9.0	27144424

ETIM

ETIM 5.0	EC000129
----------	----------

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

Nut - A-INL-PG11-P-BK - 1424560

Approvals

EAC



EAC-Zulassung