

Sealing cap - PROT-MINFS-PA-CHAIN - 1430912

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

7/8" sealing cap made of plastic with fixing band, for sensor cables, for 7/8" connectors



Key Commercial Data

| | |
|--------------------------------------|----------|
| Packing unit | 1 pc |
| Minimum order quantity | 10 pc |
| Weight per Piece (excluding packing) | 9.38 g |
| Custom tariff number | 39269097 |
| Country of origin | Germany |

Technical data

Ambient conditions

| | |
|---------------------------------|------------------|
| Ambient temperature (operation) | -25 °C ... 85 °C |
| Degree of protection | IP65 |
| | IP67 |

Material

| | |
|--|--------------------|
| Flammability rating according to UL 94 | V0 |
| Material | PA 66 GF |
| Sealing material | NBR |
| Additional material specifications | PUR (Holding band) |

Standards and Regulations

| | |
|--|----|
| Flammability rating according to UL 94 | V0 |
|--|----|

Sealing cap - PROT-MINFS-PA-CHAIN - 1430912

Classifications

eCl@ss

| | |
|------------|----------|
| eCl@ss 4.0 | 272607xx |
| eCl@ss 4.1 | 27260701 |
| eCl@ss 5.0 | 27149110 |
| eCl@ss 5.1 | 27149110 |
| eCl@ss 6.0 | 27149112 |
| eCl@ss 7.0 | 27149112 |
| eCl@ss 8.0 | 27379218 |

ETIM

| | |
|----------|----------|
| ETIM 3.0 | EC002040 |
| ETIM 4.0 | EC002040 |
| ETIM 5.0 | EC002040 |

UNSPSC

| | |
|---------------|----------|
| UNSPSC 6.01 | 31251501 |
| UNSPSC 7.0901 | 31251501 |
| UNSPSC 11 | 31251501 |
| UNSPSC 12.01 | 31251501 |
| UNSPSC 13.2 | 31251501 |

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approvals submitted


Approval details

| |
|-----|
| EAC |
|-----|

Drawings

Sealing cap - PROT-MINFS-PA-CHAIN - 1430912

Dimensional drawing

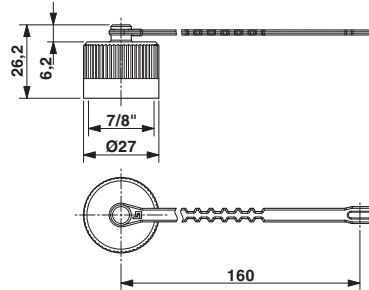

Dimensional drawing