

Filler plugs - HC-M-BS-M20 - 1645846

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Filler plug, metal, size: M20



Key Commercial Data

Packing unit	1 pc
Minimum order quantity	10 pc
Weight per Piece (excluding packing)	12.42 g
Custom tariff number	74153300
Country of origin	Germany

Technical data

Dimensions

Length	9 mm
Length without connecting thread	3 mm
Connecting thread diameter	20 mm
Wrench size, union nut	22 mm
Hexagon angular dimension GRP	24 mm
Length of the connecting thread	6 mm

Ambient conditions

Degree of protection	IP68
	IP68
Ambient temperature (operation)	-20 °C ... 80 °C

General

Material	Nickel-plated brass
Cable gland material	Nickel-plated brass
O-ring material	NBR

Filler plugs - HC-M-BS-M20 - 1645846

Technical data

General

Thread type on connection side	M20
Torque	5 Nm
Color	silver
	silver

Classifications

eCl@ss

eCl@ss 4.0	27141209
eCl@ss 4.1	27141209
eCl@ss 5.0	27149109
eCl@ss 5.1	27149109
eCl@ss 6.0	27149109
eCl@ss 7.0	27149109
eCl@ss 8.0	23111190

ETIM

ETIM 2.0	EC000441
ETIM 3.0	EC000441
ETIM 4.0	EC000032
ETIM 5.0	EC000723

UNSPSC

UNSPSC 6.01	30211808
UNSPSC 7.0901	39121408
UNSPSC 11	39121408
UNSPSC 12.01	39121408
UNSPSC 13.2	39121408

Approvals

Approvals

Approvals

EAC

Ex Approvals

Filler plugs - HC-M-BS-M20 - 1645846

Approvals


Approvals submitted

Approval details

EAC

Drawings

Dimensional drawing

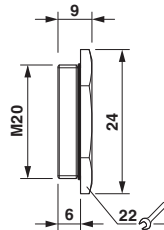

Filler plugs M20
