


Screw plug - HC-M-BS-M32 - 1645862

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Filler plug, metal, size: M32



Key Commercial Data

Packing unit	1 STK
Minimum order quantity	10 STK
GTIN	 4 017918 951115
GTIN	4017918951115
Weight per Piece (excluding packing)	24.070 g
Custom tariff number	74153300
Country of origin	Germany

Technical data

Dimensions

Length	10.5 mm
Length without connecting thread	3.5 mm
Connecting thread diameter	32 mm
Wrench size, union nut	35 mm
Hexagon angular dimension	39 mm
Length of the connecting thread	7 mm

Ambient conditions

Degree of protection	IP68
Ambient temperature (operation)	-20 °C ... 80 °C

Screw plug - HC-M-BS-M32 - 1645862

Technical data

General

Material	Brass, nickel-plated
Cable gland material	Nickel-plated brass
O-ring material	NBR
Thread type connection side	M32 x 1.5
Torque	10 Nm
Color	silver

Standards and Regulations


Halogen-free	no
--------------	----

Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Drawings

Dimensional drawing

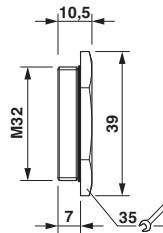

Dimensional drawing

Classifications

eCl@ss

eCl@ss 4.0	27141209
eCl@ss 4.1	27141209
eCl@ss 5.0	27149109
eCl@ss 5.1	27149109
eCl@ss 6.0	27149109
eCl@ss 7.0	27149109
eCl@ss 8.0	27149110
eCl@ss 9.0	27144433

Screw plug - HC-M-BS-M32 - 1645862

Classifications

ETIM

ETIM 2.0	EC000441
ETIM 3.0	EC000441
ETIM 4.0	EC000032
ETIM 5.0	EC000723
ETIM 6.0	EC000032

UNSPSC

UNSPSC 6.01	30211808
UNSPSC 7.0901	39121408
UNSPSC 11	39121408
UNSPSC 12.01	39121408
UNSPSC 13.2	31161501

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		RU C- DE.AI30.B.01102
-----	---	--------------------------