

RJ45 sleeve housings - VS-08-T-G-RJ45/IP20 - 1652295

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



RJ45 sleeve housing, IP20, for pin insert VS-08-ST-RJ45, with push-pull interlocking for panel mounting frames, inverted design, for Factoryline modular managed switches, for cable cross section 5.0 mm ... 6.5 mm



Ethernet

Key Commercial Data

Packing unit	1 pc
Minimum order quantity	5 pc
Weight per Piece (excluding packing)	6.1 g
Custom tariff number	85472000
Country of origin	Germany

Technical data

Mechanical characteristics

Insertion/withdrawal cycles	≥ 750
External cable diameter	5 mm ... 6.5 mm
Cable exit	straight
Color	gray

Ambient conditions

Ambient temperature (operation)	-40 °C ... 80 °C
Degree of protection	IP20

Material data

Flammability rating according to UL 94	V0
Housing material	PA

Standards and Regulations

Flammability rating according to UL 94	V0
--	----

RJ45 sleeve housings - VS-08-T-G-RJ45/IP20 - 1652295

Classifications

eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27260705
eCl@ss 7.0	27440309
eCl@ss 8.0	27440202
eCl@ss 9.0	27440202

ETIM


ETIM 2.0	EC000764
ETIM 3.0	EC001121
ETIM 4.0	EC001121
ETIM 5.0	EC000437

UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

Drawings

Dimensional drawing

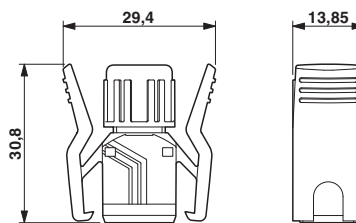

RJ45 sleeve housing, IP20, turned