

FO connecting cable - VS-PC-2X-POF-980-SCRJ/FSMA-1 - 1657106

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Assembled FO cable, break-out cable, polymer fiber 980/1000 µm, SC-RJ/IP20 on FSMA/IP20, for installation inside the control cabinets, the conductor is suitable for the UV-protected outside insert, length: 1 m



Key Commercial Data

Packing unit	1 pc
Weight per Piece (excluding packing)	45.7 g
Custom tariff number	85447000
Country of origin	Germany

Technical data

Mechanical characteristics

Number of positions	2
Connection profile	SCRJ according to DIN EN 50377-6-1
Fiber	980/1000 µm
Number of fibers	2.00
Insertion/withdrawal cycles	≥ 1000
Type of cable	Break-out cable
Length of cable	1 m

Ambient conditions

Ambient temperature (operation)	-30 °C ... 70 °C
	-20 °C ... 60 °C
	-20 °C ... 70 °C
Degree of protection	IP20

Material data

Housing material	PBT/nickel silver
Outer sheath, material	PE

FO connecting cable - VS-PC-2X-POF-980-SCRJ/FSMA-1 - 1657106

Technical data

Material data

External sheath, color	black
Ferrule holder color	blue

Classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27061001
eCl@ss 5.0	27260701
eCl@ss 5.1	27061803
eCl@ss 6.0	27061803
eCl@ss 7.0	27061803
eCl@ss 8.0	27061003

ETIM

ETIM 3.0	EC000034
ETIM 4.0	EC001476
ETIM 5.0	EC001263

UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approvals submitted

FO connecting cable - VS-PC-2X-POF-980-SCRJ/FSMA-1 - 1657106

Approvals

Approval details

 
EAC

Drawings

Dimensional drawing


Schematic diagram

FSMA plugs



Pin assignment plug SCRJ

Dimensional drawing

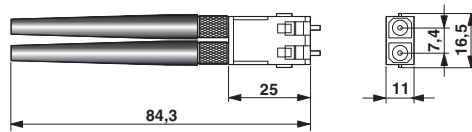

SC-RJ connector IP20