

## Connector assembly frame - HC-SMP 125-B16-AMQ - 1660973

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




HEAVYCON connector assembly frame with panel mounting base with double locking latch, for contact inserts of type B16

The illustration shows version HC-SMP 125-B 10 with double locking latch



### Key Commercial Data

Packing unit	1 pc
GTIN	 4 017918 022389
Weight per Piece (excluding packing)	216.63 g
Custom tariff number	85389099
Country of origin	Germany

### Technical data

#### Dimensions

Length	125 mm
Height	52 mm
Hole diameter	4.5 mm
Drill hole distance, horizontal	104 mm
Drill hole distance, vertical	32 mm

#### General

Note	For contact inserts B16, BB32, DD72, HS6 and HV6
Material	PA
Flammability rating according to UL 94	HB
Type	B16

# Connector assembly frame - HC-SMP 125-B16-AMQ - 1660973

## Technical data

### Standards and Regulations

Flammability rating according to UL 94	HB
--	----

## Classifications

### eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440206
eCl@ss 9.0	27440206

### ETIM

ETIM 3.0	EC002310
ETIM 4.0	EC002310
ETIM 5.0	EC002312

### UNSPSC

UNSPSC 6.01	43172601
UNSPSC 7.0901	39121416
UNSPSC 11	43172601
UNSPSC 12.01	39121408
UNSPSC 13.2	39121408

## Approvals

### Approvals

---

Approvals

EAC

---

Ex Approvals

---

Approvals submitted


# Connector assembly frame - HC-SMP 125-B16-AMQ - 1660973

## Approvals

Approval details


EAC
-----

## Drawings

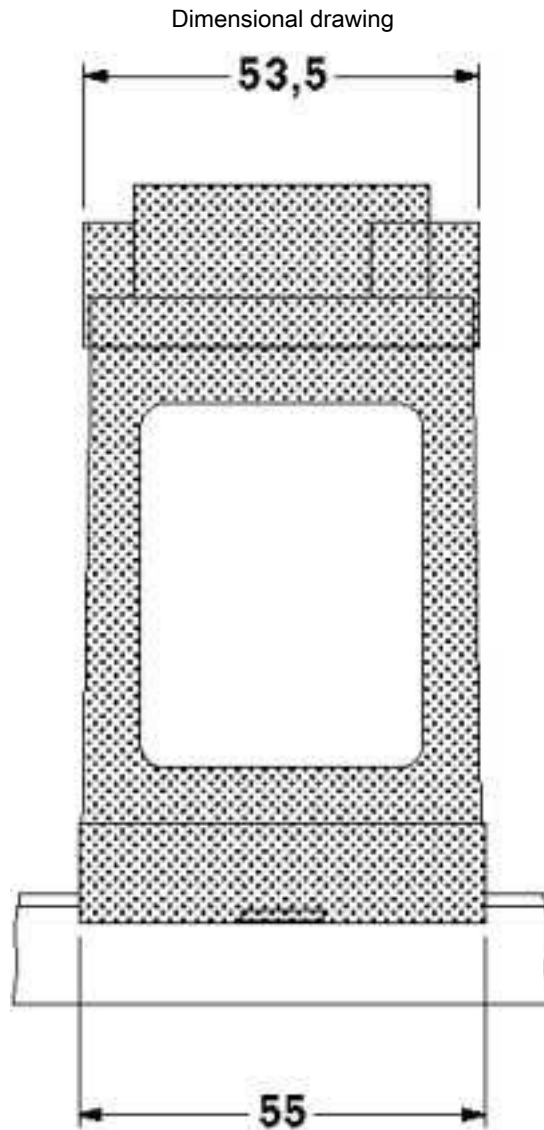

# Connector assembly frame - HC-SMP 125-B16-AMQ - 1660973

Dimensional drawing

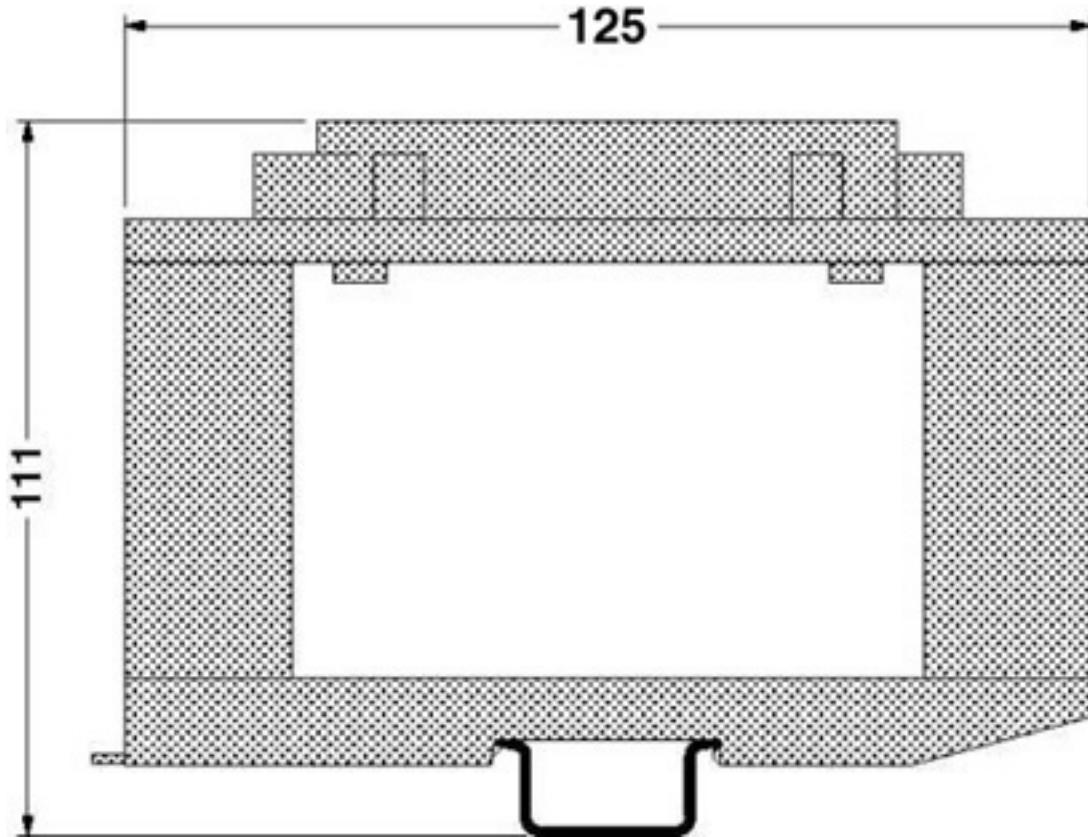

## Connector assembly frame - HC-SMP 125-B16-AMQ - 1660973

