

## Profile - UM-ALU 4-100,5 PROFILE 130 - 2200938

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Press-drawn section housings, Basic profile, Profile width (internal): 100.5 mm, length: 130 mm



### Your advantages

- ✔ Item is from the UM-ALU product range
- ✔ Aluminum press-drawn section
- ✔ Available in lengths from 42.5 mm ... 990 mm, can be cut to any length
- ✔ Available in overall widths of 75 mm and 105 mm
- ✔ Variety of connection technologies
- ✔ Can be mounted on the DIN rail
- ✔ EMC protection

### Key Commercial Data

Packing unit	1 pc
GTIN	
GTIN	4046356716451
Weight per Piece (excluding packing)	160.000 g
Custom tariff number	76042990
Country of origin	Germany

### Technical data

#### Product properties

Brief article description	Profile
Type	UM-ALU 4-100,5 PROFILE 130
Order No.	2200938

## Profile - UM-ALU 4-100,5 PROFILE 130 - 2200938

### Technical data

#### Product properties

Housing type	Press-drawn section housings
Type	Basic profile
Mounting type	Screw mounting

#### Dimensions

Length	130 mm
Profile width (external)	105 mm
Profile width (internal)	100.5 mm
Depth	29.4 mm
Depth from top edge of DIN rail	25.5 mm

#### Material specifications

Material	Aluminum
Color	aluminum color
Surface characteristics	anodized

#### Ambient conditions

Ambient temperature (operation)	-40 °C ... 105 °C
---------------------------------	-------------------

#### PCB specifications

PCB holders	2
PCB thickness	1.4 mm ... 2 mm
PCB surface	12116 mm <sup>2</sup> ... 13025 mm <sup>2</sup>
Mounting position	parallel to the DIN rail
Type of PCB mount	Slot

#### General information

Type of note	Assembly instruction:
Note	Refer to the data sheet for the range in the download area.

#### Packaging specifications

Type of packaging	packed in cardboard
Pieces per package	1
Denomination packing units	Pcs.
Outer packaging type	Carton


#### Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

### Drawings

## Profile - UM-ALU 4-100,5 PROFILE 130 - 2200938

Dimensional drawing

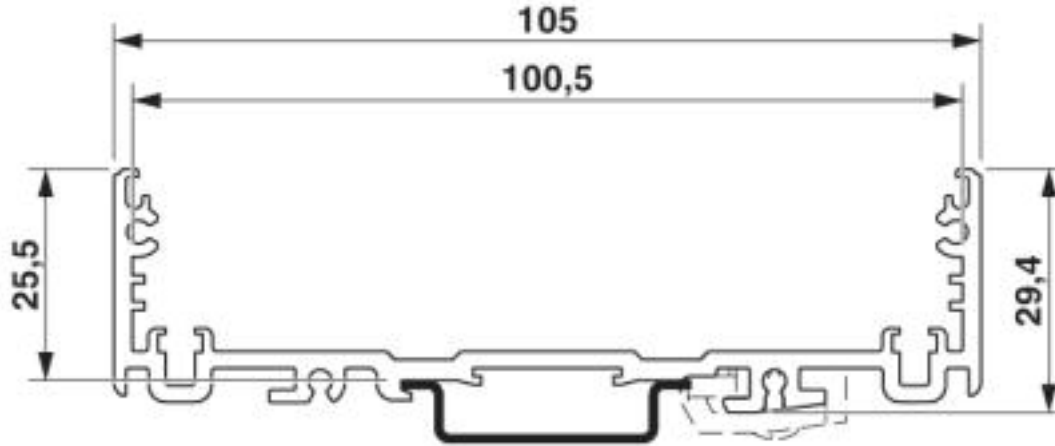

### Classifications

#### eCl@ss

eCl@ss 10.0.1	27182701
eCl@ss 4.0	27180400
eCl@ss 4.1	27180400
eCl@ss 5.0	27180500
eCl@ss 5.1	27180500
eCl@ss 6.0	27182000
eCl@ss 7.0	27182701
eCl@ss 8.0	27182701
eCl@ss 9.0	27182701

#### ETIM

ETIM 3.0	EC001031
ETIM 4.0	EC000721
ETIM 5.0	EC002779
ETIM 6.0	EC002779
ETIM 7.0	EC002779

#### UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

## Profile - UM-ALU 4-100,5 PROFILE 130 - 2200938

### Classifications

#### UNSPSC

UNSPSC 18.0	31261501
UNSPSC 19.0	31261501
UNSPSC 20.0	31261501
UNSPSC 21.0	31261501

### Accessories

#### Necessary add-on products

Side element - UM-ALU 4-100,5 COVER AL - 2200951



Press-drawn section housings, Side elements (left and right), incl. snap-on foot, width: 105.4 mm, height: 2 mm

Side element - UM-ALU 4-100,5 COVERLID 45 AL - 2201759



Press-drawn section housings, Side elements (left and right), incl. snap-on foot, width: 105.4 mm, height: 2 mm

Side element - UM-ALU 4-100,5 COVERLID 75 AL - 2201760



Press-drawn section housings, Side elements (left and right), incl. snap-on foot, width: 105.4 mm, height: 2 mm

Base latch - UM-ALU 4 FOOT - 2200974



Press-drawn section housings, Snap-on foot for DIN rail, incl. screw

## Profile - UM-ALU 4-100,5 PROFILE 130 - 2200938

### Accessories

Side element - UM-ALU 4-100,5 COVER PA BK - 2200952

Press-drawn section housings, Side elements (left and right), incl. snap-on foot, width: 105.4 mm, color: black (9005)



---

### Additional products

Profile cover - UM-ALU 4 AU45 L130 - 2200957



Press-drawn section housings, Profile cover, Profile width (internal): 42 mm, length: 130 mm

---

Profile cover - UM-ALU 4 AU75 L130 - 2200966



Press-drawn section housings, Profile cover, Profile width (internal): 71.5 mm, length: 130 mm

---

Front plate - UM-ALU 4-100,5 FRONT 130 AP - 2202098



Press-drawn section housings, Basic profile front plate, width: 101.8 mm, length: 130 mm

---