

Profile - UM-ALU 4-100,5 PROFILE 200 - 2200940

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Press-drawn section housings, Basic profile, Profile width (internal): 100.5 mm, length: 200 mm



Your advantages

- ✔ Item is from the UM-ALU product range
- ✔ Aluminum press-drawn section
- ✔ Available in lengths from 42.5 mm ... 990 mm, can be cut to any length
- ✔ Available in overall widths of 75 mm and 105 mm
- ✔ Variety of connection technologies
- ✔ Can be mounted on the DIN rail
- ✔ EMC protection

Key Commercial Data

Packing unit	1 pc
GTIN	 4 046356 716420
GTIN	4046356716420
Weight per Piece (excluding packing)	240.000 g
Custom tariff number	76042990
Country of origin	Germany

Technical data

Product properties

Brief article description	Profile
Type	UM-ALU 4-100,5 PROFILE 200
Order No.	2200940

Profile - UM-ALU 4-100,5 PROFILE 200 - 2200940

Technical data

Product properties

Housing type	Press-drawn section housings
Type	Basic profile
Mounting type	Screw mounting

Dimensions

Length	200 mm
Profile width (external)	105 mm
Profile width (internal)	100.5 mm
Depth	29.4 mm
Depth from top edge of DIN rail	25.5 mm

Material specifications

Material	Aluminum
Color	aluminum color
Surface characteristics	anodized

Ambient conditions

Ambient temperature (operation)	-40 °C ... 105 °C
---------------------------------	-------------------

PCB specifications

PCB holders	2
PCB thickness	1.4 mm ... 2 mm
PCB surface	18657 mm ² ... 19783 mm ²
Mounting position	parallel to the DIN rail
Type of PCB mount	Slot

General information

Type of note	Assembly instruction:
Note	Refer to the data sheet for the range in the download area.

Packaging specifications

Type of packaging	packed in cardboard
Pieces per package	1
Denomination packing units	Pcs.
Outer packaging type	Carton


Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Profile - UM-ALU 4-100,5 PROFILE 200 - 2200940

Dimensional drawing

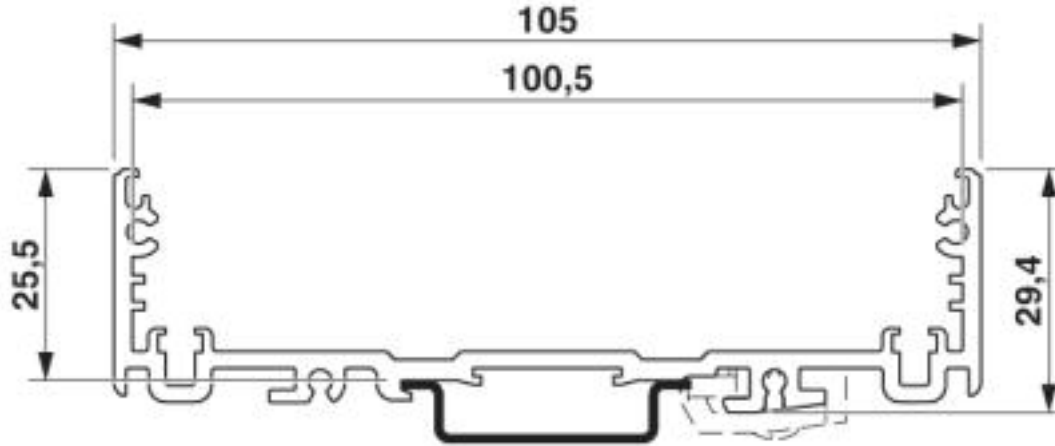

Classifications

eCl@ss

eCl@ss 10.0.1	27182701
eCl@ss 4.0	27180400
eCl@ss 4.1	27180400
eCl@ss 5.0	27180500
eCl@ss 5.1	27180500
eCl@ss 6.0	27182000
eCl@ss 7.0	27182701
eCl@ss 8.0	27182701
eCl@ss 9.0	27182701

ETIM

ETIM 3.0	EC001031
ETIM 4.0	EC000721
ETIM 5.0	EC002779
ETIM 6.0	EC002779
ETIM 7.0	EC002779

UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

Profile - UM-ALU 4-100,5 PROFILE 200 - 2200940

Classifications

UNSPSC

UNSPSC 18.0	31261501
UNSPSC 19.0	31261501
UNSPSC 20.0	31261501
UNSPSC 21.0	31261501

Accessories

Necessary add-on products

Side element - UM-ALU 4-100,5 COVER AL - 2200951



Press-drawn section housings, Side elements (left and right), incl. snap-on foot, width: 105.4 mm, height: 2 mm

Side element - UM-ALU 4-100,5 COVERLID 45 AL - 2201759



Press-drawn section housings, Side elements (left and right), incl. snap-on foot, width: 105.4 mm, height: 2 mm

Side element - UM-ALU 4-100,5 COVERLID 75 AL - 2201760



Press-drawn section housings, Side elements (left and right), incl. snap-on foot, width: 105.4 mm, height: 2 mm

Base latch - UM-ALU 4 FOOT - 2200974



Press-drawn section housings, Snap-on foot for DIN rail, incl. screw

Profile - UM-ALU 4-100,5 PROFILE 200 - 2200940

Accessories

Side element - UM-ALU 4-100,5 COVER PA BK - 2200952

Press-drawn section housings, Side elements (left and right), incl. snap-on foot, width: 105.4 mm, color: black (9005)



Additional products

Profile cover - UM-ALU 4 AU75 L200 - 2200968



Press-drawn section housings, Profile cover, Profile width (internal): 71.5 mm, length: 200 mm

Front plate - UM-ALU 4-100,5 FRONT 200 AP - 2202100



Press-drawn section housings, Basic profile front plate, width: 101.8 mm, length: 200 mm
