

## Mounting material - PSD-S ME B-P - 2700163


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Foot for tube Ø 25 mm, plastic, black



### Key Commercial Data

Packing unit	1 pc
GTIN	 4 046356 491525
GTIN	4046356491525
Weight per Piece (excluding packing)	40.000 g
Custom tariff number	39269097
Country of origin	Germany

### Technical data

#### Dimensions

Diameter	70 mm
Height	37 mm

#### Ambient conditions

Ambient temperature (operation)	-30 °C ... 60 °C
---------------------------------	------------------

#### General

Material	PA-GF
Color	black
Weight	42 g
Mounting position	any
Mounting type	Tube mounting

# Mounting material - PSD-S ME B-P - 2700163

## Technical data

### General


	Base mounting
Assembly instructions	Seal is supplied with
Scope of delivery	1 x plastic screw 1 x seal

### Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

## Drawings

Dimensional drawing

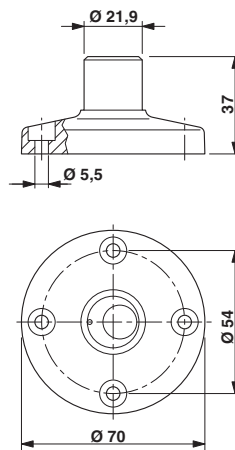

## Classifications

### eCl@ss

eCl@ss 10.0.1	27371235
eCl@ss 11.0	27371235
eCl@ss 4.0	27143200
eCl@ss 4.1	27143200
eCl@ss 5.0	27371200
eCl@ss 5.1	27371200
eCl@ss 6.0	27371200
eCl@ss 7.0	27371235
eCl@ss 9.0	27371235

# Mounting material - PSD-S ME B-P - 2700163

## Classifications

### ETIM

ETIM 3.0	EC001154
ETIM 4.0	EC001154
ETIM 6.0	EC001154
ETIM 7.0	EC001154

### UNSPSC

UNSPSC 6.01	43172015
UNSPSC 7.0901	43201404
UNSPSC 11	39121311
UNSPSC 12.01	39121311
UNSPSC 13.2	43221528
UNSPSC 18.0	43221528
UNSPSC 19.0	43221528
UNSPSC 20.0	43221528
UNSPSC 21.0	43221528

## Approvals

### Approvals

---

Approvals

EAC

---

Ex Approvals

---

### Approval details

EAC		RU *- DE.A*30.B.00237
-----	---	--------------------------

---