

## Wiring bridge - TMC 8 B1 80 57 C - 2907991

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Bus bar for TMC 81... circuit breakers (single phase). 17.8 mm pitch, up to 57 positions. Rated for 80 A (end feed) 1000 V AC/DC. UL 508 Listed for connection of UL 489 rated circuit breakers.



### Key Commercial Data

Packing unit	1 pc
GTIN	 4 055626 352909
GTIN	4055626352909
Weight per Piece (excluding packing)	1.000 g
Country of origin	Germany

### Technical data

#### Dimensions

Width	1031 mm
Height	28.5 mm
Depth	19.3 mm

#### General

Nominal voltage $U_N$	1000 V AC/DC
Nominal current $I_N$	80 A (End feed) 160 A (Center feed with two 115A TMC 8 B TERM PIN terminals required per phase)
Rated voltage	1000 V
Number of positions	57
Color	gray
Housing material	Plastic


# Wiring bridge - TMC 8 B1 80 57 C - 2907991

## Technical data

### General

Type	Comb bridge
------	-------------

## Drawings

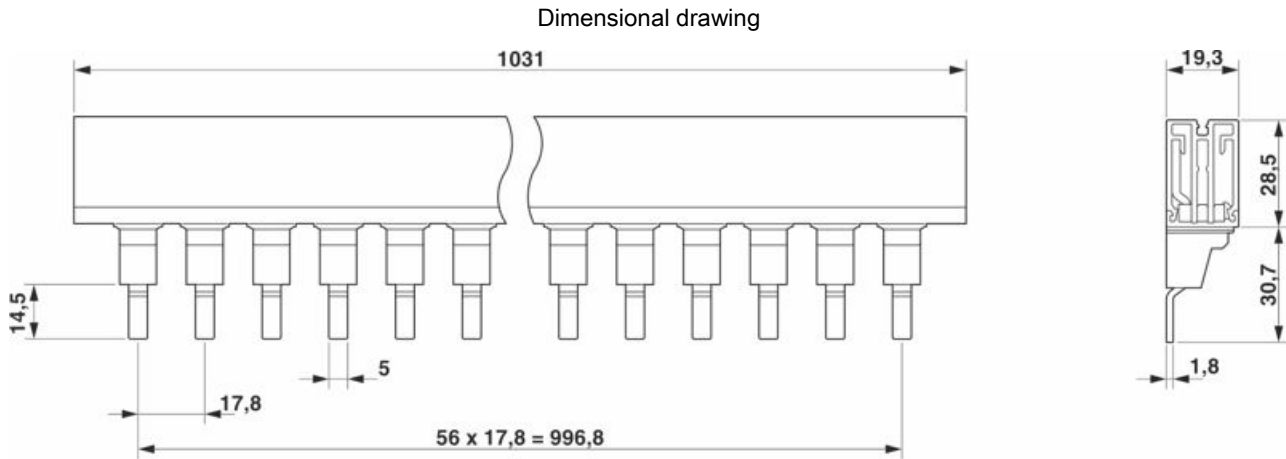

## Approvals

### Approvals

---

### Approvals

UL Listed / cUL Listed / cULus Listed

---

### Ex Approvals

---


### Approval details

## Wiring bridge - TMC 8 B1 80 57 C - 2907991

### Approvals

UL Listed		<a href="http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm">http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm</a>	FILE E 123528
-----------	---	---	---------------

cUL Listed		<a href="http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm">http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm</a>	FILE E 123528
------------	---	---	---------------

cULus Listed			
--------------	---	--	--