

Wiring bridge - TMC 8 B1 80 37 CA - 2907992

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Bus bar for TMC 81... circuit breakers (single phase) with auxilliary switch module. 17.8 mm pitch, up to 37 positions. Rated for 80 A (end feed) 1000 V AC/DC. UL 508 Listed for connection of UL 489 rated circuit breakers.

Image shows ...C version



Key Commercial Data

| | |
|--------------------------------------|---|
| Packing unit | 1 pc |
| GTIN |  4 055626 352916 |
| GTIN | 4055626352916 |
| Weight per Piece (excluding packing) | 1.000 g |
| Country of origin | Germany |

Technical data

Dimensions

| | |
|--------|---------|
| Width | 1006 mm |
| Height | 19.3 mm |
| Depth | 59.2 mm |

General

| | |
|-----------------------|---|
| Nominal voltage U_N | 1000 V AC/DC |
| Nominal current I_N | 80 A (End feed) |
| | 160 A (Center feed with two 115A TMC 8 B TERM PIN terminals required per phase) |
| Rated voltage | 1000 V |
| Number of positions | 37 |
| Color | gray |


Wiring bridge - TMC 8 B1 80 37 CA - 2907992

Technical data

General

| | |
|------------------|-------------|
| Housing material | Plastic |
| Type | Comb bridge |

Drawings

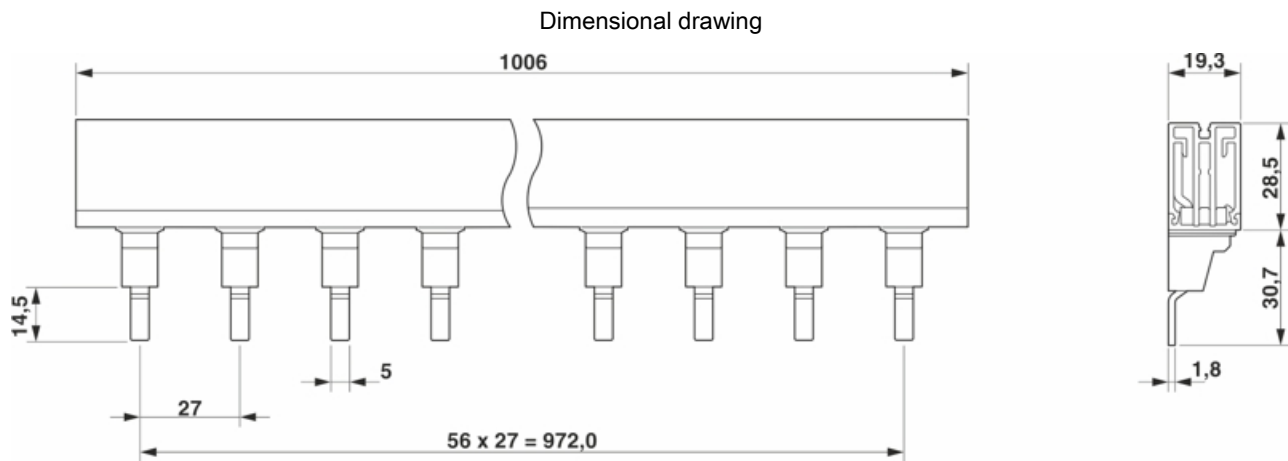

Approvals

Approvals

Approvals

UL Listed / cUL Listed / cULus Listed

Ex Approvals

Approval details

Wiring bridge - TMC 8 B1 80 37 CA - 2907992

Approvals

| | | | |
|-----------|---|---|---------------|
| UL Listed |  | http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm | FILE E 123528 |
|-----------|---|---|---------------|

| | | | |
|------------|---|---|---------------|
| cUL Listed |  | http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm | FILE E 123528 |
|------------|---|---|---------------|

| | | | |
|--------------|---|--|--|
| cULus Listed |  | | |
|--------------|---|--|--|