

Wiring bridge - TMC 8 B3 80 57 C - 2907996

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Bus bar for TMC 83... circuit breakers (three phase) 17.8 mm pitch, up to 57 positions. Rated for 80 A (end feed) 600 V AC/DC. UL 508 Listed for connection of UL 489 rated circuit breakers.



Key Commercial Data

Packing unit	1 pc
GTIN	
GTIN	4055626352947
Weight per Piece (excluding packing)	1.000 g
Country of origin	Germany

Technical data

Dimensions

Width	1031 mm
Height	19.3 mm
Depth	59.2 mm

General

Nominal voltage U_N	600 V AC/DC
Nominal current I_N	80 A (End feed) 160 A (Center feed with two 115A TMC 8 B TERM PIN terminals required per phase)
Rated voltage	600 V
Number of positions	57
Color	gray
Housing material	Plastic

Wiring bridge - TMC 8 B3 80 57 C - 2907996


Technical data

General

Type	Comb bridge
------	-------------

Drawings

Dimensional drawing

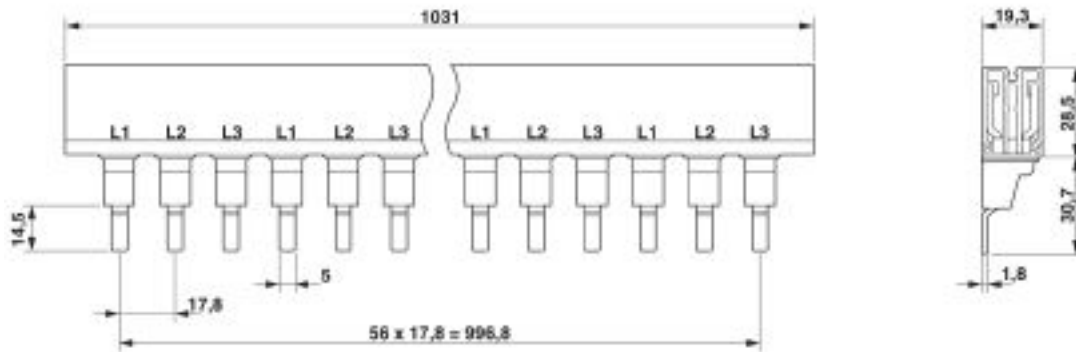

Approvals

Approvals

Approvals

UL Listed / cUL Listed / cULus Listed

Ex Approvals

Approval details

UL Listed		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	FILE E 123528
-----------	--	---	---------------

cUL Listed		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	FILE E 123528
------------	--	---	---------------

Wiring bridge - TMC 8 B3 80 57 C - 2907996

Approvals

cULus Listed

