


Single plug-in bridge - FBST 6-PLC GY - 2966825

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

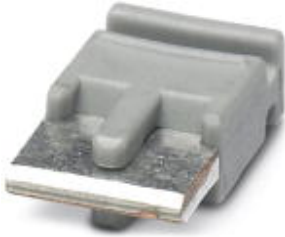


Single plug-in bridge, length: 6 mm, number of positions: 2, color: gray



COMPLETE

Key Commercial Data

Packing unit	1 pc
Minimum order quantity	50 pc
GTIN	 4 017918 130640
GTIN	4017918130640
Weight per Piece (excluding packing)	0.436 g
Custom tariff number	85389099
Country of origin	Germany

Technical data

Dimensions

Length	6 mm
--------	------

General

Current	6 A
Number of positions	2
Color	gray

Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Single plug-in bridge - FBST 6-PLC GY - 2966825

Classifications

eCl@ss

eCl@ss 4.0	27371100
eCl@ss 4.1	27371100
eCl@ss 5.0	27371600
eCl@ss 5.1	27371600
eCl@ss 6.0	27379200
eCl@ss 7.0	27379208
eCl@ss 8.0	27379208
eCl@ss 9.0	27371692

ETIM

ETIM 4.0	EC002586
ETIM 5.0	EC002586
ETIM 6.0	EC002586
ETIM 7.0	EC002586

UNSPSC

UNSPSC 6.01	30211802
UNSPSC 7.0901	39121402
UNSPSC 11	39121402
UNSPSC 12.01	39121402
UNSPSC 13.2	39121426

Approvals

Approvals

Approvals

PRS / GL

Ex Approvals

Approval details

PRS		http://www.prs.pl/	TE/2109/880590/16
-----	---	---	-------------------

Single plug-in bridge - FBST 6-PLC GY - 2966825

Approvals

GL		https://approvalfinder.dnvgl.com/	46016-03 HH
----	---	---	-------------