

## Ring cable lug - C-RC 2,5/M5 DIN - 3240079

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Ring cable lug, non-insulated, 1.1 ... 2.5 mm<sup>2</sup>, M5

### Why buy this product

- ✓ The CRIMPFOX-RC... tools from our CRIMPFOX range of crimping pliers are available for optimum crimping
- ✓ The ring cable lugs without plastic sleeve are made from high-quality tin-plated electrolytic copper for maximum protection against corrosion
- ✓ The hard-soldered press zone enables maximum conductor pull-out values to be achieved

### Key Commercial Data

Packing unit	1 STK
Minimum order quantity	100 STK
GTIN	 4 046356 452960
GTIN	4046356452960
Weight per Piece (excluding packing)	1.000 g
Custom tariff number	85369010
Country of origin	China

### Technical data

#### Dimensions

Length (b)	19 mm
Width (a)	10 mm
Maximum stripping length	8 mm
Length of insulation sleeve (c)	5 mm
Inner dimension of the insulating collar (d)	2.3 mm
Distance between the center and the insulation sleeve (e)	9 mm

# Ring cable lug - C-RC 2,5/M5 DIN - 3240079

## Technical data

### Dimensions

Inner diameter (f)	5.3 mm
Material thickness (g)	0.8 mm

### Ambient conditions


Ambient temperature (operation)	110 °C
---------------------------------	--------

### General

Color	silver
Stripping length	8 mm
Material	Copper
Coating	Tin-plated

## Drawings

Dimensional drawing

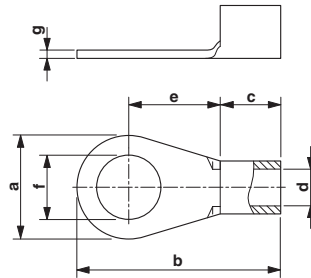

## Approvals

Approvals

---

Approvals

EAC / EAC

---

Ex Approvals

---

Approval details

EAC 7500651.22.01.00246
-------------------------

## Ring cable lug - C-RC 2,5/M5 DIN - 3240079

### Approvals

EAC EAC-Zulassung
-------------------