

Ring cable lug - C-RC 10/M5 DIN - 3240089

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Ring cable lug, non-insulated, 10 mm², M5

Why buy this product

- ✓ The CRIMPFOX-RC... tools from our CRIMPFOX range of crimping pliers are available for optimum crimping
- ✓ The ring cable lugs without plastic sleeve are made from high-quality tin-plated electrolytic copper for maximum protection against corrosion
- ✓ The hard-soldered press zone enables maximum conductor pull-out values to be achieved

Key Commercial Data

Packing unit	1 STK
Minimum order quantity	100 STK
GTIN	 4 046356 453066
GTIN	4046356453066
Weight per Piece (excluding packing)	5.200 g
Custom tariff number	85369010
Country of origin	China

Technical data

Dimensions

Length (b)	21 mm
Width (a)	10 mm
Maximum stripping length	11 mm
Length of insulation sleeve (c)	8 mm
Inner dimension of the insulating collar (d)	4.5 mm
Distance between the center and the insulation sleeve (e)	8 mm

Ring cable lug - C-RC 10/M5 DIN - 3240089

Technical data

Dimensions

Inner diameter (f)	5.3 mm
Material thickness (g)	1.1 mm

Ambient conditions


Ambient temperature (operation)	110 °C
---------------------------------	--------

General

Color	silver
Stripping length	11 mm
Material	Copper
Coating	Tin-plated

Drawings

Dimensional drawing

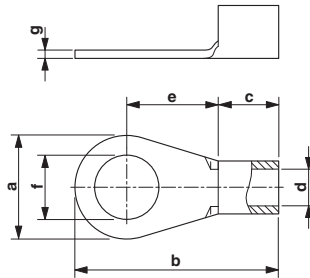

Approvals

Approvals

Approvals

EAC / EAC

Ex Approvals

Approval details

EAC 7500651.22.01.00246

Ring cable lug - C-RC 10/M5 DIN - 3240089

Approvals

EAC EAC-Zulassung
