

Crimping pliers - CRIMPFOX 16R TWIN - 1212845


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Crimping pliers, for TWIN ferrules according to UL 486F, three marked die stations, unlockable pressure lock, lateral entry

Why buy this product

- Ergonomically designed handles ensure an optimum grip and reduce the amount of force required by 25%

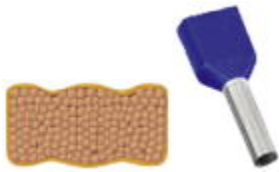

Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 406220
GTIN	4055626406220
Weight per Piece (excluding packing)	680.000 g
Custom tariff number	82032000
Country of origin	Sweden

Technical data

Dimensions

Length (b)	256 mm
Width (a)	25 mm
Height (c)	68 mm

General

Color	black
Compression	WM crimp
Type of contact	TWIN ferrules

Crimping pliers - CRIMPFOX 16R TWIN - 1212845

Technical data

General

Weight	578 g
Min. cross section	6 mm ²
Max. cross section	16 mm ²

Classifications

eCl@ss

eCl@ss 4.0	21040301
eCl@ss 4.1	21040301
eCl@ss 5.0	21040301
eCl@ss 5.1	21040301
eCl@ss 7.0	21043811
eCl@ss 9.0	21043811

ETIM

ETIM 2.0	EC001186
ETIM 3.0	EC001186
ETIM 4.0	EC001186
ETIM 5.0	EC000168
ETIM 6.0	EC000168

UNSPSC

UNSPSC 6.01	27112118
UNSPSC 7.0901	27111518
UNSPSC 11	23171604
UNSPSC 12.01	27111518
UNSPSC 13.2	27111518

Approvals

Approvals

Approvals

EAC

Ex Approvals

Crimping pliers - CRIMPFOX 16R TWIN - 1212845

Approvals

Approval details

EAC		RU x- DE.xx08.B.02974
-----	---	--------------------------

Accessories

Accessories

Die

Replacement die - CRIMPFOX 16R TWIN/DIE - 1212846



Replacement die for CRIMPFOX 16R TWIN

Mounting material

Replacement spring - CRIMPFOX/ SPR-1 - 1212069



Spare recuperating spring