

Thermomagnetic device circuit breaker - TMC 7/8 240VAC SHNT - 2908227

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Thermomagnetic device circuit breaker, connection method: Screw, cross section: 1 mm²- 35 mm², AWG: 18 - 2, width: 18 mm, mounting type: Snaps on to side of circuit breaker, Color: gray



Key Commercial Data

Packing unit	1 STK
Weight per Piece (excluding packing)	150.000 g
Custom tariff number	85362010
Country of origin	China

Technical data

General

Mounting type	Snaps on to side of circuit breaker
Color	gray

Electrical data

Operating voltage	240 V AC
Rated current I _N	6 A

Dimensions

Height	83 mm
Width	18 mm
Depth	65.7 mm

Ambient conditions

Ambient temperature (operation)	-35 °C ... 70 °C
---------------------------------	------------------

Connection data

Conductor cross section solid min.	1 mm ²
------------------------------------	-------------------

Thermomagnetic device circuit breaker - TMC 7/8 240VAC SHNT - 2908227


Technical data

Connection data

Conductor cross section solid max.	35 mm ²
Conductor cross section flexible min.	1 mm ²
Conductor cross section flexible max.	35 mm ²
Conductor cross section AWG min.	18
Conductor cross section AWG max.	2
Connection method	Screw
Tightening torque max	1 Nm

Drawings

Dimensional drawing

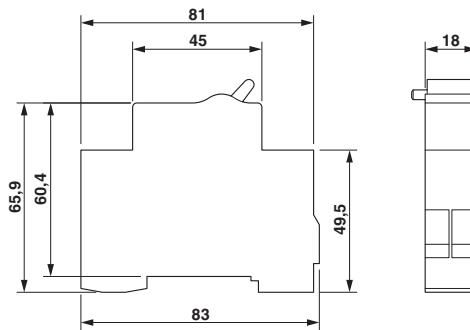

Classifications

eCl@ss

eCl@ss 5.1	27379201
eCl@ss 7.0	27130806
eCl@ss 8.0	27141116
eCl@ss 9.0	27141116

ETIM

ETIM 5.0	EC000899
ETIM 6.0	EC000942

UNSPSC

UNSPSC 13.2	39121620
-------------	----------

Approvals

Approvals

Thermomagnetic device circuit breaker - TMC 7/8 240VAC SHNT - 2908227

Approvals

Approvals


UL Listed / cUL Listed / cULus Listed

Ex Approvals

Approval details

UL Listed		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	FILE E 478429
-----------	---	---	---------------

cUL Listed		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	FILE E 478429
------------	---	---	---------------

cULus Listed			
--------------	---	--	--
