

PA AMPLIFIER & LINE MATCHING TRANSFORMERS

MOBILE FIXED LOCATIONS

AC-DC P.A. Amplifier

30 WATTS RMS
2 LOW IMPEDANCE
MICROPHONE INPUTS

USE IT ANYWHERE

45 WATT (PEAK POWER)

- 12 Volt DC for MOBILE USE
- 117 Volt AC 50/60 HZ for FIXED LOCATIONS

No. PA503

The versatility of this powerful P.A. Amplifier enables the user to operate it anywhere: For mobile use - 12VDC (with positive or negative ground). For auditoriums or other fixed stations -117VAC 50-60 cycles.

Its versatility does not end as WHERE it can be used - but also as to HOW it can be used: Two low impedance microphone inputs, auxiliary input for cassettes, reel-to-reel tape recorders, phonos and CD players. Special music input for musical instruments, tuners and audio decks. The brushed aluminum front panel has gain controls for 3 different sources of audio including 2 independent mike mixing controls.

FEATURES

- Sturdy Adjustable Mounting Bracket
- Convenient Mike Input on Rear and Front Panel
- Fused Line
- Ideally suited for both crisp and clean sound whether using amplifier for voice or music.
- Size: 10-3/4" W x 6-3/8" D x 2-3/4" H (Less Feet)



SPECIFICATIONS:

Power Output: 30 watts RMS @ 2% THO

Frequency Response: 50 - 18,000 Hz

Line Outputs: 25 volts & 70 volts

Output

Impedance: 4-8-16 ohms

Power

Requirements: 12VDC and / or 117VAC 50-60Hz

INCLUDED ACCESSORIES

A Complete Indoor / Outdoor Mobile P.A. System No. PAK4

CONTAINING
ALL THESE
QUALITY
COMPONENTS



This...SOLID STATE AMPLIFIER Plus...TRUMPET SPEAKER Plus...CARDIOID DYNAMIC MICROPHONE

No. PA503

No. WP13

No. 71-1500



See Features Listed Above

See page 92 for Features




High Quality Speaker Wire

This speaker wire is American made, and is polarity marked for your convenience. We offer speaker wire in varying gauges and put-ups to suit your particular needs. All on plastic spool.

| | 24AWG | 22AWG | 20AWG | 18AWG | 16AWG | 14AWG |
|-------|----------|----------|----------|----------|----------|----------|
| 25' | 48-24025 | 48-22025 | 48-20025 | 48-18025 | 48-16025 | 48-14025 |
| 50' | 48-24050 | 48-22050 | 48-20050 | 48-18050 | 48-16050 | 48-14050 |
| 100' | 48-24100 | 48-22100 | 48-20100 | 48-18100 | 48-16100 | 48-14100 |
| 500' | 48-24500 | 48-22500 | 48-20500 | 48-18500 | 48-16500 | 48-14500 |
| 1000' | 48-24102 | 48-22102 | 48-20102 | 48-18102 | 48-16102 | 48-14102 |

Dual Line Matching Transformer

Eliminate power loss caused by long distance between Amplifier and speaker. For 8 ohm speakers .70 volt / 25 volt dual voltage

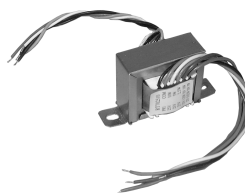

No. MT2570

Specifications:

- * Full range frequency response ± 1.2 db 50-15000HZ
- * High efficiency design
- * Insertion loss .6 db
- * Primary taps .63, 1.25, 2.5, 5, & 10W
- * Secondary impedance: 8 ohms
- * Primary terminations: 6" color coded leads
- * Secondary terminations: 6" color coded leads
- * Power rating: 10 watts

For bulk add suffix letter "B"