


FUSE & FUSE HOLDERS

FUSE HOLDERS

Fuse Block
for 5.0 x 20mm Fuses

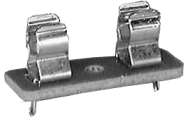

Specifications:
Electrical: Rated for currents, up to 6.3A
Clip/terminals: Nickel-plated tin-plated spring Brass ear type
Base: Phenolic laminate or glass fiber
No. FH501

Fuse Block
for 5.0 x 20mm Fuses



Specifications:
Electrical: Rated for currents, up to 6.3A
Clip/terminals: Nickel-plated tin-plated spring Brass ear type
Base: Phenolic laminate or glass fiber
No. FH503

Fuse Block
for 3AG Fuses



Specifications:
Electrical: Rated for currents, up to 10A
Clip/terminals: Nickel-plated tin-plated spring Brass ear type
Base: Phenolic laminate or glass fiber
No. FH551

Fuse Block
for 3AG Fuses



Specifications:
Electrical: Rated for currents, up to 10A
Clip/terminals: Nickel-plated tin-plated spring Brass ear type
Base: Phenolic laminate or glass fiber
No. FH554

Automotive Trailer Harnesses

These molded trailer harnesses are manufactured with a loop of 16AWG primary wire between the mating ends. We offer the most popular sizes for your custom installation needs.

Specifications
Connectors: .156" Bullet plugs & sockets
Wire: 16 AWG Automotive Primary wire
Body Material: Molded Vinyl



No. 65-1602
2 position flat, 12" loop
(Brn, Red)



No. 65-1603
3 position flat, 12" loop
(Grn, Yel, Brn)



No. 65-1604
4 position flat, 12" loop
(Grn, Yel, Brn, Wht)



No. 65-1624
4 position square, 12" loop
(Grn, Brn, Yel, Wht)

MAXI Fuses

These Buss™ fuses are suitable for use wherever Maxi Blade type fuses are specified. They are perfect for car stereo, Marine or General Automotive use. Made in U.S.A.



Part Number	Amperage	Color
MAX20A	20A	Yellow
MAX30A	30A	Green
MAX40A	40A	Orange
MAX50A	50A	Red
MAX60A	60A	Blue
MAX80A	80A	Clear

Buss is a registered trademark of Cooper/Bussman Industries

AGU Heavy Duty In-line Fuse Holder

Heavy Duty Spring loaded Fuse holder for AGU or AG Glass fuses. It has machine brass contacts in a bakelite housing with a 12" loop of 8 AWG wire.



No. FH8600

ATC Style In-line Fuse Holder

This is a heavy duty fuse holder to be used with ATC, ATO, and ATG blade type fuses. The wire is 10 AWG automotive primary wire in a 12" loop.



No. FH1040

 
Maxi Style In-line Fuse Holder

A heavy duty in-line fuse designed for the MAXI style fuses. It is constructed from 8 AWG automotive power cable, and has a screw hole for easy mounting. The fuse holder is rated for up to 80A.



No. FHMAXI

FUSES




Dimensions - 1/4" x 1-1/4"
Voltage Rating - 250V AC
Test Conditions - Grade A U.L. Listed up to 7.0 amps.
 Display packaged of (5) pcs.

No.	Current (amps)
No. 3AG1/4	1/4
No. 3AG1/2	1/2
No. 3AG3/4	3/4
No. 3AG1	1
No. 3AG1-1/2	1-1/2
No. 3AG2	2
No. 3AG3	3
No. 3AG4	4
No. 3AG5	5
No. 3AG7-1/2	7-1/2
No. 3AG10	10
No. 3AG15	15
No. 3AG20	20
No. 3AG25	25
No. 3AG30	30

EUROPEAN FUSES GMA TYPE

 
Dimensions - 5mm O.D. x 20mm length.
 Replacement fuse for foreign equipment.
 Display package of 5 pcs.
 Voltage Rating: 250V AC



No.	Current	No.	Current
No. EF1005	.5A	No. EF1050	5.0A
No. EF1010	1.0A	No. EF1060	6.0A
No. EF1015	1.5A	No. EF1080	8.0A
No. EF1020	2.0A	No. EF1100	10.0A
No. EF1025	2.5A	No. EF1150	15.0A
No. EF1030	3.0A		
No. EF1040	4.0A		

SFE SERIES AUTO FUSES

 Voltage Rating - 32V
 Display package of (5) pcs.



No.	Current	Size
No. SFE4A	4A	1/4" x 5/8"
No. SFE6A	6A	1/4" x 3/4"
No. SFE75A	7-1/2A	1/4" x 7/8"
No. SFE9A	9A	1/4" x 7/8"
No. SFE14A	14A	1/4" x 1-1/16"
No. SFE20A	20A	1/4" x 1-1/4"
No. SFE30A	30A	1/4" x 1-7/16"

FUSE PULLER and INSERTION TOOL



No. P100
 Durable plastic tool for removal of all 5mm and 1/4" diameter glass fuses. 2nd end allows user to remove and insert blade type fuses.

Gold AGU / 5 AG TYPE FUSES

For HI-FI, Auto high Current Fuses, Custom Installation.



13/32" D x 1-1/2" L.
 (32V) 15A, 20A, 25A, 30A, 35A, 40A, 50A & 60A.
 Display Package of 2 Pcs.

No.	Current	Volts
No. 8615	15A	32V
No. 8620	20A	32V
No. 8625	25A	32V
No. 8630	30A	32V
No. 8635	35A	32V
No. 8640	40A	32V
No. 8650	50A	32V
No. 8660	60A	32V

BLADE TYPE TERMINAL FUSES

Voltage Rating - 32V
 Suitable for American cars. Display package of (5) pcs.



No.	Current (amps)
No. PAP3	3 Purple
No. PAP5	5 Tan
No. PAP75	7.5 Brown
No. PAP10	10 Red
No. PAP15	15 Blue
No. PAP20	20 Yellow
No. PAP25	25 Clear
No. PAP30	30 Green

EMERGENCY KIT
 Contains 1 each of value fuse in display package.
No. PAP8

SLO-BLO



Dimensions:
 1/4" x 1-1/4"
Voltage Rating:
 250V AC
Test Conditions:
 Grade A U.L. Listed up to 7.0 amps.
 Display Package of (2) pcs. Current

No. SB1	1A
No. SB2	2A
No. SB3	3A
No. SB5	5A
No. SB7-1/2	7-1/2A
No. SB10	10A