

SWITCHES AUTOMOTIVE & MARINE

Stylish Automotive TOGGLE SWITCH with LED

Brushed and tapered bat handle gives this switch a "classy" look; perfect for custom dash. LED (red) lights to indicate power is "on". The 20 amp rating is plenty for many automotive accessories. Terminals accept standard .250" push-on terminals or may be soldered.

This is a three terminal switch with one connection for ground which is needed to light the LED.




Electrical Rating:
SPST snap action toggle.
Rated at 12-14 volts DC, 20 amps.
Terminals: .250" push-on terminals or solder.
Mounting hole: 1/2" diameter round.
Metal actuator 1 1/16" length
Construction: polycarbonate UL94-1 rating

Part No.	Circuit Type
30-12180	ON - OFF SPST




"Surf and Turf" GUARDIAN SWITCHES

The Guardian series is dust and moisture resistant, designed for use in a marine environment or dusty equipment such as construction equipment, off-road vehicles and farm equipment. This is a tough switch and designed to meet or exceed IP66 requirements. Snap-in mounting requires a rectangular cut-out

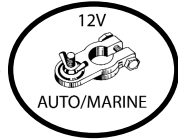

Electrical Rating:
SPST or SPDT snap action toggle
Rated: 12-14 volts DC 20 amps.
Terminals: accept .250" push-on terminals.
Mounting hole: rectangular .60 X 1.450 (+/- .004") hole in panels up to .050" thickness.

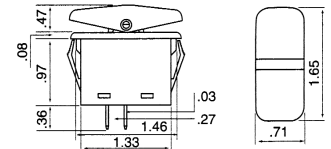

Part No.	Rocker Color	Action	no. of Terminals	Type
30-12280	Black/Black	ON-OFF	2	SPST
30-12281	Black/Red Dep.	ON-OFF	3	SPST
30-12282	Black/Black	ON-OFF-ON	3	SPDT
30-12284	Black/Black	(ON)-OFF-(ON)	3	SPDT

Auto Alarm Style SUB-MINIATURE TOGGLE SWITCH

A switch often used by alarm installers to set/un-set alarm systems; mounting is typically under or in the dash. The alarm switch comes with an attached "pigtail" that is 24" long, red and black insulated, stranded 20 gauge wire. Rated at 6 amps at 12-14 VDC, this ON-OFF SPST switch could easily be used for any number of appliances, as well as for arming alarms. Included is a miniature escutcheon plate with the legends ON and OFF. Mount hole: 1/4" diameter round.



No. 30-10005

MODULAR PANELS (Switch Brackets)

Modular panels, or switch mounting brackets, permit mixing of switch types and easy mounting of switches in general. Two brackets will accommodate switches that need either round or rectangular holes.



Part No.	Description
30-12575	for switches needing a 1/2" X 1" rectangular hole
30-12585	for switches needing a 1/2" dia. round hole

Big PUSH-BUTTON SWITCH (HORN SWITCH)

Surface mounting switch commonly used for fog-horn or siren. Momentary action, horn will sound only as long as button is depressed. The switch is designed for typical mobile and marine 12-14 volt DC applications.

The actuator is black plastic button, and the frame is chrome plated brass construction. Overall length is 2-5/8" by 1-1/2". Rated at 5 Amps 12-14 VDC. SPST, (ON)-OFF



Mounting Center 2 1/16"



No. 30-12465

* () = Momentary

Extra Heavy Duty PUSH BUTTON (Starter) SWITCH WITH WEATHER-BOOT NUT

A heavy-duty (50 amps) push-button momentary switch that is dust and moisture resistant; rubber boot-nut is included for enhanced protection. Contacts are silver/copper for long life.

Electrical and mechanical
5/8" x 32 mounting bushing, panels up to 1/2" thickness.
SPST Momentary action, (ON)-OFF
Screw Terminals (X2)
Rated 50 amps @ 12-14 VDC
Rubber dust boot/nut included.



No. 30-12475

* () = Momentary