

# TOOLS

## CRIMPING TOOL for "D" SUBMINIATURE CONNECTORS



Hand held tool crimps D-Sub pins (male and female) with a single squeeze on the contact material. Has built-in wire cutter. PVC handle allows crimping in comfort.

**No. WS26**

## PROFESSIONAL D-SUB CONTACT RATCHET CRIMPING TOOL



**No. YAC4 D-Sub Contact Crimping Tool**

- Precision
- High Quality
- Durable
- 18-22 AWG, 24-30 AWG
- Six section pressure adjustment
- For female and male D-subminiature contacts

## CRIMPING TOOL for "F" CONNECTORS

For a tight, permanent crimp, this ferrule tool does the proper job every time. Two slots are provided for RG59/U and RG58/U coaxial cable.



**No. WS17**

## ECONOMY HEX CRIMPING TOOL


For a tight and permanent crimp. Designed for coaxial fittings on RG59/U, RG62/U and RG6/U. PE insulation grip handle for comfort and maximum crimping force. Made of tempered steel. 8" long.



**No. 12-170**

## PROFESSIONAL RATCHET COAXIAL CRIMPING TOOL

For CATV, MATV, and TVRO installations. This economically priced tool is just right for the professional installer and hobbyist alike. Small enough to fit in the tool belt and rugged enough for any job. It works with most "F", BNC, TNC, UHF, Mini-UHF, SMA, & RCA connectors

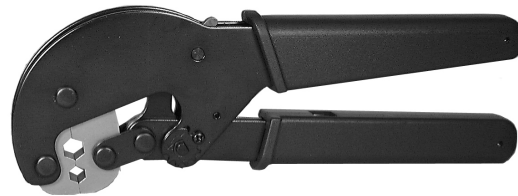

### Features

- Heavy-duty Steel construction
- Insulated Handle
- Non-replaceable Drop-forged jaws
- Overall length 9" (229mm)
- Hex Crimp for RG 59, RG62 (.255") RG6, (.322")

**No. 63-116** Professional Ratcheting Hex Crimp Tool  
RG59, RG62, and RG6

## PROFESSIONAL HEX CRIMP TOOL

Perfect for CATV, MATV and TVRO installations, when heavy duty crimping is required. It's light enough to fit conveniently in an installers belt. Features cushion plastic handles for comfortable gripping. 9" overall length.



Works for all Philmore **No. WS25** - Crimps RG59/U, RG6/U crimp-on connectors for **No. WS27** - Crimps RG58/U, RG59/U stated wire type: 'F', BNC, TNC, UHF, Mini **No. WS29** - Crimps Philmore Pro-Crimp UHF, SMA.

## Professional Ratchet Crimp Tool w/ Interchangeable Dies

- Full cycle ratchet mechanism with quick release safety lock
- High carbon steel ratchet frame
- PE insulation grip handle for comfort and maximum crimping force
- Interchangeable dies for F, BNC, TNC, N, Teflon, Thinnet-PVC / Teflon and Fiber-Optic connectors



**No. WS28** - (RG58/U, RG59/U and 1/16" pin)

**No. WS34** - For Insulated Terminals: (22-18 AWG, 16-14 AWG and 12-10 AWG)

**No. WS36** - (RG58/U, RG59/U and RG6/U)

## INTERCHANGEABLE CRIMP DIES

for Nos. WS28, WS34, WS36

Part No. Dies Only	Hex	Hex	Hex	Hex	Pin	Sq Pin	For Crimping RG Type Cable
<b>No. WS74</b>		.256"	.213"		.068"		59, 62, 140, 210, BELDEN 8279, 55, 58, 141, 142, 223, 303, 400, Fiber Optic
<b>No. WS76</b>	.319"		.213"	.187"			6, 55, 58, 141, 142, 223, 303, 400, 174, Fiber Optic
<b>No. WS78</b>	.319"	.256"	.213"		.068"		6, 59, 62, 140, 210, BELDEN 8279, 55, 58, 141, 142, 223, 303, 400, Fiber Optic.
<b>No. WS80</b>	.255"	.213"	.137"	.100"	.069"	.043"	59, 62, 8X, 140, 210, BELDEN 8279, 55, 58, 141, 142, 223, 303, 400, Fiber Optic
<b>No. WS82</b>	.178"	.151"	.128"	.078"	.068"	.042"	122, 174, 179, 180, 187, 188, 195, Fiber Optic 178, 316, BELDEN 8218.
<b>No. WS84</b>		.255"	.213"	.187"	.068"		55, 58, 59, 62, 140, 141, 142, 210, 223, 174, 303, 400, Fiber Optic, BELDEN 8279.
<b>No. WS88</b>	Coded: Red 22-18 Blue 16-14 Yellow 12-10						Insulated Terminals 10-22 ga.