

HEAVY-DUTY CABLE CUTTER

This heavy-duty cable cutter is perfect for those who are in need of a cutter which can cut large copper or aluminum cable. It is capable of cutting solid copper cable

up to 6 AWG (16mm²), stranded copper cable up to 2 AWG (35mm²) and stranded Aluminum up to 1/0 AWG (70mm²).



Features

Heavy-duty Carbon Steel construction
 Insulated Handle
 Non-replacable Drop-forged jaws
 Overall length 9.2" (235mm)
 Cutting Specifications: Solid Copper 6AWG MAX
 Stranded Copper 2AWG MAX
 Stranded Aluminum 1/0 AWG MAX

No. 63-6201 Heavy-duty cable cutter

COAXIAL CABLE CUTTER & STRIPPER

A tool for every handy man and home owner. This tool is great for cutting and stripping all types of wire and cable and has the added feature of a crimping function for F-59 and F-56 rings.



Features

High carbon Steel construction
 Insulated Handle
 Cuts Cable + Special slots for RG59, RG6
 Crimps F-59 & F-56 rings
 Overall length 6.7" (170mm)
 Economically Priced

No. 63-226 Coaxial Cutter & Stripper

WIRE STRIPPER & CUTTING TOOL

Dial-A-Wire Size

12-24 Gauge for Precision Stripping

Flush Cutting

The dial assures perfect stripping without a nick or break.

The tool has a black oxide finish with plastic cushion grip handles.

No. WS18



CABLE CUTTER

This heavy duty cable cutter features hardened carbon steel cutting blades and cushion handle grips. Cuts cable to 3/8" diameter. Perfect for coax and electrical cable. Length - 6-1/2" with closed lock feature.

No. WS50



WIRE STRIPPER

Stripper automatically holds wire and strips in one cycle. For wire sizes 8 thru 22 gauge. An optional strip-length setting stop is included.




No. 63-369

5-WAY ALL-PURPOSE WIRE TOOL

The overall length of the tool is 9" and is made of hardened steel. Matte black permanent finish with bright, clear markings makes it an attractive and easy-to-use product.

No. WS16

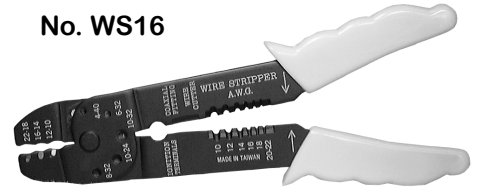

Features large comfortable plastic grip handles

A one piece tool that shapes and cuts wire 5 different ways:

- Standard wire cutter
- Crimps insulated terminals 22-14 • 12-10 AWG
- Shears 5 bolt sizes: 4-40 • 6-32 • 8-32 • 10-24 • 10-32
- Crimps non-insulated terminals 10-12 AWG • 14-16 AWG • 18-22 AWG
- Strips wire 10 to 22 AWG

COAXIAL CABLE STRIPPER

FAST - EFFECTIVE - NEAT - SINGLE ACTION

With an easy twirl of the finger, this stripper prepares cable at once for attaching coax connectors. A convenient changeover method using a reversible V-block assembly switches the cable size effortlessly between RG58/U, RG59/U and RG6/U.

The cutters are easily adjusted for non-standard cables by turning two set screws using the hex wrench stored in the handle. After the cable is cut, it is automatically stripped in a single action by removing the tool from the cable. Spare cutting blades are available and are readily installed.

No. WS145 - Strips RG6/U, RG58/U, RG59/U & RG62/U

No. WSB - Package of (4) Replacement Blades



PROFESSIONAL WIRE STRIPPER

This compact, self-adjust wire stripper is especially designed for smaller wire, Easily handles 16-30 gauge wire without adjustment. Tool has built in cutter. It is compact and operates with low force. Will strip stranded and solid wire with out nicking. Has adjustable stop for strip length.



- PATENTED
- PRECISE
- DURABLE
- FINE QUALITY

No. YY78318