 


# SOLDERLESS TERMINALS & CONNECTORS

## Male Bullet Connector Terminals

These bullet connectors are made of copper with tin plating. They are available in several wire sizes with receptacles to match.



Part #	Wire Size	Thick. (in.)	Width (in.)	Insulation Material	Color
65-7521 <sup>F</sup>	22-18	.032	.156	Vinyl	RED
65-7541 <sup>A</sup>	16-14	.032	.156	Vinyl	BLUE
65-7542 <sup>F</sup>	16-14	.032	.195	Vinyl	BLUE
65-7562 <sup>F</sup>	12-10	.032	.195	Vinyl	YELLOW

Package Qty: A = 15, B = 10, D = 8, F = 12, G = 5 Add "C" to # = 100pk

## Non-Insulated Seamless Butt Connectors

These butt connectors are braised and seamless for a smoother and more uniform crimp. They are available in several wire sizes.



 
Part #	Wire Size	Barrel Length
65-3020 <sup>B</sup>	22-18	15.0 mm
65-3040 <sup>D</sup>	16-14	15.0 mm
65-3060 <sup>G</sup>	12-10	20.0 mm

Package Qty: A = 15, B = 10, D = 8, F = 12, G = 5 Add "C" to # = 100pk

## Nylon Insulated Close End Connectors

These close end or pigtail connectors are constructed of tin plated copper which has a clear nylon insulator. They are available to accommodate several different wire sizes.

Part #	Wire Range
65-1232 <sup>F</sup>	22-14
65-1237 <sup>G</sup>	18-10
65-1242 <sup>G</sup>	18-8




Package Qty: A = 15, B = 10, D = 8, F = 12, G = 5 Add "C" to # = 100pk

## Wire Tap Splices

These connectors make it easy to splice into an existing cable in order to add another wire. They are available in three different sizes which are insulated and color coded for wire size identification.

Part #	Wire Range	Color
65-1280 <sup>B</sup>	22-18	Red
65-1285 <sup>B</sup>	16-14	Blue
65-1290 <sup>B</sup>	12-10	Yellow

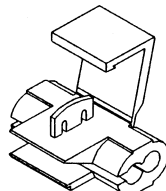

Package Qty: A = 15, B = 10, D = 8, F = 12, G = 5 Add "C" to # = 100pk

## Female Bullet Connector Receptacles

These bullet connectors are made of copper with tin plating. They are available in several wire sizes with male plugs to match. They are FULLY Insulated.



Part #	Wire Size	Thick. (in.)	Width (in.)	Insulation Material	Color
65-6521 <sup>D</sup>	22-18	.032	.156	Vinyl	RED
65-6541 <sup>D</sup>	16-14	.032	.156	Vinyl	BLUE
65-6542 <sup>D</sup>	16-14	.032	.195	Vinyl	BLUE
65-6562 <sup>D</sup>	12-10	.032	.195	Vinyl	YELLOW

Package Qty: A = 15, B = 10, D = 8, F = 12, G = 5 Add "C" to # = 100pk

## Insulated Seamless Butt Connectors

These butt connectors are braised and seamless for a smoother and more uniform crimp. They are available in several wire sizes with color coded insulation.



Part #	Wire Size	Barrel Length	Material	Color
65-1230 <sup>B</sup>	22-18	30.0 mm	Vinyl	RED
65-1235 <sup>B</sup>	16-14	30.0 mm	Vinyl	BLUE
65-1240 <sup>B</sup>	12-10	33.0 mm	Vinyl	YELLOW
65-1830 <sup>B</sup>	22-18	30.0 mm	Nylon	RED
65-1835 <sup>B</sup>	16-14	30.0 mm	Nylon	BLUE
65-1840 <sup>G</sup>	12-10	33.0 mm	Nylon	YELLOW

Package Qty: A = 15, B = 10, D = 8, F = 12, G = 5 Add "C" to # = 100pk

## Insulated Solderless Terminal Assortment

This convenient assortment lets you have the most popular terminals and sizes right at your finger tips.

### 175 Assorted Terminals


- Butt Splices
- Ring Terminals
- Spade Terminals
- Quick Connects

### 3 Wire Sizes

- 22-18
- 16-14
- 12-10

### H.D. Stripper & Crimp Tool

### Reusable Case

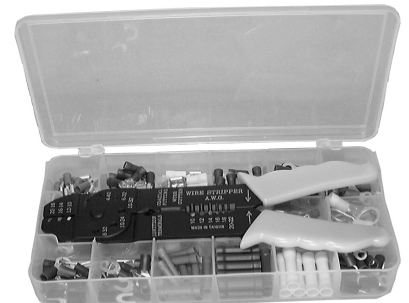

No. 65-1875