
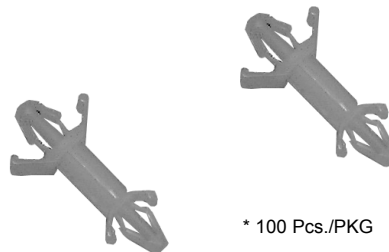


# CABLE TIES & MOUNTS

## CIRCUIT BOARD SUPPORT

Part #	A
13-316	3/16"
13-180	1/8"
13-380	3/8"
13-120	1/2"
13-580	5/8"
13-340	3/4"
13-780	7/8"
13-110	1"
13-118	1-1/8"
13-138	1-3/8"

Material: UL approved NYLON 6/6, 94V-2  
P.C.B. support can be removed easily for replacement

 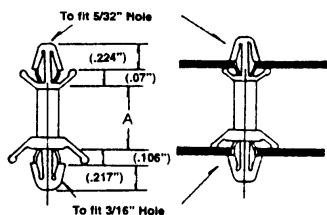


\* 100 Pcs./PKG

## CABLE TIE

- Material: Philmore standard cable ties made from U.L. approved nylon 6/6. Normal service temperature range: - 40° C to 85° C. Flammability rating: UL 94V-2
- Weather resistant nylon: Carbonate "A" was added for greater resistance to ultra violet light in outdoor application.
- Heat stabilized nylon: Service temperature 135° C
- Specification: Made to comply with mil-spec drawing No. MS-3367 tensile strength meets or exceeds MIL-S-23190D Standards.

Part No.		Length	Width	Max. Bundle Dia	Min. Tensile Strength
Natural	Black UV Resistant				
13-2004	13-3004	4"	.10"	31/32"	18 lbs.
13-2006	13-3006	6"	.14"	1-1/2"	50 lbs.
13-2008	13-3008	8"	.12"	2-5/32"	40 lbs.
13-2011	13-3011	11"	.18"	3-5/32"	50 lbs.
13-2145	13-3145	14-1/2"	.18"	4"	50 lbs.



\*100 Pcs./Pkg.



- Philmore cable ties are also available in 1000 pcs. Pack. Please add suffix letter "M" to the part number. Example: No. 13-2004 - 100 pcs/pkg. No. 13-2004M - 1000 pcs/pkg.

## P.C.B Track

- Material: UL approved NYLON 6/6, 94V-2
- Mounted with No. 4 flat-head screws.

Part No.	A	B	C	D	E	F	G
13-350	3.50"	3.03"	.075"	.177"	.374"	.059"	.118"
13-351*	3.50"	3.03"	.075"	.177"	.374"	.059"	.118"
13-468	4.68"	4.72"	.075"	.177"	.374"	.059"	.118"
13-550	5.50"	4.53"	.075"	.177"	.374"	.059"	.118"
13-630	6.30"	5.30"	.075"	.177"	.374"	.059"	.118"

\*No. 13-351 with snap in design.

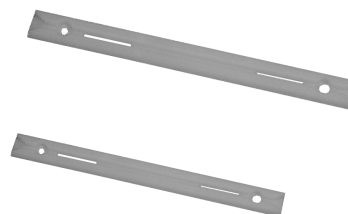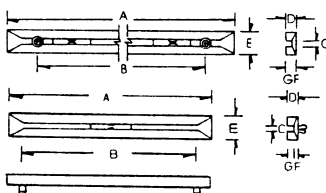


\*25 Pcs./Pkg.

## Snap Rivet

- Material: UL approved NYLON 6/6, 94V-2
- Rivet post pressure expands legs for fast and permanent fastening.

Part No.	A	B	C
13-355	.12"	.22"	.10"-.16"
13-365	.12"	.26"	.14"-.20"

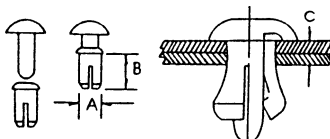


\*100 Pcs./Pkg.

## Push Mount Tie

- Material: UL approved NYLON 6/6, 94V-2
- Drill hole in panel to affix tie mount. Insert tie into mount for bundling cables.

Part No.		T	Hole Size
25/pkg.	100/pkg.		
13-425	13-400	.15"	.15"
13-825	13-800	.30"	.30"

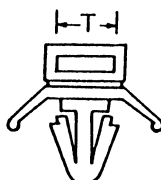

\*100 Pcs./Pkg.