



platt
Professional cases for business and industry

Platt Luggage, Inc.

“Quality That Lasts!” Since 1921

Platt Luggage, Inc. * 4051 W. 51st Street * Chicago, IL 60632 * www.plattcases.com * 1.800.222.1555

Contents

| | |
|---|-------|
| FOAM-FILLED CASES | |
| HEAVY-DUTY ATA CASES with recessed hardware and wheels and telescoping handle | 3 |
| HEAVY-DUTY ATA CASES with recessed hardware | 3 |
| HEAVY-DUTY POLYETHYLENE CASES with wheels and telescoping handle | 3 |
| HEAVY-DUTY POLYETHYLENE CASES | 3 |
| BLOW-MOLDED CASES | 4 |
| LIGHT-DUTY ABS CASES | 4 |
| MEDIUM-DUTY ABS CASES | 4 |
| PARALLEL RIB CASES | 4 |
| ATA SHIPPING CASES | 5 |
| WATERTIGHT CASES | |
| PELICAN® CASES | 6 |
| PELICAN® FLASHLIGHTS | 6 |
| MOLDED TOOL CASES | |
| SUPER-SIZE™ TOOL CASES with wheels and telescoping handle | 7 |
| SUPER-SIZE™ TOOL CASES | 7 |
| MILITARY TYPE SUPER-SIZE™ TOOL CASES | 7 |
| ROTATIONAL MOLDED TOOL CASE | 7 |
| TRANSPORTER TOOL CASE with wheels and telescoping handle | 7 |
| POLYETHYLENE TOOL CASES (ultimate) | 8 |
| POLYETHYLENE TOOL CASES (deluxe, premium, standard) | 8 |
| POLYPROPYLENE TOOL CASES (deluxe, economy) | 9 |
| ATA TOOL CASES | |
| GUARDSMAN ATA TOOL CASES | 9 |
| GUARDSMAN ATA TOOL CASES with wheels and telescoping handle | 9 |
| ALUMINUM GUARDSMAN ATA TOOL CASES | 9 |
| TOOL PALLETS | |
| INJECTION MOLDED TOOL PALLETS | 10 |
| SEWN AND RIVETED TOOL PALLETS | 10 |
| WINGED TOOL PALLET/BOOK TOOL PALLET | 11 |
| SEWN TOOL CASES | |
| ZIPPER TOOL / TECHNICIAN CASES | 11-12 |
| TELECOM CASES | 13 |
| MECHANIC'S TOOL BAGS | 14 |
| TOOL ROLLS | 14 |
| CLC TOOL BAGS AND ORGANIZERS | 14 |
| BUFFALO CASE COMPANY | |
| SEWN TOOL CASES | 15 |
| MOLDED TOOL CASE | 15 |
| COMPUTER & ATTACHÉ CASES | |
| COMPUTER/AV CASES | 16 |
| ALUMINUM ATTACHÉ | 16 |
| DELUXE SOFT-MOLDED ATTACHÉ | 16 |
| HIGH-IMPACT POLYPROPYLENE ATTACHÉ | 16 |
| SPECIALTY/MISC | |
| CATALOG CASES | 17 |
| FABRICATED SOFT-SIDED STATIC-FREE PCB CASES | 17 |
| AEROSOL CAN SAMPLE CASE | 17 |
| SLIDE CAROUSEL CASE | 17 |
| INFINITE DIVIDER BOXES | 17 |
| CARTS | 18 |
| CASE REPLACEMENT HARDWARE | 18 |

Our Mission

Our mission is to lead our industry by providing quality products, superior customer service, technical innovation and on-time delivery. We realize that we cannot exist without the support of our customers, employees, and suppliers and we will treat them all with integrity and professionalism.

What To Know

Ordering with Platt is easy. Please specify Platt part number, color and quantity. For molded cases and sewn tool cases specify top and bottom pallet option. Use chart below as a reference or call our customer service department at 1-800-99-PLATT (997-5288) or visit our webpage at www.plattcases.com.

To Order Specify:

1. Platt#
2. Color
3. Top pallet (select from page 10-11)
4. Bottom pallet (select from page 10-11)

REFERENCE INFORMATION

| | |
|---------------|--|
| Platt # | Platt part number |
| O.D. | Outside dimension |
| I.D. | Inside dimension |
| Color | Available color options |
| Body Depth | Interior depth of bottom half of case |
| Ship wt. | Shipping weight, including packaging |
| Option | Additional info to consider. ie. turnbutton on pallets. |
| Valance | Aluminum molding around edges of lid and base to ensure snug closure. Also referred to as a rim or frame. |
| Turnbutton | Knob fastener to hold top pallet in case lid. |
| ABS | ABS Thermoplastic. A tough high-performance material specified for years in many consumer and commercial applications because of its cost/performance balance, strength and durability. |
| HMW | (High Molecular Weight) Polyethylene. A superior performing, yet lightweight material providing the best in high-impact strength, durability, environmental stress-crack resistance, economy and superior chemical resistance. |
| Polypropylene | A tough high-performance material with superior chemical resistance. |

Reference Material

| | |
|---------|---------------------------------|
| BM99-1 | Blow Molded Case Product Sheet |
| ENG03-1 | Engineering Custom Case Catalog |
| MST05-1 | Mini Product Catalog |

Limited Warranty

All Platt cases are under warranty against manufacturing defects, under normal use, for a period of one year from the date of purchase. Any defect, which is a result of faulty workmanship or materials will be repaired and returned free of charge. When, in our judgement, damage is caused by misuse or the guarantee period has expired, we will repair, if practical, for a reasonable charge. If damage is caused by common carrier abuse or airline mishandling, claim must be made with that carrier. Determination of suitability of product for uses and applications contemplated by Buyer shall be at the sole responsibility of Buyer.

Disclosure

Platt continues product improvements. We reserve the right to deviate from product descriptions as shown in catalog.

FOAM-FILLED CASES

NEW SIZES

Heavy-Duty ATA Cases



Heavy-Duty ATA Cases with Wheels and Telescoping Handle

Heavy-duty polyethylene ATA cases with recessed hardware. The exterior shell is tough impact-resistant HMW polyethylene. Foam-filled, heavy-duty aluminum rim and gasket, locking provision, full-length piano hinge and spring-loaded handle.

This durable, rugged transportation case series includes wheels and telescoping handle for convenient transportation.

*Gray in color +This case also comes in laptop version (see page 16)

| Platt# | Inside Dim. | | | Body Depth |
|---------------------|----------------------------------|----------------------------------|-----|---------------------------------|
| | L | W | D | |
| 201409AH | 19 ⁵ / ₈ " | 13 ³ / ₄ " | 9" | 5" |
| 202014AH | 20" | 20" | 14" | 10" |
| 221609AH | 21 ¹ / ₂ " | 15 ¹ / ₂ " | 9" | 5" |
| 222214AH | 22" | 22" | 14" | 10" |
| 231510AHG* | 23" | 15" | 10" | 5" |
| 231511AH | 23 ³ / ₈ " | 15 ³ / ₈ " | 11" | 6" |
| 241811AH | 23 ³ / ₄ " | 17 ³ / ₄ " | 11" | 5 ¹ / ₂ " |
| NEW 242416AH | 24" | 24" | 16" | 12" |
| NEW 242420AH | 24" | 24" | 20" | 15" |
| 252310AHG* | 25" | 23" | 10" | 5" |
| 252316AH | 25 ¹ / ₄ " | 23 ³ / ₈ " | 16" | 9" |
| 261613AH | 26" | 16" | 13" | 10" |
| 261617AH* | 26" | 16" | 17" | 12" |
| 282011AH | 27 ¹ / ₂ " | 19 ¹ / ₂ " | 11" | 5 ¹ / ₂ " |
| NEW 301816AH | 30" | 18" | 16" | 12" |
| NEW 301820AH | 30" | 18" | 20" | 15" |
| 322211AH | 31 ³ / ₄ " | 22" | 11" | 5 ¹ / ₂ " |
| NEW 460909AH | 46" | 9" | 9" | 4 ¹ / ₂ " |
| NEW 531111AH | 53" | 11" | 11" | 5 ¹ / ₂ " |



Heavy-Duty ATA Cases with Recessed Hardware

Heavy-duty polyethylene ATA cases with recessed hardware. The exterior shell is tough impact-resistant HMW polyethylene. Foam-filled, heavy-duty aluminum rim and gasket, locking provision, full-length piano hinge and spring-loaded handle.

| Platt# | Inside Dim. | | | Body Depth |
|---------|----------------------------------|----------------------------------|-----|----------------------------------|
| | L | W | D | |
| 181309A | 18 ¹ / ₂ " | 12 ¹ / ₂ " | 9" | 5" |
| 201409A | 19 ⁵ / ₈ " | 13 ³ / ₄ " | 9" | 5" |
| 202014A | 20" | 20" | 14" | 10" |
| 202020A | 20" | 20" | 20" | 14" |
| 221609A | 21 ¹ / ₂ " | 15 ¹ / ₂ " | 9" | 5" |
| 222214A | 22" | 22" | 14" | 10" |
| 222222A | 22" | 22" | 22" | 15 ¹ / ₂ " |
| 241811A | 23 ³ / ₄ " | 17 ³ / ₄ " | 11" | 5 ¹ / ₂ " |
| 261611A | 26" | 16" | 11" | 7 ¹ / ₂ " |
| 282011A | 27 ¹ / ₂ " | 19 ¹ / ₂ " | 11" | 5 ¹ / ₂ " |
| 322211A | 31 ³ / ₄ " | 22" | 11" | 5 ¹ / ₂ " |

Heavy-Duty Polyethylene Cases



Heavy-Duty Polyethylene Cases with Wheels and Telescoping Handle

Tough impact-resistant HMW polyethylene. Foam-filled, heavy-duty aluminum valance with black trim and gasket, full-length piano hinge, cast chrome key locks and golf grip handle.

This series includes wheels and telescoping handle for convenient transportation.

| Platt# | Inside Dim. | | | Body Depth |
|---------|----------------------------------|----------------------------------|-----|---------------------------------|
| | L | W | D | |
| 181509H | 17 ¹ / ₂ " | 14 ⁵ / ₈ " | 9" | 5" |
| 201407H | 19 ⁵ / ₈ " | 13 ³ / ₄ " | 7" | 4" |
| 221609H | 21 ¹ / ₂ " | 15 ¹ / ₂ " | 9" | 5" |
| 241811H | 23 ³ / ₄ " | 17 ³ / ₄ " | 11" | 5 ¹ / ₂ " |
| 282011H | 27 ¹ / ₂ " | 19 ¹ / ₂ " | 11" | 5 ¹ / ₂ " |



NEW SIZES

Heavy-Duty Polyethylene Cases

The exterior shell is tough impact-resistant HMW polyethylene. Foam-filled, heavy-duty aluminum rim with black trim and gasket, cast chrome key locks, full-length piano hinge, and deluxe golf grip handle.

| Platt# | Inside Dim. | | | Body Depth |
|-------------------|----------------------------------|----------------------------------|-----|---------------------------------|
| | L | W | D | |
| 181307 | 18 ¹ / ₂ " | 12 ¹ / ₂ " | 7" | 4" |
| 201407 | 19 ⁵ / ₈ " | 13 ³ / ₄ " | 7" | 4" |
| 221609 | 21 ¹ / ₂ " | 15 ¹ / ₂ " | 9" | 5" |
| 241809 | 23 ³ / ₄ " | 17 ³ / ₄ " | 9" | 5" |
| 282007 | 27 ¹ / ₂ " | 19 ¹ / ₂ " | 7" | 4" |
| 282009 | 27 ¹ / ₂ " | 19 ¹ / ₂ " | 9" | 5" |
| 322209 | 31 ³ / ₄ " | 22" | 9" | 5" |
| NEW 460909 | 46" | 6" | 9" | 4 ¹ / ₂ " |
| NEW 531111 | 53" | 11" | 11" | 5 ¹ / ₂ " |

Custom Foam-Filled Cases



Custom Foam-Filled Cases

Custom foam can be cut to fit almost any application and is perfect for protecting delicate equipment.

"Your Small Quantity Specialist"

FOAM-FILLED CASES

Blow Molded Cases



Blow Molded Cases

Meet Platt's low cost solution to "Make-Your-Own" case needs.

These cases are foam-filled and manufactured from prime, high-density polyethylene, with double wall construction. The textured exteriors resist dents, cracking and scuffs. The shells are unaffected by extreme temperatures.

The hardware features mechanical latches that are field replaceable and a mechanical hinge system that is made to last.

All cases meet U.S. 94B Specifications as an electrical insulator and are impervious to chemical attack.

| Platt# | Inside Dim. | | | Outside Dim. | | |
|--------|------------------------------------|------------------------------------|-----------------------------------|-----------------------------------|----------------------------------|-----------------------------------|
| | L | W | D | L | W | D |
| 102 | 5 ⁵ / ₈ " | 3 ⁵ / ₈ " | 1 ³ / ₈ " | 6 ¹ / ₂ " | 4 ¹ / ₂ " | 1 ¹¹ / ₁₆ " |
| 103 | 5 ⁵ / ₈ " | 3 ³ / ₈ " | 1 ⁷ / ₈ " | 6 ¹ / ₂ " | 4 ¹ / ₂ " | 2 ¹ / ₈ " |
| 104 | 7 ¹ / ₈ " | 4" | 1 ⁷ / ₁₆ " | 8" | 5" | 1 ³ / ₄ " |
| 105 | 7 ¹ / ₈ " | 4" | 1 ¹⁵ / ₁₆ " | 8" | 5" | 2 ¹ / ₈ " |
| 106 | 7 ¹ / ₂ " | 5" | 1 ¹¹ / ₁₆ " | 8 ¹ / ₂ " | 6" | 2" |
| 107 | 7 ¹ / ₂ " | 5" | 2 ³ / ₁₆ " | 8 ¹ / ₂ " | 6" | 2 ¹ / ₂ " |
| 108 | 7 ¹ / ₂ " | 5" | 2 ¹¹ / ₁₆ " | 8 ¹ / ₂ " | 6" | 3" |
| 202 | 8 ¹ / ₂ " | 5 ¹ / ₂ " | 1 ¹¹ / ₁₆ " | 9 ¹ / ₂ " | 6 ¹ / ₂ " | 2" |
| 203 | 8 ¹ / ₂ " | 5 ¹ / ₂ " | 2 ¹¹ / ₁₆ " | 9 ¹ / ₂ " | 6 ¹ / ₂ " | 2 ¹ / ₂ " |
| 204 | 8 ¹ / ₂ " | 5 ¹ / ₂ " | 2 ¹¹ / ₁₆ " | 9 ¹ / ₂ " | 6 ¹ / ₂ " | 3" |
| 205 | 8 ¹ / ₂ " | 5 ¹ / ₂ " | 3 ³ / ₁₆ " | 9 ¹ / ₂ " | 6 ¹ / ₂ " | 3 ¹ / ₂ " |
| 206 | 9 ¹ / ₂ " | 6" | 1 ¹⁵ / ₁₆ " | 10 ¹ / ₂ " | 7" | 2 ¹ / ₁₆ " |
| 207 | 9 ¹ / ₂ " | 6" | 2 ¹¹ / ₁₆ " | 10 ¹ / ₂ " | 7" | 3" |
| 208 | 9 ¹ / ₂ " | 6" | 3 ⁷ / ₁₆ " | 9 ¹ / ₂ " | 7" | 3 ³ / ₄ " |
| 302 | 10 ³ / ₁₆ " | 6 ¹ / ₂ " | 1 ¹⁵ / ₁₆ " | 11 ³ / ₁₆ " | 7 ¹ / ₂ " | 2 ¹ / ₄ " |
| 303 | 10 ³ / ₁₆ " | 6 ¹ / ₂ " | 2 ¹¹ / ₁₆ " | 11 ³ / ₁₆ " | 7 ¹ / ₂ " | 3" |
| 304 | 10 ³ / ₁₆ " | 6 ¹ / ₂ " | 3 ⁷ / ₁₆ " | 11 ³ / ₁₆ " | 7 ¹ / ₂ " | 3 ³ / ₄ " |
| 305 | 11" | 7" | 1 ¹⁵ / ₁₆ " | 12" | 8" | 2 ¹ / ₄ " |
| 306 | 11" | 7" | 2 ¹¹ / ₁₆ " | 12" | 8" | 3" |
| 307 | 11" | 7" | 3 ⁷ / ₁₆ " | 12" | 8" | 3 ³ / ₄ " |
| 308 | 12 ³ / ₈ " | 6 ⁷ / ₈ " | 2 ⁷ / ₈ " | 13 ¹ / ₂ " | 8" | 3 ¹ / ₄ " |
| 309 | 12 ³ / ₈ " | 6 ⁷ / ₈ " | 4 ¹ / ₁₆ " | 13 ¹ / ₂ " | 8" | 4 ³ / ₈ " |
| 310 | 12 ³ / ₈ " | 6 ⁷ / ₈ " | 5 ¹ / ₁₆ " | 13 ¹ / ₂ " | 8" | 5 ¹ / ₂ " |
| 402 | 12 ³ / ₈ " | 7 ⁷ / ₈ " | 2 ⁷ / ₈ " | 13 ¹ / ₂ " | 9" | 3 ¹ / ₄ " |
| 403 | 12 ³ / ₈ " | 7 ⁷ / ₈ " | 4" | 13 ¹ / ₂ " | 9" | 4 ³ / ₈ " |
| 404 | 12 ³ / ₈ " | 7 ⁷ / ₈ " | 5 ¹ / ₈ " | 13 ¹ / ₂ " | 9" | 5 ¹ / ₂ " |
| 405 | 12 ³ / ₈ " | 8 ⁷ / ₈ " | 2 ⁷ / ₈ " | 13 ¹ / ₂ " | 10" | 3 ¹ / ₄ " |
| 406 | 12 ³ / ₈ " | 8 ⁷ / ₈ " | 4" | 13 ¹ / ₂ " | 10" | 4 ³ / ₈ " |
| 407 | 12 ³ / ₈ " | 8 ⁷ / ₈ " | 5 ¹ / ₈ " | 13 ¹ / ₂ " | 10" | 5 ¹ / ₂ " |
| 503 | 13 ³ / ₈ " | 8 ⁷ / ₈ " | 2 ⁷ / ₈ " | 15" | 10" | 3 ¹ / ₄ " |
| 504 | 13 ³ / ₈ " | 8 ⁷ / ₈ " | 4" | 15" | 10" | 4 ³ / ₈ " |
| 505 | 13 ³ / ₈ " | 8 ⁷ / ₈ " | 5 ¹ / ₈ " | 15" | 10" | 5 ¹ / ₂ " |
| 506 | 13 ³ / ₈ " | 9 ⁷ / ₈ " | 2 ⁷ / ₈ " | 15" | 11" | 3 ¹ / ₄ " |
| 507 | 13 ³ / ₈ " | 9 ⁷ / ₈ " | 4" | 15" | 11" | 4 ³ / ₈ " |
| 508 | 13 ³ / ₈ " | 9 ⁷ / ₈ " | 5 ¹ / ₈ " | 15" | 11" | 5 ¹ / ₂ " |
| 604 | 14 ⁷ / ₈ " | 10 ³ / ₈ " | 2 ⁷ / ₈ " | 16" | 11 ¹ / ₂ " | 3 ¹ / ₄ " |
| 605 | 14 ⁷ / ₈ " | 10 ³ / ₈ " | 4" | 16" | 11 ¹ / ₂ " | 4 ³ / ₈ " |
| 606 | 14 ⁷ / ₈ " | 10 ³ / ₈ " | 5 ¹ / ₈ " | 16" | 11 ¹ / ₂ " | 5 ¹ / ₂ " |
| 607 | 15 ⁷ / ₈ " | 10 ⁷ / ₈ " | 2 ⁷ / ₈ " | 17" | 12" | 3 ¹ / ₄ " |
| 608 | 15 ⁷ / ₈ " | 10 ⁷ / ₈ " | 4" | 17" | 12" | 4 ³ / ₈ " |
| 609 | 15 ⁷ / ₈ " | 10 ⁷ / ₈ " | 5 ¹ / ₈ " | 17" | 12" | 5 ¹ / ₂ " |
| 610 | 16 ⁷ / ₈ " | 11 ¹¹ / ₁₆ " | 3 ⁷ / ₈ " | 18" | 13" | 4 ¹ / ₄ " |
| 611 | 16 ⁷ / ₈ " | 11 ¹¹ / ₁₆ " | 5" | 18" | 13" | 5 ³ / ₈ " |
| 612 | 16 ⁷ / ₈ " | 11 ¹¹ / ₁₆ " | 6 ¹ / ₈ " | 18" | 13" | 6 ¹ / ₂ " |
| 705 | 17 ⁷ / ₈ " | 12 ¹¹ / ₁₆ " | 4 ³ / ₈ " | 19" | 14" | 4 ³ / ₄ " |
| 706 | 17 ⁷ / ₈ " | 12 ³ / ₄ " | 5 ³ / ₄ " | 19" | 14" | 6 ¹ / ₄ " |
| 707 | 17 ⁷ / ₈ " | 12 ³ / ₄ " | 7 ¹ / ₈ " | 19" | 14" | 7 ¹ / ₂ " |
| 802* | 21 ⁵ / ₁₆ " | 14 ⁵ / ₁₆ " | 6 ⁵ / ₈ " | 23" | 16" | 7" |
| 803* | 21 ⁵ / ₁₆ " | 14 ⁵ / ₁₆ " | 9 ⁵ / ₈ " | 23" | 16" | 10" |
| 902* | 25 ¹³ / ₁₆ " | 14 ⁵ / ₁₆ " | 6 ⁵ / ₈ " | 27 ¹ / ₂ " | 16" | 7" |
| 903* | 25 ¹³ / ₁₆ " | 14 ⁵ / ₁₆ " | 9 ⁵ / ₈ " | 27 ¹ / ₂ " | 16" | 10" |

* Molded-in handle reduces "W" dimension usable space.
Please contact Platt Engineering for info

Light-Duty ABS Cases



Light-Duty ABS Cases

This series has been a mainstay of Platt's rugged case line for over 25 years. Light-duty, black, scuff resistant molded ABS thermoplastic forms the tough shell of these cases. Foam-filled, extruded aluminum rim, drawbolt key locks and strong molded handle.

* 1425 has a medium-duty valance

| Platt# | Inside Dim. | | | Body Depth |
|--------|-------------|-----|----|------------|
| | L | W | D | |
| 1410 | 10" | 7" | 5" | 3" |
| 1412 | 12" | 8" | 5" | 3" |
| 1414 | 12" | 11" | 5" | 3" |
| 1416 | 16" | 12" | 5" | 3" |
| 1426 | 16" | 12" | 7" | 4" |
| 1705 | 17" | 11" | 5" | 3" |
| 1419 | 18" | 13" | 5" | 3" |
| 1425* | 18" | 13" | 7" | 4" |

Medium-Duty ABS Cases



Medium-Duty ABS Cases

Modern look of heavy-duty grained ABS with extruded aluminum frame, these foam-filled cases have a deluxe golf grip handle, cast chrome key locks and piano hinge.

* 2005 has a light-duty valance.

| Platt# | Inside Dim. | | | Body Depth |
|--------|-------------|-----|----|------------|
| | L | W | D | |
| 2005* | 20" | 14" | 5" | 3" |
| 2007 | 20" | 14" | 7" | 4" |
| 2207 | 22" | 16" | 7" | 4" |
| 2407 | 24" | 18" | 7" | 4" |
| 2807 | 28" | 20" | 7" | 4" |

Parallel Rib Cases



Heavy-Duty Polyethylene Cases With Stylish Parallel Rib Pattern Without Foam

The exterior shell is tough impact-resistant HMW polyethylene. Heavy-duty aluminum rim with gasket, black trim, molded handle, full-length piano hinge and cast chrome key locks.

 
ALL PARALLEL RIB CASES FURNISHED WITHOUT FOAM.

| Platt# | Inside Dim. | | | Body Depth |
|----------|----------------------------------|----------------------------------|---------------------------------|---------------------------------|
| | L | W | D | |
| 141106PR | 14 ¹ / ₈ " | 10 ¹ / ₂ " | 6" | 3 ¹ / ₂ " |
| 171206PR | 17 ¹ / ₄ " | 12 ¹ / ₂ " | 6" | 3 ¹ / ₂ " |
| 201675PR | 19 ³ / ₄ " | 15 ³ / ₄ " | 7 ¹ / ₂ " | 4 ¹ / ₂ " |
| 221006PR | 22" | 10" | 6" | 3 ¹ / ₂ " |
| 241609PR | 23 ³ / ₄ " | 15 ³ / ₄ " | 9" | 4 ¹ / ₂ " |
| 251709PR | 25" | 16 ³ / ₄ " | 9" | 4 ³ / ₄ " |

Guardsman ATA 300 Cases



1116CPU case has foam cavity 6-1/2"x16"x17" with keyboard cavity 2"x7"x19".
1114M Monitor case is lined with 1" high density foam. Included in case are 4 pieces of 1" and 4 pieces of 1/2" Polyethylene Foam. Case will fit monitors 19"x19"x19" or smaller.



1016HW & 1018HW come with four ball bearing wheels and telescoping handle.



1118LAP holds 5 laptops and contains 2 cavities for projector, cords and cables.

Platt Guardsman cases can be made to hold any quantity of laptops. Contact Platt engineering department for assistance.

Guardsman™ ATA 300 Shipping Cases

Heavy-duty black HMW polyethylene material with unique continuous industrial frame based on Platt's patented Guardsman™ design and construction. All hardware is recessed for wearability and shipping purposes. Cases come with locking provision, spring loaded handle, full-length piano hinge and security type bolts. All top and body interiors of cases are lined with high density foam.

DIMENSIONS SHOWN ARE INSIDE THE FOAM LINING.

| Platt# | Inside Dim. | | | Body Depth |
|---------|-------------|---------|---------|------------|
| | L | W | D | |
| 1008 | 12" | 8 1/2" | 14" | 11" |
| 1012 | 16 1/2" | 10" | 16" | 12 1/2" |
| 1013 | 17 1/2" | 11" | 8" | 6" |
| 1016 | 20 1/2" | 14 1/2" | 14" | 10 1/2" |
| 1016HW | 20 1/2" | 14 1/2" | 14" | 10 1/2" |
| 1018 | 25 1/2" | 17 1/2" | 17 1/2" | 14 1/2" |
| 1018HW | 25 1/2" | 17 1/2" | 17 1/2" | 14 1/2" |
| 1114M | 19" | 19" | 19" | 16" |
| 1116CPU | 20" | 12 1/2" | 24" | 20" |
| 1118LAP | 25 1/4" | 15 1/4" | 13" | 9 3/4" |

Ordering: Cases all available with lining only (add L to end of P/N) or foam filled with layers of foam (add F to end of P/N).
(except 1114M, 1116CPU and 1118LAP)

*1112 This case has been discontinued as a stock item. It is still available as a special.

All cases also available as a Jetalum™ all aluminum construction.
(See page 9 for photo)

NEW

TSA Accepted Locks

- Airport Luggage & Security
- TSA Accepted
- TSA Recognized
- Opened Lock Window
- Patented Security Window
- Prevents Surreptitious Entry
- Red Window - Lock Opened
- Green Window - Lock Not Opened
- 1,000 Re-settable Combinations
- Regular and Heavy Duty Shackles
- Different styles and colors available



TSA6430PSB
NEW



TSA7400PW
NEW



TSA7470PFY
NEW

Custom ATA Guardsman Cases

Multi-Laptop Case



Piggyback Case



Multi-Purpose Shipping Case



Patented Guardsman™ Design & Construction

Platt's Guardsman cases are unique and easily recognizable. Construction features HMW polyethylene thermoplastic sheets bent to size to form strong but lightweight shipping cases ideal for computer, video, audio, medical, electronic instrumentation and industrial equipment. All cases use our UNIQUE CONTINUOUS FRAME CONSTRUCTION for maximum strength and durability. Cases include full-length piano hinge, recessed spring-loaded handle and latches.

Foam interiors can be made to your individual requirements using polyurethane ether or ester foam, polyethylene foam, anti-static, conductive or static dissipative foam.

Options include different colors, stacking studs, combination lock, fixed or removable casters, wheels and telescoping handle, key lock, padlockable latches and conductive polyethylene for protection against ESD discharge damage.

All orders (EVEN ONE CASE) are quoted by Platt depending on size, foam interiors, other options and quantity. Call your local distributor.

Color / Material Options

Platt's Guardsman cases are available in black, safety yellow, safety orange, gray, blue, green, and white. Other special colors are available with minimum order requirements. Also available as a Jetalum™ all aluminum construction. Contact factory for availability.

Telescoping Handle ATA

Platt's Guardsman cases are available with built-in wheels and telescoping handle. Not only are the Guardsman cases able to take the rigors of shipping, but now, when you get the case, it is easy to move. Convenient for display cases or product cases.

"Your Small Quantity Specialist"

Pelican Watertight Cases



New & Improved Latches.

- 1120 Guard Box®
- 1150 Case™
- 1200 Case™
- 1300 Case™
- 1400 Case™
- 1450 Case™
- 1470 Case™
- 1470 Case™
- 1490 Case™
- 1500 Case™
- 1520 Case™
- 1550 Case™
- 1600 Case™
- 1620 Case™
- 1650 Case™
- 1700 Travel VaultIII®
- 1750 Travel Vault®



| Platt# | Inside Dim. | | | Outside Dim. | | | Ship Weight |
|-----------------|------------------------------------|------------------------------------|-----------------------------------|------------------------------------|------------------------------------|------------------------------------|-------------|
| | L | W | D | L | W | D | |
| 0350 | 20" | 20" | 18 ¹ / ₄ " | 22 ¹ / ₂ " | 22 ⁷ / ₁₆ " | 21 ¹ / ₄ " | 26 lbs. |
| 0370 | 24 ¹ / ₄ " | 24" | 23" | 25 ¹ / ₄ " | 26 ¹ / ₂ " | 26 ¹ / ₂ " | 30 lbs. |
| 1010 | 4 ⁵ / ₁₆ " | 2 ¹³ / ₁₆ " | 1 ⁵ / ₈ " | 5 ⁷ / ₁₆ " | 4 ¹ / ₁₆ " | 2 ¹ / ₈ " | 3.2 lbs. |
| 1020 | 5 ¹ / ₄ " | 3 ¹ / ₂ " | 1 ³ / ₈ " | 6 ³ / ₈ " | 4 ³ / ₄ " | 2 ¹ / ₈ " | 4 lbs. |
| 1030 | 6 ³ / ₈ " | 2 ⁵ / ₈ " | 2" | 7 ¹ / ₂ " | 3 ⁷ / ₈ " | 2 ⁷ / ₁₆ " | 4.24 lbs. |
| 1040 | 6 ⁷ / ₁₆ " | 3 ¹³ / ₁₆ " | 1 ¹¹ / ₁₆ " | 7 ¹ / ₂ " | 5 ¹ / ₁₆ " | 2 ¹ / ₈ " | 4.85 lbs. |
| 1050 | 6 ⁷ / ₁₆ " | 3 ¹³ / ₁₆ " | 2 ¹¹ / ₁₆ " | 7 ¹ / ₂ " | 5 ¹ / ₁₆ " | 3 ¹ / ₈ " | 6.4 lbs. |
| 1060 | 8 ⁵ / ₁₆ " | 4 ⁵ / ₁₆ " | 2 ³ / ₁₆ " | 9 ³ / ₈ " | 5 ⁹ / ₁₆ " | 2 ⁵ / ₈ " | 6.88 lbs. |
| 1120WF | 7 ³ / ₈ " | 4 ⁷ / ₈ " | 3 ¹ / ₁₆ " | 8 ¹ / ₄ " | 6 ⁷ / ₁₆ " | 3 ⁹ / ₁₆ " | 11.2 lbs. |
| 1150WF | 8 ³ / ₈ " | 5 ⁷ / ₈ " | 3 ⁹ / ₁₆ " | 9 ¹ / ₄ " | 7 ⁹ / ₁₆ " | 4 ³ / ₈ " | 2.5 lbs. |
| 1200WF | 9 ³ / ₈ " | 7 ¹ / ₄ " | 4 ¹ / ₁₆ " | 10 ⁵ / ₈ " | 9 ¹¹ / ₁₆ " | 4 ⁷ / ₈ " | 3 lbs. |
| 1300WF | 9 ³ / ₈ " | 7 ¹ / ₄ " | 6 ¹ / ₈ " | 10 ⁵ / ₈ " | 9 ¹¹ / ₁₆ " | 6 ⁷ / ₈ " | 3.5 lbs. |
| 1400WF | 12" | 9 ¹ / ₁₆ " | 5 ³ / ₁₆ " | 13 ³ / ₈ " | 11 ⁵ / ₈ " | 6" | 5.5 lbs. |
| 1420WF | 13" | 5" | 10" | 15" | 8 ¹ / ₂ " | 10 ¹ / ₂ " | 5.5 lbs. |
| 1450WF | 14 ¹³ / ₁₆ " | 10 ³ / ₈ " | 6" | 16" | 13" | 6 ⁷ / ₈ " | 7.5 lbs. |
| 1470WF | 15 ⁵ / ₄ " | 10 ⁹ / ₁₆ " | 3 ³ / ₄ " | 16 ¹¹ / ₁₆ " | 13 ¹ / ₁₆ " | 4 ³ / ₈ " | 7.8 lbs. |
| 1470CC#1 | 15 ³ / ₄ " | 10 ⁹ / ₁₆ " | 3 ³ / ₄ " | 16 ¹¹ / ₁₆ " | 13 ¹ / ₁₆ " | 4 ³ / ₈ " | 6.8 lbs. |
| 1470CC#2 | 15 ³ / ₄ " | 10 ⁹ / ₁₆ " | 3 ³ / ₄ " | 16 ¹¹ / ₁₆ " | 13 ¹ / ₁₆ " | 4 ³ / ₈ " | 6.75 lbs. |
| 1470AC | 15 ³ / ₄ " | 10 ⁹ / ₁₆ " | 3 ³ / ₄ " | 16 ¹¹ / ₁₆ " | 13 ¹ / ₁₆ " | 4 ³ / ₈ " | 6.75 lbs. |
| 1490WF | 17 ⁷ / ₈ " | 11 ¹ / ₂ " | 4 ¹ / ₈ " | 19 ⁷ / ₁₆ " | 13 ¹⁵ / ₁₆ " | 4 ¹¹ / ₁₆ " | 6.5 lbs. |
| 1490CC#1 | 17 ⁷ / ₈ " | 11 ¹ / ₂ " | 4 ¹ / ₂ " | 19 ⁷ / ₁₆ " | 13 ¹⁵ / ₁₆ " | 4 ¹¹ / ₁₆ " | 8.3 lbs. |
| 1490CC#2 | 17 ⁷ / ₈ " | 11 ¹ / ₂ " | 4 ¹ / ₂ " | 19 ⁷ / ₁₆ " | 13 ¹⁵ / ₁₆ " | 4 ¹¹ / ₁₆ " | 8.25 lbs. |
| 1490AC | 17 ⁷ / ₈ " | 11 ¹ / ₂ " | 4 ¹ / ₈ " | 19 ⁷ / ₁₆ " | 13 ¹⁵ / ₁₆ " | 4 ¹¹ / ₁₆ " | 8.25 lbs. |
| 1500WF | 17" | 11 ⁷ / ₁₆ " | 6 ¹ / ₈ " | 18 ¹ / ₂ " | 14 ¹ / ₁₆ " | 6 ⁷ / ₈ " | 8.85 lbs. |
| 1504* | 17" | 11 ⁷ / ₁₆ " | 6 ¹ / ₈ " | 18 ¹ / ₂ " | 14 ¹ / ₁₆ " | 6 ⁷ / ₈ " | 8.85 lbs. |
| 1510 | 20 ³ / ₁₆ " | 11 ³ / ₈ " | 7 ¹ / ₂ " | 22" | 14" | 9" | 13.9 lbs. |
| 1520WF | 17 ⁷ / ₈ " | 12 ³ / ₄ " | 6 ³ / ₄ " | 19 ¹ / ₈ " | 15 ⁷ / ₁₆ " | 7 ⁹ / ₁₆ " | 10.75 lbs. |
| 1524* | 17 ⁷ / ₈ " | 12 ³ / ₄ " | 6 ³ / ₄ " | 19 ¹ / ₈ " | 15 ⁷ / ₁₆ " | 7 ⁹ / ₁₆ " | 10.75 lbs. |
| 1526** | 17 ⁷ / ₈ " | 12 ³ / ₄ " | 6 ³ / ₄ " | 19 ¹ / ₈ " | 15 ⁷ / ₁₆ " | 7 ⁹ / ₁₆ " | 10.75 lbs. |
| 1527+ | 17 ³ / ₄ " | 13 ¹ / ₂ " | 7 ¹ / ₄ " | 19 ¹ / ₈ " | 15 ⁷ / ₁₆ " | 7 ⁹ / ₁₆ " | 10.75 lbs. |
| 1550WF | 18 ³ / ₄ " | 14 ³ / ₈ " | 7 ³ / ₈ " | 20 ³ / ₈ " | 16 ⁷ / ₈ " | 8 ³ / ₈ " | 13.5 lbs. |
| 1600WF | 21 ³ / ₄ " | 16 ¹³ / ₁₆ " | 7 ⁷ / ₈ " | 24 ¹ / ₄ " | 19 ⁷ / ₁₆ " | 8 ¹¹ / ₁₆ " | 16 lbs. |
| 1610WF | 22 ³ / ₁₆ " | 17 ¹ / ₈ " | 10 ⁹ / ₁₆ " | 24 ⁹ / ₁₆ " | 19 ⁵ / ₁₆ " | 11 ¹⁵ / ₁₆ " | 25.5 lbs. |
| 1620WF | 22 ⁷ / ₁₆ " | 17" | 12 ⁹ / ₁₆ " | 24 ¹³ / ₁₆ " | 19 ³ / ₈ " | 13 ⁷ / ₈ " | 27 lbs. |
| 1650WF | 29" | 17 ⁷ / ₈ " | 10 ¹ / ₂ " | 32 ³ / ₄ " | 20 ¹ / ₂ " | 11 ⁵ / ₁₆ " | 30 lbs. |
| 1660WF | 29 ¹ / ₈ " | 20 ¹¹ / ₁₆ " | 17 ⁵ / ₈ " | 31 ¹ / ₂ " | 22 ⁷ / ₈ " | 18 ⁷ / ₈ " | 49 lbs. |
| 1700WF | 35 ⁵ / ₄ " | 13 ¹³ / ₁₆ " | 5 ¹ / ₄ " | 31 ¹ / ₈ " | 17 ¹³ / ₁₆ " | 6 ¹ / ₈ " | 19 lbs. |
| 1720WF | 42" | 13 ¹ / ₂ " | 5 ¹ / ₄ " | 44 ³ / ₈ " | 16" | 6 ¹ / ₈ " | 21.15 lbs. |
| 1750WF | 50 ¹ / ₂ " | 13 ⁷ / ₁₆ " | 5 ¹ / ₄ " | 53" | 17 ⁷ / ₁₆ " | 6 ¹ / ₁₆ " | 25.65 lbs. |

Pelican Protector® Watertight Equipment Cases

Watertight and airtight to 30 feet for the ultimate in protection. Constructed of light-weight space-age structural resin with a neoprene O-ring seal and exclusive purge valve. Supplied complete with pre-scored pick-n-pluck foam or padded dividers (no cutting required). Also includes locking flanges, massive multiple latches for absolute security and a comfortable molded fold-down handle. Custom colors and foam inserts fabricated on special order.

#1700 and #1750 supplied with regular foam. Pick-n-pluck is not available.

*Case With Padded Dividers **Case With Travel Bag +Travel Bag Only

Pelican Flashlights

PELICAN® FLASHLIGHTS

Platt carries a complete line of Pelican® Flashlights. Please call Platt Customer Service at 1-800-299-PLATT (997-5288) for more information.



1900C



2400C

PELICAN® 100% GUARANTEE

Unconditional lifetime guarantee of excellence by Pelican® Products, Inc. Warranty and additional information available through your local dealer or call 1-800-99-PLATT (997-5288) or visit our webpage www.plattcases.com.

Pelican Tool Case



| Platt# | Inside Dim. | | |
|-----------------|----------------------------------|----------------------------------|---------------------------------|
| | L | W | D |
| 1520T-CB | 17 ⁷ / ₈ " | 12 ³ / ₄ " | 6 ³ / ₄ " |

PELICAN® FEATURES

Pelican protector case is now available as a Platt tool case. This case is constructed of high impact co-polymer resin with a pressure relief valve and padlock loops. Meets MIL-STD 4150 for stacking, drop test and chemical attack.

This case is not watertight.

MOLDED TOOL CASES

Super-Size Cases



369TH-SGSH

Super-Size™ Tool Cases with Wheels and Telescoping Handle

High-tech rugged HMW polyethylene ribbed case in a large size. Black valance with all black hardware, combination lock, recessed latches, full-length piano hinge, stitched vinyl steel-core handle, ball-bearing wheels, accessory pouch and telescoping handle. Comes standard with Platt's SG and SH super-size pallets. Accepts only a super-size pallet.

| Platt# | Inside Dim. | | | Color |
|-------------|-------------|------|----|--------|
| | L | W | D | |
| 369TH-SGSH | 17½" | 14⅝" | 9" | Black |
| 369THG-SGSH | 17½" | 14⅝" | 9" | Gray |
| 369THY-SGSH | 17½" | 14⅝" | 9" | Yellow |

Super-Size Cases



359TG-SGSH 359TY-SGSH

359T-SGSH

Super-Size™ Tool Cases

High-tech rugged HMW polyethylene ribbed case in a large size. Black valance with all black hardware, combination lock, full-length piano hinge, stitched vinyl steel-core handle and cast key locks. Comes standard with Platt's super-size pallets SG and SH. Accepts only a super-size pallet.

| Platt# | Inside Dim. | | | Color |
|------------|-------------|------|----|--------|
| | L | W | D | |
| 357T-SGSH | 17½" | 14⅝" | 7" | Black |
| 359T-SGSH | 17½" | 14⅝" | 9" | Black |
| 359TG-SGSH | 17½" | 14⅝" | 9" | Gray |
| 359TY-SGSH | 17½" | 14⅝" | 9" | Yellow |

Custom Tool Cases



Ask us about our "Molded-In Logo" option!

"Your Small Quantity Specialist"

Military Type Super-Size Cases



349TG-SGSH 349TY-SGSH

349T-SGSH

Military Type Super-Size™ Tool Cases

High-tech rugged HMW Polyethylene ribbed case in a large size with molded in-corner bumpers to protect the valance and hardware. Black valance with all black hardware, combination lock, full-length piano hinge, spring loaded handle and twist draw latches. Comes standard with Platt's super-size pallets SG and SH. Accepts only a super-size pallet.

| Platt# | Inside Dim. | | | Color |
|------------|-------------|------|----|--------|
| | L | W | D | |
| 349T-SGSH | 17½" | 14½" | 9" | Black |
| 349TG-SGSH | 17½" | 14½" | 9" | Gray |
| 349TY-SGSH | 17½" | 14½" | 9" | Yellow |

Rotational Molded Case



Rotational Molded Tool Case with Wheels and Telescoping Handle

Heavy-duty rotational-molded polyethylene shells with 15% thicker corners, unique molded-in bumper system so hardware and valance are "drop-protected". Cases are stackable, rugged with key locking latches, full-length piano hinge, deluxe golf grip handle, combo lock and a provision for padlock or cable tie.

| Platt# | Inside Dim. | | | Color |
|------------|-------------|-----|------|-------|
| | L | W | D | |
| 410TH-SGSH | 18" | 15" | 10½" | Black |

Transporter Tool Case



Transporter Tool Case with Wheels and Telescoping Handle

This tool case has two over-sized tool pallets which is equivalent to 3 super-size pallets. With full-length piano hinge, recessed hardware, strong rib design, HMW polyethylene, heavy-duty mill valance with black tape inlay and locking provision.

| Platt# | Inside Dim. | | | Body Depth |
|--------------|-------------|-----|-----|------------|
| | L | W | D | |
| 555TH-XGHXEH | 26" | 16" | 13" | 10" |

Tools Not Included

MOLDED TOOL CASES

Ultimate Polyethylene



Ultimate Polyethylene Tool Cases with Black Hardware

The "Ultimate" Platt tool case also features the durable molded ribbed HMW polyethylene shell. Constructed with black anodized heavy-duty frame and gasket, black finished cast key locks and combination lock, deluxe golf grip handle and full-length piano hinge. Comes standard with molded adjustable bottom divider, convenient literature pocket and two molded pallets.

| Platt# | Inside Dim. | | | Color |
|-----------------|-------------|-----|----|-------|
| | L | W | D | |
| 976T-CB | 18" | 13" | 7" | Black |
| 978T-CB | 18" | 13" | 8" | Black |
| 978TG-CB | 18" | 13" | 8" | Gray |

Deluxe Polyethylene



Deluxe Polyethylene Tool Cases with Chrome Hardware

Molded HMW polyethylene with durable ribbed shell. Features a heavy-duty aluminum frame with black trim and gasket, cast key locks, deluxe golf grip handle, full-length piano hinge and comes in three popular sizes. Comes standard with molded adjustable bottom divider, convenient literature pocket and two molded pallets.

*920TC-CB has combination lock.

| Platt# | Inside Dim. | | | Color |
|------------------|-------------|-----|----|--------|
| | L | W | D | |
| 926T-CB | 18" | 13" | 6" | Black |
| 928T-CB | 18" | 13" | 8" | Black |
| 928TG-CB | 18" | 13" | 8" | Gray |
| 928TY-CB | 18" | 13" | 8" | Yellow |
| 920TC-CB* | 18" | 13" | 9" | Black |

Premium Polyethylene



Premium Polyethylene Tool Cases with Recessed Hardware

Molded HMW polyethylene with durable ribbed shell. Features attractive black powder coated frame, all black hardware, including recessed key lock, deluxe golf grip handle and full-length piano hinge. This quality case comes standard with molded adjustable bottom divider, convenient literature pocket and two molded pallets.

| Platt# | Inside Dim. | | | Color |
|-----------------|-------------|-----|----|--------|
| | L | W | D | |
| 946T-CB | 18" | 13" | 6" | Black |
| 946TY-CB | 18" | 13" | 6" | Yellow |
| 946TG-CB | 18" | 13" | 6" | Gray |

Tools Not Included

Standard Polyethylene



Standard Polyethylene Tool Cases

Molded HMW polyethylene with durable ribbed shell. Features medium-duty valance, cast key locks and molded handle. Interior has molded fixed divider, convenient literature pocket and two molded pallets.

*605T-C comes with single pallet.

| Platt# | Inside Dim. | | | Color |
|----------------|-------------|-----|----|-------|
| | L | W | D | |
| 600T-CB | 18" | 13" | 6" | Black |
| 605T-C* | 18" | 13" | 5" | Black |

Deluxe Polypropylene



Deluxe Polypropylene Tool Cases

Black, chemical resistant with extruded aluminum frame, golf grip handle, cast chrome key locks and full-length piano hinge. Interior has divider system, two molded pallets and deluxe literature pocket.

*805T-C comes with one pallet.

| Platt# | Inside Dim. | | |
|----------------|-------------|-----|----|
| | L | W | D |
| 800T-CB | 18" | 13" | 6" |
| 805T-C* | 18" | 13" | 5" |

Economy Polypropylene



| Platt# | Inside Dim. | | |
|----------------|-------------|-----|----|
| | L | W | D |
| 836T-CB | 18" | 13" | 6" |

Economy Polypropylene Tool Case

Black injection molded polypropylene shells, heavy-duty valance with gasket, cast key locks, stitched vinyl steel-core handle, full-length piano hinge and literature pocket.

Deluxe Soft-Molded



| Platt# | Inside Dim. | | | Color |
|---------------|-------------|-----|----|--------|
| | L | W | D | |
| 610T-C | 18" | 13" | 5" | Oxford |

Deluxe Soft-Molded Tool Case

Features patented construction utilizing ABS thermoplastic shell interior, quality leather-like vinyl exterior, black anodized extruded aluminum frame for maximum strength, combination lock, cast bolts, and golf grip handle. Interior has one molded pallet, bottom divider and deluxe literature pocket. Oxford Brown. Rugged tool case with the appearance of an attache - this professional looking case will get you in the front door.

ATA TOOL CASES

Guardsman ATA 300 Cases



Guardsman™ ATA Tool Cases

Heavy-duty HMW polyethylene material with unique continuous industrial frame both on the exterior and interior of case for maximum strength (ATA 300). Recessed hardware, locking provision, full-length piano hinge, spring loaded handle and security type bolts. Deluxe literature pocket in lid and two molded pallets. Foam in bottom of case for meters.

| Platt# | Inside Dim. | | | Outside Dim. | | | Color |
|--------------|-------------|-----|----|--------------|-----|-----|--------|
| | L | W | D | L | W | D | |
| 747T-CB | 17½" | 11" | 9" | 19" | 13" | 10" | Black |
| 747TY-CB | 17½" | 11" | 9" | 19" | 13" | 10" | Yellow |
| 747TG-CB | 17½" | 11" | 9" | 19" | 13" | 10" | Gray |
| 747TO-CB | 17½" | 11" | 9" | 19" | 13" | 10" | Orange |
| 747TBLU-CB | 17½" | 11" | 9" | 19" | 13" | 10" | Blue |
| 747TGREEN-CB | 17½" | 11" | 9" | 19" | 13" | 10" | Green |



Guardsman™ ATA Tool Cases with Wheels and Telescoping Handle

Platt's rugged Guardsman™ ATA Case has now been designed and is available with a telescoping handle and built-in wheels. The case has all recessed hardware, locking provision, full-length piano hinge, literature pocket, two molded pallets and foam in bottom for meters. 777TH comes with super-size pallets and the 788TH-XGHXEH has over-sized pallets that are equivalent to three super-size pallets.

| Platt# | Inside Dim. | | | Outside Dim. | | | Color |
|-----------------|-------------|------|-----|--------------|------|------|--------|
| | L | W | D | L | W | D | |
| 757TH-CB | 18½" | 13" | 9¾" | 19½" | 14" | 12½" | Black |
| 777TH-SGSH | 18½" | 14½" | 9¾" | 19½" | 15½" | 12½" | Black |
| 777THY-SGSH | 18½" | 14½" | 9¾" | 19½" | 15½" | 12½" | Yellow |
| 777THG-SGSH | 18½" | 14½" | 9¾" | 19½" | 15½" | 12½" | Gray |
| 777THO-SGSH | 18½" | 14½" | 9¾" | 19½" | 15½" | 12½" | Orange |
| 777THBLU-SGSH | 18½" | 14½" | 9¾" | 19½" | 15½" | 12½" | Blue |
| 777THGREEN-SGSH | 18½" | 14½" | 9¾" | 19½" | 15½" | 12½" | Green |
| 788TH-XGHXEH | 25¼" | 15¼" | 13" | 26¼" | 16¼" | 16" | Black |

(757 and 788 Series also available in yellow, gray, orange, blue, white, and green.)

Aluminum Guardsman ATA 300 Cases

Aluminum Guardsman™ ATA Tool Cases

Heavy-duty textured aluminum material with unique continuous industrial frame both on the exterior and interior of case for maximum strength (ATA 300). Recessed hardware, locking provision, full-length piano hinge, spring loaded handle and security type bolts. Literature pocket and two molded pallets. Foam in bottom of case for meters.



*Wheel & Handle Cases

| Platt# | Inside Dim. | | | Color |
|-------------------|-------------|------|-----|----------|
| | L | W | D | |
| 747TALUM-CB | 17½" | 11" | 9" | Aluminum |
| 757THALUM-CB* | 18½" | 13" | 9¾" | Aluminum |
| 777THALUM-SGSH* | 18½" | 14½" | 9¾" | Aluminum |
| 788THALUM-XGHXEH* | 25¼" | 15¼" | 13" | Aluminum |

Custom Guardsman Tool Cases



Platt's Patented Guardsman ATA Tool Cases are built to exceed the exacting ATA shipping requirements. They have been tested and approved to ATA 300 specs.

They're constructed from an *ultra-durable (yet light-weight) HMW polyethylene material* with your choice of seven standard colors. They're *line bent to assure uniform thickness and unsurpassed strength*. By using polyethylene, these cases are *up to 50% lighter* than traditional wood transit cases, and because they are bent instead of formed, all corners and edges are the same thickness as the rest of the case, thereby eliminating the traditional weak spots associated with other materials.

Polyethylene can be stored in any environment from -40° to 140° and is unaffected by all common industrial solvents. Plus, our bent aluminum continuous framing system provides the ultimate in strength, and attractive appearance. Our valance system has a gasket for water/dust resistance. Platt uses completely recessed hardware which further resists damage in transit and can be furnished with combination locks or key locks in the latches.

These cases are also available as a Jetalum™ all aluminum construction.

Platt's Engineering Department will assist you in the design of your Guardsman ATA case. Pallets and interiors can be customized to hold your selection of tools.

"Your Small Quantity Specialist"

Tools Not Included

TOOL PALLETS

All Platt standard size stock tool cases come with molded pallets. The top pallet is always pallet C. The bottom pallet is always B. If these pallets are not appropriate for the user's tools, Platt will substitute the molded pallets of user's preference at no charge, or sewn pallets for a small additional cost.

If you wish to change the pallet(s) in a stock case, simply change the pallet

letter(s) after the case letter, i.e. 600T-KL. (First letter is top pallet, second letter is bottom pallet).

Pallets can be ordered separately by ordering the individual pallet letter. All of our sewn pallets can be furnished as top or bottom pallets. Our urethane pallets are molded with just the right amount of give, but also toughness to be a pleasure to work with. Our sewn pallets have strong

pockets and pouches to hold a wide range of tools and parts.

All outer edges of our pallets are sewn through our heavy backing material to prevent the separation you might have experienced in pallets of lesser quality.

Platt can custom design sewn pallets in a broad range of configurations. Contact Platt for further details,

specific capabilities, and minimum order quantity.

All Platt super-size stock cases come with SGSH pallets. (357T, 349T, 369T, 410TH, 777TH) Super-size pallets are designated with S, in front of the pallet letter, i.e. SE

Clean room pallets available upon request.

Injection Molded



A/B

All-purpose pallets with 27 pockets each. (A) Pallet, if specified as top, includes turnbutton. Bottom pallet (B) comes without turnbutton.

| Platt# | Dim. | | Options |
|--------|---------|---------|------------|
| | L | W | |
| A | 17 1/4" | 12 1/4" | Turnbutton |
| B | 17 1/4" | 12 1/4" | - |



C/D

All purpose pallets with 22 pockets each. (C) Pallet, if specified as top, includes turnbutton. Bottom pallet (D) comes without turnbutton.

| Platt# | Dim. | | Options |
|--------|---------|---------|------------|
| | L | W | |
| C | 17 1/4" | 12 1/4" | Turnbutton |
| D | 17 1/4" | 12 1/4" | - |

Sewn & Riveted




E/SE

Field service pallet designed primarily for automotive material handling and major appliance installation and maintenance.




G/SG

Field service pallets designed primarily for the installation and maintenance of office copiers and office machines.

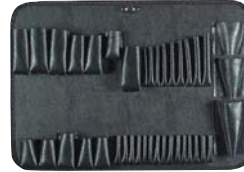

I/SI

Field service pallets designed primarily for computer and high technology installation and maintenance.

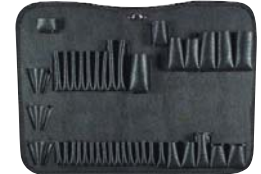

K/SK

Field service pallets designed primarily for electronic installation and maintenance.



F/SF



H/SH



J/SJ



L/SL



M/SM



O/SO

Field service pallet designed primarily for telecommunication installation and maintenance.



Q/SQ

Platt's padded notebook computer pocket mounted to a pallet allows a protective compartment for your computer.



N/SN

Field service pallets designed primarily for HVAC installation and maintenance



P/SP

Platt's quality attaché pockets mounted to a pallet allows you to carry paperwork in your tool case.



R/SR

A clipboard on a pallet allows you an area to hold papers and documentation.

| Platt# | Dim. | | Options |
|----------|---------|---------|------------|
| | L | W | |
| Standard | 17 1/4" | 12 1/4" | Standard |
| "S" | 17 1/4" | 14 1/2" | Super-size |

Additional Pallet Information

The outer edges of Platt sewn pallets are sewn all the way through the heavy backing material and reinforced with rivets to prevent the separation and tearing common in pallets of lesser quality.

Pallets may be ordered without cases. Simply specify the pallet letter.

Platt will custom design pallets for your specific needs. Please contact your local Platt representative or call our customer service department for details. A minimum quantity may apply.

Custom Pallets



All pallets can be ordered as top pallet or bottom pallet. Turnbutton comes on top pallet.

Winged Pallets



Winged Pallets

Allows for full display of your tools, and for easy access to any item. The center pallet is a G pallet and the wings are modified H pallets.

| Platt# | Dim. | | | Size |
|--------------|---------|---------|----|---------------|
| | L | W | D | |
| WGH | 17 1/4" | 12 1/4" | 2" | Standard size |
| WSGSH | 17" | 14" | 2" | Super-size |

Book Pallet



Book Pallet

Side-hinged set of pallets allows loading of additional tools in lid of case. The main pallet is an H pallet and the side pallet is a G pallet.

| Platt# | Dim. | | | Size |
|--------------|---------|---------|----|------------|
| | L | W | D | |
| BSGSH | 17 1/4" | 14 1/2" | 2" | Super-size |

Nylon Zipper Tool Cases



Nylon Zipper Tool Cases

Black nylon zipper tool cases designed to hold all of the standard size tool pallets shown on page 10. The 651ZT single zipper holds two pallets. The 652ZT double zipper holds four pallets. Now you can have a zipper tool case in the configuration you want by selecting your choice of pallets. i.e. 651ZT-GH or 652ZT-GHPQ.

IF NO PALLETS ARE SPECIFIED, 651ZT AND 652ZT ARE SHIPPED EMPTY WITHOUT PALLETS.

Shoulder strap included.

| Platt# | Outside Dim. | | |
|--------------|--------------|-----|----|
| | L | W | D |
| 651ZT | 18" | 13" | 3" |
| 652ZT | 18" | 13" | 6" |

Soft Rolling Tool Case



Soft Rolling Tool Case

Heavy-duty tool case holds two standard tool pallets and comes complete with wheels and telescoping handle for easy transportation of your tools. G and H pallets are supplied unless otherwise specified. Additional pockets for notebook computer, cords, accessories, etc.

| Platt# | Outside Dim. | | |
|---------------------|--------------|-----|----|
| | L | W | D |
| 191308ZTH-GH | 19" | 13" | 8" |

Trouble Shooter



Trouble Shooter

Consistently a best seller, the 660ZT series "Trouble Shooter" carrying case is designed for versatility. With 29 sewn tool pockets and a meter pouch on the inside, 2 additional meter pouches and a document pocket on the outside, this case will carry a wide variety of tools. Constructed of heavy-duty nylon with industrial strength zipper for durability.

| Platt# | Outside Dim. | | | Colors |
|-------------------|--------------|-----|----|----------|
| | L | W | D | |
| 660ZT | 13" | 10" | 2" | Black |
| 660ZTBLU | 13" | 10" | 2" | Blue |
| 660ZTBURG | 13" | 10" | 2" | Burgundy |
| 660ZTGREEN | 13" | 10" | 2" | Green |

Master Technician



Master Technician

For additional capacity, the larger 669ZT series "Master Technician" carrying case contains 47 sewn tool pockets and a meter pouch inside, as well as 2 meter pouches and document pocket on the outside. Constructed of heavy-duty nylon with industrial strength zipper for durability. **Shoulder strap included.**

| Platt# | Outside Dim. | | | Colors |
|-------------------|--------------|-----|----|----------|
| | L | W | D | |
| 669ZT | 15 1/2" | 11" | 2" | Black |
| 669ZTBLU | 15 1/2" | 11" | 2" | Blue |
| 669ZTBURG | 15 1/2" | 11" | 2" | Burgundy |
| 669ZTGREEN | 15 1/2" | 11" | 2" | Green |

Tools Not Included

"Quality That Lasts"

SEWN TOOL CASES

Combo Tool & Attaché/Notebook



Combo Tool and Attaché/Notebook Computer

Keep your files, manuals and misc. paperwork organized and readily available with the 689ZT "Combo Tool and Computer Attaché" case from Platt. This case contains the same interior 47 tool pocket and meter pouch configuration as our popular 669ZT, plus a padded pocket for your computer (689ZT) or a built-in clipboard (679ZT).

Shoulder strap included.

| Platt# | Outside Dim. | | |
|--------|--------------|------|----|
| | L | W | D |
| 679ZT | 17½" | 10¼" | 6" |
| 689ZT | 18" | 13" | 6" |

Machine/Copy Repair Field Service



| Platt# | Outside Dim. | | |
|--------|--------------|-----|----|
| | L | W | D |
| 641ZT | 18½" | 13" | 3" |

Machine/Copier Repair Field Service

The 641ZT "Machine/Copier Repair Field Service" carrying case with sewn in pockets features the same inside pocket configuration as our popular G & H pallet set (see pg. 10). This configuration was specifically designed for the unique needs of the office machine and copier field technician. Outside, 2 pockets with hook and loop flaps and a full-length document pocket provide additional storage capacity.

Mini Tech



Mini Tech

The compact "Mini Tech" may be used alone or stowed inside one of our larger cases. With 14 interior sewn tool pockets and one inside pouch, it is ideal when only a limited number of tools are needed. The 602ZT contains an additional 3 exterior pockets and wrapped handles.

| Platt# | Outside Dim. | | |
|--------|--------------|-----|----|
| | L | W | D |
| 601ZT | 10½" | 7⅜" | 2" |
| 602ZT | 10½" | 7⅜" | 2" |

Computer Field Service



| Platt# | Outside Dim. | | |
|--------|--------------|-----|----|
| | L | W | D |
| 642ZT | 18½" | 13" | 3" |

Computer Field Service

The 642ZT "Computer Field Service Case" is the same as the 641ZT with the exception that the inside sewn pocket configuration is the same as our pallet set I & J (see pg.10), specifically designed for the unique needs of computer and computer based equipment repair and maintenance.

Field Service Supervisor



| Platt# | Outside Dim. | | |
|--------|--------------|-----|----|
| | L | W | D |
| 691ZT | 18½" | 13" | 3" |

Field Service Supervisor

Carry a full complement of tools plus all your paperwork in this attractive attaché style 691ZT "Field Supervisor Case". With a slim 3" width profile, this cleverly designed carrying case still has room for 22 sewn in tool pockets, a snap pouch and hook and loop straps (for a flashlight or larger tools) on one side and a deluxe 3-pocket attaché interior on the other side. Outside, 2 pockets with hook and loop flaps and a full-length document pocket offer additional storage capacity.

Technician



Technician

For users who prefer molded tool pallets, Platt offers the 665ZT "Technician" case as an alternative to the popular 660ZT series with sewn pockets. The 665ZT features 27 molded pockets and 2 hook and loop pockets inside the case. Outside, 2 pockets with hook and loop flaps and a full-length document pocket provide additional storage capacity.

| Platt# | Outside Dim. | | |
|--------|--------------|-----|----|
| | L | W | D |
| 665ZT | 13¾" | 13" | 2" |

YOU'LL FIND QUALITY FEATURES IN ALL PLATT SEWN TOOL CASES

Heavy-duty nylon construction with industrial strength memory zippers. Outside pockets with hook & loop flaps provide additional storage capacity. Additional features include poly web straps with wrapped handles, and water and stain resistant exteriors. Platt is known for its superior workmanship.

Tools Not Included

SEWN TOOL CASES

Field Service Tech



| Platt# | Outside Dim. | | |
|--------|--------------|------|----|
| | L | W | D |
| 695ZT | 17½" | 10¼" | 6" |

Field Service Tech

Need to carry multiple tools and parts to the job? Store them all in the double-sided 695ZT "Field Service Tech" case. One side features 39 sewn in tool pockets and one large pouch with 3 more storage pouches and a full-length literature holder in the other side. Outside, 2 pockets with hook and loop flaps and a full-length document pocket provide additional storage capacity. **Shoulder strap included.**

Telecom



| Platt# | Outside Dim. | | |
|--------|--------------|-----|----|
| | L | W | D |
| 630ZT | 14" | 10" | 3" |

Telecom

Compact and economical, the 630ZT Telecom case still includes the hook and loop strap "buttset" holder along with 20 sewn tool pockets and 1 parts pouch.

Vacuum Pack



| Platt# | Outside Dim. | | |
|--------|--------------|-----|----|
| | L | W | D |
| VP511 | 18" | 7½" | 6" |

Vacuum Pack

Use the VP511 "Vacuum Pack" to securely store and carry your portable vacuum system and accessories. This sturdy nylon carrying case will accommodate most portable vac systems including 3M#496, Atrix's AAA Toner vac, etc. Lid compartment has sewn pockets to hold tools and accessories. **Shoulder strap included.**

Pro Telecom



| Platt# | Outside Dim. | | |
|--------|--------------|-----|----|
| | L | W | D |
| 680ZT | 18" | 13" | 4" |

Pro Telecom

Many new tools, testers and accessories are now being used by telecom installers. The 680ZT has been designed by telecom professionals. It is designed to hold all of the standard tools such as screwdrivers, hex keys, retrievers, marks, probes, punch tools, scissors, wrenches, pliers, wire strippers, solder gun, test adapters, lamp puller, polarity tester, cable tester, flashlight and much more. Now you have a case "designed by professionals for professionals". **Shoulder strap included.**

Master Telecom



| Platt# | Outside Dim. | | |
|--------|--------------|-----|----|
| | L | W | D |
| 685ZT | 15½" | 13" | 3" |

Master Telecom

Custom designed for Platt by professional telecom installers, the deluxe 685ZT "Master Telecom" carrying case efficiently and securely stores the specialized tools used by telecom installers. Stay organized with 24 sewn interior pockets, 5 small parts pouches, special pockets for tone generator and probe set, and hook and loop strap "buttset" holder. Unique clip-on "stay straps" allow case to function as a handy shelf when hung by the carrying handle on a ladder or wall hook. **Shoulder strap included.**

LAN



| Platt# | Outside Dim. | | |
|--------|--------------|------|----|
| | L | W | D |
| 688ZT | 17" | 12¼" | 5" |

LAN

The 688ZT LAN case is designed to hold a multitude of tools and testers for installation and trouble-shooting. This double-sided carrying case features 40 sewn in tool pockets and 4 pouches in one side and 11 sewn in tool pockets with 4 additional pouches in the second side. Outside, 2 pockets with hook and loop flaps and a full-length document pocket provide additional storage capacity. **Shoulder strap included.**

Basic Telecom



| Platt# | Outside Dim. | | |
|--------|--------------|------|----|
| | L | W | D |
| 675ZT | 13¾" | 12⅞" | 3" |

Basic Telecom

Slightly smaller than the Master Telecom case, the 675ZT Basic Telecom carrying case features 14 sewn tool pockets and 6 small parts pouches. Includes the same unique clip-on "stay straps" to allow case to function as a handy shelf. **Shoulder strap included.**

Custom Sewn Tool Cases



"Quality That Lasts"

Tools Not Included

SEWN TOOL CASES

Tool Bags



Mechanic's Tool Bag

This handy "Mechanic's Tool Bag" is similar to the GI tool bag used for decades by the U.S. Military. Our water-repellent nylon fabric makes it much more durable and with 8 sewn-in pockets on the inside and 2 divided snap pouches on the outside, this compact utility bag will keep your smaller tools and parts organized.

| Platt# | Outside Dim. | | | Colors |
|------------------|--------------|----|-----|----------|
| | L | W | D | |
| MTB | 12" | 6" | 6½" | Black |
| MTB-BLU | 12" | 6" | 6½" | Blue |
| MTB-BURG | 12" | 6" | 6½" | Burgundy |
| MTB-GREEN | 12" | 6" | 6½" | Green |

NEW

Tool Rolls



Tool Rolls

Durable material that allows you to organize your tools and store them in small places.

| Platt# | Outside Dim. | |
|-----------------|--------------|-----|
| | L | W |
| NEW TR01 | 21" | 12" |
| NEW TR02 | 37" | 14" |

CLC Tool Bags, Organizers & Gloves

CLC Tool Bags & Bucket Organizers

Platt carries the complete CLC product line. For additional info, please call for CLC's full line catalog.

| Platt# | Description |
|----------------|---------------------------------|
| CLC1101 | 3 Zippered Bags |
| CLC1119 | 48 Pocket Bucket Organizer |
| CLC1139 | 14 Pocket Large Traytote Bag |
| CLC1141 | 37 Pocket Double Traytote Bag |
| CLC1148 | 22 Pocket Drawstring Bucket Bag |
| CLC1161 | 23 Pocket Standard BigMouth Bag |
| CLC1162 | 29 Pocket MegaMouth Bag |
| CLC1165 | 22 Pocket Large BigMouth Bag |
| CLC1167 | 30 Pocket Roller Tote Bag |
| CLC1168 | 42 Pocket Sideglide Roller Bag |
| CLC1526 | 28 Pocket Tool Pouch |
| CLC4122 | 61 Pocket Bucket Organizer |



CLC1101



CLC1119



CLC1139



CLC1141



CLC1148



CLC1161



CLC1162



CLC1165

CLC Gloves

Handyman

General purpose glove designed for uses like: Carpentry, Automotive, Basic Utility, Plumbing, Assembly Use, etc.

| Platt# | Size |
|------------------|----------|
| CLC125S | Small |
| CLC125M | Medium |
| CLC125L | Large |
| CLC125XL | X Large |
| CLC125XXL | XX Large |



Boxer

Box Handler gloves designed for professional uses like: Warehouse, Transportation, Material/Box Handling, Parcel Delivery, Low Abrasive Applications, etc.



| Platt# | Size |
|------------------|----------|
| CLC135S | Small |
| CLC135M | Medium |
| CLC135L | Large |
| CLC135XL | X Large |
| CLC135XXL | XX Large |

Tradesman

Heavy utility gloves designed for professional uses like: Carpentry, Framing, Roofing, Material Handling, Demolition, Electrical/HVAC, etc.

| Platt# | Size |
|------------------|----------|
| CLC145S | Small |
| CLC145M | Medium |
| CLC145L | Large |
| CLC145XL | X Large |
| CLC145XXL | XX Large |



CLC1167



CLC1168



CLC1526



CLC4122

Tools Not Included

"Quality That Lasts"



Buffalo Case Company Sewn Tool Cases

Designed In U.S.A. - Made Off-Shore



| Platt# | Outside Dim. | | |
|---------------|--------------|-----|----|
| | L | W | D |
| BCC-06 | 13" | 10" | 2" |

This rugged case has 29 sewn tool pockets and a meter pouch on the inside, plus 2 additional meter pouches and document pocket on the outside. This case is not only attractive, but is very versatile and holds a variety of tools. Constructed of durable 600d polyester with an industrial strength zipper.



| Platt# | Outside Dim. | | |
|---------------|--------------|-----|----|
| | L | W | D |
| BCC-20 | 10½" | 7¾" | 2" |

This durable bag has 14 sewn tool pockets and a parts pouch. This case can be used alone when only a limited number of tools are needed or it can be carried in one of our larger cases.



| Platt# | Outside Dim. | | |
|---------------|--------------|-----|----|
| | L | W | D |
| BCC-58 | 15½" | 13" | 3" |

This case efficiently stores the specialized tools used by telecom installers. Contains 24 sewn interior pockets, 5 small parts pouches, special pockets for tone generator and probe set and hook and loop strap "butts" holder. Case also comes with side straps to hold the case open as a work platform. Constructed of durable 600d polyester, with industrial strength zipper, this carrying case comes complete with an adjustable and removable shoulder strap.



| Platt# | Outside Dim. | | |
|---------------|--------------|------|----|
| | L | W | D |
| BCC-59 | 17½" | 10¼" | 6" |

This large capacity tool carrying case is double-sided and has 39 sewn tool pockets, one large snap pouch on one side and 3 additional pouches with a full-length document pocket on the other side. Adjustable and removable shoulder strap also included.



| Platt# | Outside Dim. | | |
|---------------|--------------|-----|----|
| | L | W | D |
| BCC-96 | 15½" | 11" | 2" |

For additional capacity, this carrying case contains 47 sewn tool pockets and a meter pouch inside, as well as 2 meter pouches and document pocket on the outside. Constructed of durable 600d polyester, with industrial strength zipper, this carrying case comes complete with an adjustable and removable shoulder strap.



| Platt# | Outside Dim. | | |
|---------------|--------------|-----|----|
| | L | W | D |
| BCC-98 | 18" | 13" | 6" |

This case contains the same interior 47 tool pocket and meter pouch configuration as our BCC-96, plus a padded pocket for your laptop computer. The 2 outside meter pouches and outside document pocket are also standard on this case. Constructed of durable 600d polyester, with industrial strength zipper, this carrying case comes complete with an adjustable and removable shoulder strap.

Buffalo Case Company Molded Tool Case

**Case Made in U.S.A.
Pallets Made Off-Shore**

This sturdy molded polyethylene tool case has a medium-duty aluminum valance, chrome cast key locks, molded handle and comes complete with 2 sewn tool pallets.

| Platt# | Inside Dim. | | |
|-------------------|-------------|-----|----|
| | L | W | D |
| BCC-00T-GH | 18" | 13" | 6" |



Computer / AV Cases



| Platt# | Inside Dim. | | |
|--------------------|-------------|-----|----|
| | L | W | D |
| AVEXE191308 | 19" | 13" | 8" |

This case is both rugged and lightweight. Designed for double-duty, it carries both your notebook computer and other equipment such as video projectors, printers and extra hard-drives. Complete with telescoping handle and wheels for convenient transportation.



| Platt# | Inside Dim. | | |
|----------------|-------------|-----|--------|
| | L | W | D |
| AVPC020 | 20" | 14" | 6 1/2" |

The AVPC020 has a main compartment that opens very wide for easy access to your computer equipment. The case has zippered pockets and its telescoping handle and wheel system allows for easy transport of your equipment while keeping your equipment safe in padded compartments.



| Platt# | Inside Dim. | | |
|--------------------|-------------|---------|----|
| | L | W | D |
| AVEXE141208 | 14" | 11 1/2" | 7" |

This case comes with adjustable divider to accommodate your projector and notebook computer. Side pocket has built-in organizer for cell-phone, pens, business cards, etc. **Shoulder strap included.**



| Platt# | Inside Dim. | | |
|---------------|-------------|-----|----|
| | L | W | D |
| LN-777 | 17 1/2" | 10" | 5" |

Exterior has two storage pockets and one large document pocket. Interior features large literature lid pocket plus storage for disks. Bottom comes with adjustable dividers to accommodate laptop and accessories. **Shoulder strap included.**



| Platt# | Inside Dim. | | | Body Depth |
|--------------------|-------------|-----|-----|------------|
| | L | W | D | |
| 261617AHLAP | 26" | 16" | 17" | 12" |

This durable, rugged transportation case series includes wheels and telescoping handle for convenient transportation. Molded from high molecular weight polyethylene, with rib design for strength, this case is quality that lasts. Interior is set up to hold 5 notebook computers, video projector and accessories.

Aluminum Attaché Cases



| Platt# | Inside Dim. | | |
|--------------|-------------|---------|--------|
| | L | W | D |
| 06488 | 17 3/4" | 12 3/4" | 4 1/2" |

Drawn Aluminum Attaché

Sleek and stylish, this satin finish anodized aluminum shell briefcase is lined with tweed fabric and features deluxe interior vinyl pockets for literature, pens, diskettes, etc. Complete with padded handle, combination lock and durable full-length piano hinge.



| Platt# | Inside Dim. | | |
|--------------|-------------|---------|--------|
| | L | W | D |
| 06448 | 17 1/4" | 12 1/4" | 4 1/2" |

Fabricated Aluminum Attaché

Attractive ribbed aluminum finish with contrasting black corner assemblies, this lightweight rigid body attaché case features an ergonomic cushion-grip handle, same deluxe tweed/vinyl interior plus 2 combination locks.

Deluxe Soft Molded Attaché Cases



Shown Open
06273

Deluxe Soft Molded Attaché Cases

Patented leather-like vinyl construction sewn over and through molded ABS thermoplastic shell. Black anodized aluminum frame, recessed combination lock and golf grip handle. Interior has 3 pocket soft-touch vinyl folder.

* 06273 and 06373 have recessed combination lock and latches.

** 06283 and 06288 have 2 flip down combination locks.

| Platt# | Inside Dim. | | | Colors |
|----------------|-------------|---------|--------|--------|
| | L | W | D | |
| 06273* | 18" | 12 1/2" | 3 1/2" | Oxford |
| 06373* | 18" | 12 1/2" | 3 1/2" | Black |
| 06283** | 18" | 12 1/2" | 3 1/2" | Oxford |
| 06288** | 18" | 12 1/2" | 4 1/2" | Oxford |

High Impact Polypropylene Attaché



| Platt# | Inside Dim. | | |
|--------------|-------------|-----|----|
| | L | W | D |
| 06385 | 18" | 13" | 5" |

High-Impact Polypropylene Attaché

High-impact black polypropylene shells with extruded aluminum frame, cast chrome key locks, full-length piano hinge and golf grip handle. Interior has 3 pocket soft-touch vinyl file folder.

Catalog Cases



Catalog Cases

Patented construction features nylon-backed vinyl top, bottom and sides. Thermoplastic end shells and clear anodized aluminum frames give superior support, making it the best and longest lasting catalog case available. Concealed metal rods running length of case interconnected and riveted to end shells form a lightweight yet flexible frame. With large bottom glides for maximum wearability, outside pocket for convenience, chrome plated combination locks and unique golf grip handle.

| Platt# | Inside Dim. | | | Colors |
|--------|-------------|-----|----|--------|
| | L | W | D | |
| HT219I | 17" | 12" | 8" | Oxford |
| HT319I | 17" | 12" | 8" | Black |
| HT221I | 19" | 12" | 8" | Oxford |
| HT321I | 19" | 12" | 8" | Black |

Fabricated Static-Free PCB Cases



Static-Free PCB Cases

Exterior is static-free black cotton duck and anti-static blue poly end shells inter-locked and riveted to an aluminum frame for maximum strength. Two combination locks, golf grip handle, and giant studs for wearability. Interior features our unique adjustable static-free environment with cushioned separators. Platt cases incorporate Dry Stat/Cryovac EPG 112 humidity independent, amine free static dissipative material and Cancel amine free open cell cushion materials that meet or exceed Military specifications MIL-B-81705, Type II and PPP-C-1842A, Type III. With grounding snap. The number of slots determines the amount of board space available in each case. All but the 12-PCB have two dividers for enhanced board storage.

| Platt# | Inside Dim. | | | Slots |
|--------|-------------|-----|-----|-------|
| | L | W | D | |
| 12-PCB | 12" | 12" | 8" | 7 |
| 21-PCB | 21" | 12" | 8" | 7 |
| 24-PCB | 17" | 14" | 13" | 11 |
| 29-PCB | 23" | 18" | 8" | 9 |



Aerosol Can Sample Case



Detail of inside bottom molded insert for 639.

Aerosol Can Sample Cases

Molded of black ABS thermoplastic exterior with extruded aluminum frame, drawbolt key locks, and molded handle. Interior is custom molded to hold 8 cans.

| Platt# | Inside Dim. | | |
|--------|-------------|-----|----|
| | L | W | D |
| 639 | 19" | 13" | 4" |

Slide Carousel Projector Case



Slide Carousel Projector Case

ABS thermoplastic exterior with extruded aluminum frame, drawbolt key locks and molded handle. Interior custom formed to fit Ektagraphic series 4000 and 5000 series.

| Platt# | Inside Dim. | | |
|--------|-------------|-----|----|
| | L | W | D |
| 1913 | 19" | 13" | 7" |

Divider Boxes



Infinite Divider Boxes

The ultimate storage container for small parts. Dividers are moveable in 1/16" increments providing flexibility in organized space. Resistant to oil, solvents and most common chemicals. Sold in master pack quantity only.

| Platt# | Dim. | | | #Dividers |
|--------|----------------------------------|---------------------------------|---------------------------------|-----------|
| | L | W | D | |
| PB300 | 6 ³ / ₈ " | 3 ³ / ₈ " | 1 ¹ / ₄ " | 6 |
| PB600 | 10 ¹ / ₂ " | 6 ¹ / ₂ " | 1 ¹ / ₂ " | 6 |
| PB900 | 13 ¹ / ₈ " | 8 ³ / ₄ " | 1 ⁷ / ₈ " | 16 |

"Quality That Lasts"

Carts



CART01-B

Constructed of 16 gauge steel tubing .625 dia. and 3/8" dia. solid steel rod. Patented safety hook.

CART07

Glides up and down steps and curbs, yet telescopes closed in a single motion to fit airline overheads. When open: 52"x16 1/2"x19"

CART08

Glides up and down steps and curbs, yet telescopes closed in a single motion to fit airline overheads. When open: 52"x16 1/2"x19". Cart has unique rear wheel assembly that supports larger loads.

CART13

For business, home, recreation or travel. Folds to 2 1/2" flat. Large 7 1/4" shock absorbent tires.

CART14

For business, home, recreation or travel. Folds to 2 1/2" flat. Large 7 1/4" shock absorbent tires.

CART15

This durable and lightweight cart fits in the airline overhead compartment and easily stores in a closet or car trunk. Folds to 2" flat.

| Platt # | Load Cap. | Load Tray | | Height | Ship Weight | Fold Height | | | Wheel Dia. | Color |
|-----------------|-----------|-----------|---------|-------------------|-------------|-------------|---------|--------|------------|----------|
| | | L | W | | | L | W | D | | |
| CART01-B | 275 lbs. | 14" | 13" | 46" | 10.3 lbs. | 27" | 17" | 8" | 7" | Black |
| CART07 | 400 lbs. | 16" | 12 3/4" | 52" | 15 lbs. | 25 1/2" | 16 1/2" | 5 3/4" | 6" | Chrome |
| CART08 | 400 lbs. | 16" | 12 3/4" | 52" | 19 lbs. | 25 1/2" | 16 1/2" | 5 3/4" | 6" | Chrome |
| CART13 | 275 lbs. | 9 1/2" | 19" | 40" | 11.5 lbs. | 25 3/4" | 19" | 2 1/2" | 7 1/2" | Aluminum |
| CART14 | 275 lbs. | 16" | 15 1/2" | 44" | 16 lbs. | 27 3/4" | 19" | 2 1/2" | 7 1/4" | Aluminum |
| CART15 | 200 lbs. | 15 1/4" | 9 1/4" | 35 1/2" & 39 1/2" | 7 1/4 lbs. | 25 1/4" | 15 1/4" | 2" | 5" | Aluminum |

* Warranty provided through cart manufacturer.*

Case Replacement Hardware

Handles, Locks & Wheels

Please contact our customer service department at 1-800-99-PLATT if you should ever need to order replacement handles, locks or wheels. Additional hardware available, view our Engineering Catalog on our web site for a full listing.



HAN011
Die-cast chrome
Golf grip handle



HAN011B
Die-cast black
Golf grip handle



HAN006
Black plastic with
cushioned grip,
screw-on handle



LOC005
Die-cast chrome
key-lock

LOC024
Black
key-lock



LOC019
Die-cast chrome
key-lock



LOC011
Combo lock
Black



HDW007
Polyurethane wheel



TSA6430PSB
TSA7400PW
TSA7470PFY
Padlock for cases
with padlock
provision

Custom Sewn Cases



The design options are almost unlimited. In addition to soft-sewn cases, we produce pouches, pockets, padded cases, foam-filled soft cases, plus numerous other workplace styles.

We work primarily with nylon, 600d polyester, and coated vinyl, but other materials are available in a wide range of colors, depending on your application and your preference.

Contact Platt's Engineering Department at (800) 222-1555 to discuss your particular application.

Custom Molded Cases



The design options are almost unlimited. Platt can do standard cases with custom foam, custom molded cases with your choice of hardware, custom logos, doors, handles, wheels, etc. Platt can also do custom tooling to make your case totally unique.

Contact Platt's Engineering Department at (800) 222-1555 to discuss your particular needs and details.

"Your Small Quantity & Custom Case Specialist"

If you don't see a case that fits your needs,
then our custom case department will build it for you.

Custom Colors

Nameplates

In-House Foam Capability

Digital Artwork Capability

Custom Foam

Molded-In Logo

In-House CAD Design Capability

In-House Digital Photo Capability



CUSTOM DIE-CUT FOAM



CUSTOM SOFT-SEWN



INSERTS

Quality that Lasts.

84 years of experience and innovation in the custom case industry has positioned Platt as the industry leader.

It's no wonder when you consider that Platt was the first to introduce: combination locks on luggage, cushioned handles, custom hardware, plastic molded bowling bags, and urethane pallets. Our product development team and experienced engineers have the knowledge to make your dream case a reality.

From soft-sewn zipper tool bags to foam-filled cases, we will work with you to create a case for any use.

Contact our engineering department or your local distributor for additional information.

Platt Luggage, Inc.
4051 W. 51st Street, Chicago, IL 60632
1-800-997-5288, fax 1-773-838-2010
or visit us at www.plattcases.com.