


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

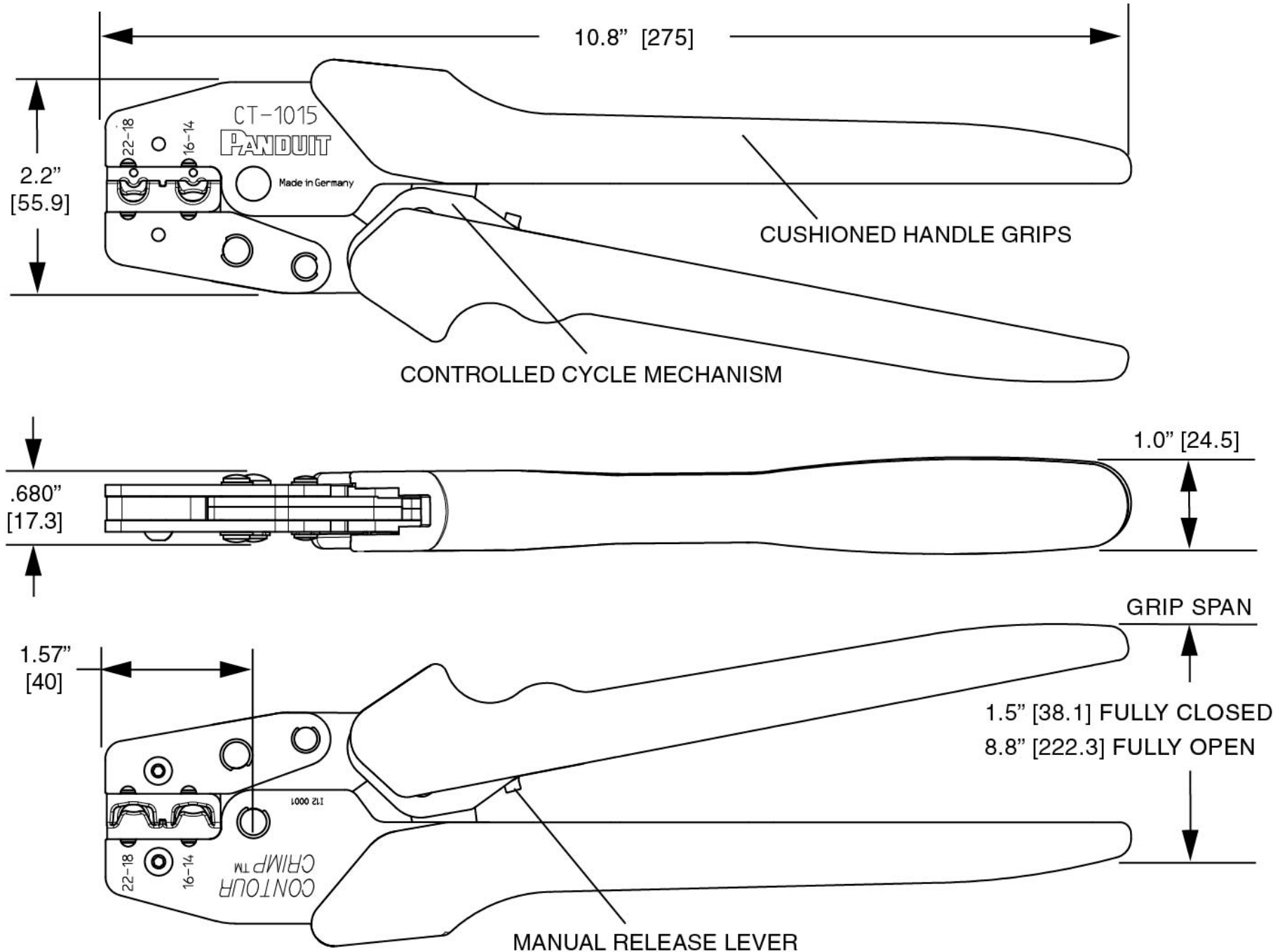

NOTES, UNLESS OTHERWISE SPECIFIED:

PANDUIT CT-1015 TOOL:

TOOL WEIGHT: 27.1 oz. [0.77] kg

Crimps Panduit #22 - #14 AWG Supra-Grip Female Disconnects.

Provides UL Listed and CSA Certified terminations with applicable Panduit terminals.

DIMENSIONS SHOWN IN BRACKETS [] ARE METRIC, AND ARE FOR REFERENCE ONLY.

CRIMP POCKET AWG / mm ²	ENGLISH GO / NO GO GAGE MEMBERS		METRIC GO / NO GO GAGE MEMBERS	
	"G" Dia. (GO)	"NG" Dia. (NO GO)	"G" Dia. (GO)	"NG" Dia. (NO GO)
22-18/0,5-1,5	.071"	.081"	1,80mm	2,06mm
16-14/1,5-2,5	.091"	.101"	2,31mm	2,57mm



NOTE: In the interest of higher quality and value, Panduit products are continually being improved and updated. Consequently, pictures shown may vary from the product received.

							CT-1015 Contour Crimp™ Crimping Tool							
							CUSTOMER DRAWING							
							ITEM REVISION NAME:		TP28307B01_00			PANDUIT		
							UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE:					MATERIAL: -----		
							(.x) ± --- (.xxx) ± --- (.xx) ± --- ANGLES ± ---					DRAWING NUMBER: TP28307B01		
							THIRD ANGLE PROJECTION							
							DRAWN BY:		DATE:		SCALE		SIZE	
							BLR		11-18-16		NONE		SHT 1 OF 1 B	
							10928							
							00		11-18-16		BLR		BJPU JADE RELEASED	
							REV		DATE		BY		CHK APR DESCRIPTION ECN	