

Search Results

- Evaluate
- FAQ's
- How to Buy
- Bill of Material
 - Favorite Products List
 - Locate Distributor


Home > Products Overview > Search Results >

Current refinements (click  to remove) Search Tips  Within Results

 Text Search: 'GE380-Q'

Your search criteria matched only one product, shown below

GE380-Q

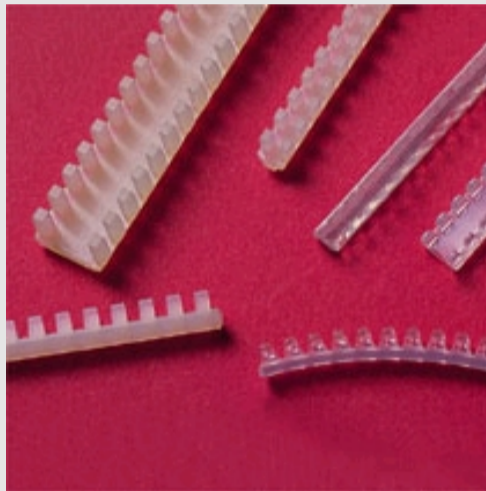

Part Number	GE380-Q
RoHS Compliancy Status	Compliant
Part Description	Military Specification Nylon Grommet Edging in 12.75" strips.
Material	Nylon 6.6
Color	Natural
Military Specification	MS21266-7N
Height (In.)	.26
Height (mm)	6.5
Length (In.)	12.75
Length (mm)	323.9
Width (In.)	.52
Width (mm)	13.1
Flammability Rating	UL94 V-2
Outside Depth (In.)	.255
Outside Depth (mm)	6.5
Outside Width (In.)	.515
Outside Width (mm)	13.1
Panel Thickness Range (In.)	.318 – .380
Panel Thickness Range (mm)	8.1 – 9.7
Pricing Description	Grommet Edging, Slot Strip, Nylon, Natural
Temperature Range	-40°F to 149°F (-40°C to 65°C)
Min. Order UOM	PC
Min. Order Qty.	25
BOM Qty. (# of Pkgs.)	<input type="text" value="0"/>
Add to Favorite Product List	

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.