

Search Results

- Evaluate
 - FAQ's
- Design a Solution
 - Part Drawings
 - PDFMilitary Sta ..
- How to Buy
 - Bill of Material
 - Favorite Products List
 - Locate Distributor


Home > Products Overview > Search Results >

Current refinements (click  to remove) Search Tips

 Text Search: 'GE85-C'

Your search criteria matched only one product, shown below

GE85-C

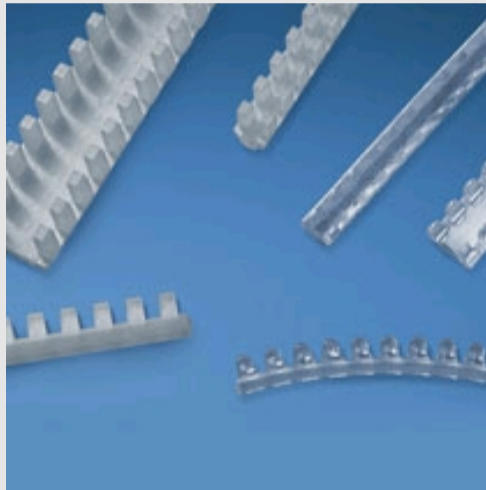

Part Number	GE85-C
RoHS Compliancy Status	Compliant
Part Description	Military Specification Nylon Grommet Edging in 12.75" strips.
Material	Nylon 6.6
Color	Natural
Military Specification	MS21266-2N
Height (In.)	.16
Height (mm)	3.9
Length (In.)	12.75
Length (mm)	323.9
Width (In.)	.18
Width (mm)	4.5
CE Compliant	No
CE Marking	No
Flammability Rating	UL94 V-2
Outside Depth (In.)	.155
Outside Depth (mm)	3.9
Outside Width (In.)	.175
Outside Width (mm)	4.5
Panel Thickness Range (In.)	.052 – .085
Panel Thickness Range (mm)	1.3 – 2.2
Pricing Description	Grommet Edging, Slot Strip, Nylon, Natural
Temperature Range	-40°F to 149°F (-40°C to 65°C)
Min. Order UOM	PC
Min. Order Qty.	100
BOM Qty. (# of Pkgs.)	<input type="text" value="0"/>
Add to Favorite Product List	

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.