

TTR-35RX0

Hook & Loop Cable Ties

Hook and Loop 35' Rolls, 10 Roll-pack, Standard Cross Section.



Specifications

Application	Bundle High performance communication cabling in air handling spaces
Color	Black
Length (ft.)	35
Length (m)	10.7
Material	Nylon/Polyethylene
Min. Bundle Diameter (In.)	0.625
Min. Bundle Diameter (mm)	16
Min. Loop Tensile Strength (Lbs.)	40



Min. Loop Tensile Strength (N)	178
Thickness (In.)	0.035
Thickness (mm)	0.9
Type	Roll
RoHS Compliancy Status	Compliant
Min. Order Qty.	1

Packaging Details


UPC	61305625935
Std. Pkg. Qty.	1
Std. Pkg. Volume (cf)	0.1593

Std. Ctn. Qty.	10
Std. Ctn. Volume (cf)	1.5932

Resources


Part Drawings	Tak-Tape™ Rolls TRR Series: 00555BD-01	US English	PDF	135.82KB		
---------------	--	------------	-----	----------	---	---

Related Products

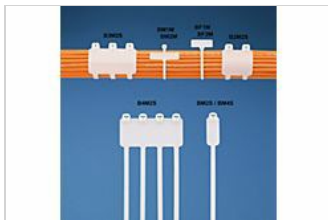


B2M2S-D

Dome-Top® barb ty marker tie, wrap, standard cross section, 8.0 (203mm) length, 1.15 x .91 (29.2 x 23.1mm) marker write-on area, nylon 6.6, natural.

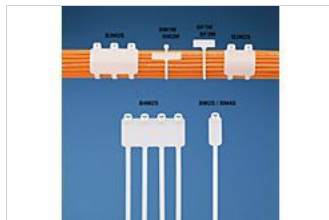

B2M2S-D0

Dome-Top® barb ty marker tie, wrap, standard cross section, 8.0 (203mm) length, 1.15 x .91 (29.2 x 23.1mm) marker write-on area, weather resistant nylon 6.6, black.

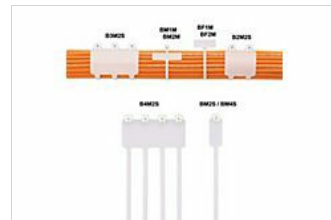

B3M2S-TL

Dome-Top® barb ty marker tie, wrap, standard cross section, 8.0 (203mm) length, 1.81 x .91 (46.0 x 23.1mm) marker write-on area, nylon 6.6, natural.



Email Support

Email support available
24/7



800-777-3300

Monday through Friday
7:00 am-6:30 pm CST



Where to Buy

Find a Panduit Distributor
or Partner

ABOUT US

Research and Development

Media Resources

World Headquarters

Awards

Partner Ecosystem

CAREERS AT PANDUIT

THE HUB – PARTNER PORTAL

PRODUCT REGISTRATION

PANDUIT CONNECTIONS BLOG



GET OUR CATALOG

Download the PDF or request a copy be mailed to you.

Which catalog would you like? ▼

▶ **DOWNLOAD** ▶ **REQUEST COPY**

