

Search Results

Evaluate

- FAQ's
- Press Releases
- Improve Wire ..
- Product Bulletins
 - PDFType H HN HS ..

Design a Solution

- Part Drawings
 - DXF-Type H-Hing ..
 - DWG-Type H-Hing ..
 - PDFType H-Hing ..

How to Buy

- Bill of Material
- Favorite Products List
- Locate Distributor


Home > Products Overview > Search Results >

Current refinements (click  to remove) Search Tips  Within Results

 Text Search: 'H2X3LG6'

Your search criteria matched only one product, shown below

H2X3LG6

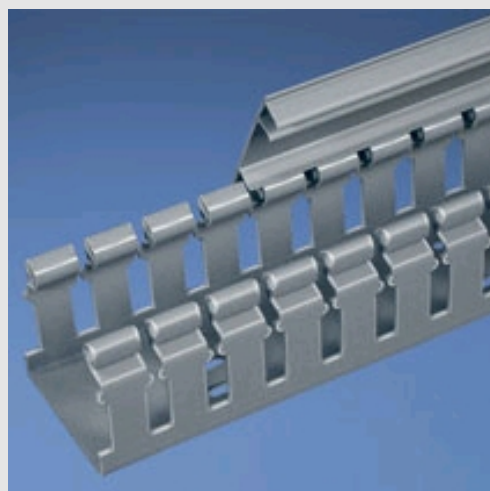

Type H Wiring Duct is ideal for applications that require easy access in control panels and communication closets for frequent equipment modifications or repairs where moves, adds and changes are common. Due to the hinging feature, Hinged Cover Slotted Wall Wiring Duct reduces the time and hassle associated with removing and reinstalling traditional duct cover to perform maintenance or changes.


Specifications

- Wide slot/finger design provides excellent wire management in general purpose applications and is compatible a wide range of wire sizes and component types
- Made of lead-free PVC
- Rated for continuous use temperature: 122°F (50°C)
- UL94 Flammability Rating V -0
- Conforms with NFPA 79 -2007 section 13.3.1 requirement for flame retardant material
- Provided with standard mounting holes
- Base and cover length is 6 ft.

Features and Benefits

- Integrated hinged cover design allows easy access to wiring without hassle of removing and reinstalling cover
- Dual-sided hinge can open up to 100° from either sidewall of duct base for easy access to channel
- Cover retention flanges allows the cover to open and close easily
- Double scoreline allows fingers and complete sidewall removal
- Cover removal rib makes cover easy to open from either side
- Restricted slot design retains wire in slot for fast, easy wire installation or removal

Base and cover sold separately.

Part Number	H2X3LG6
RoHS Compliancy Status	Compliant
Part Description	Wide finger, slotted hinged wiring duct.
Material	Lead- Free PVC
Color	Light Gray
CSA Certified	Yes
UL Recognized (File No. E147128)	Yes
Length (ft.)	6
Duct Size W x H (In.)	2.17 x 3.06
Duct Size W x H (mm)	55.1 x 77.7
Mounting Method	Standard Mounting Holes
Pricing Description	Slotted Hinged Duct,PVC,2"X3"X6',Light Gray
Slot Width (In.)	.31
Slot Width (mm)	7.9
Cover Part Number	HC2LG6
Min. Order UOM	FT
Min. Order Qty.	6
BOM Qty. (# of Pkgs.)	<input type="text" value="0"/>
Add to Favorite Product List	

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.