


Current refinements (click to remove)

Search Tips

Region **USA** Product Family **HSTTV Heat Shrink on 100 Ft. Reels** Text Search: 'HSTTV19-C'

Your search criteria matched only one product, shown below.

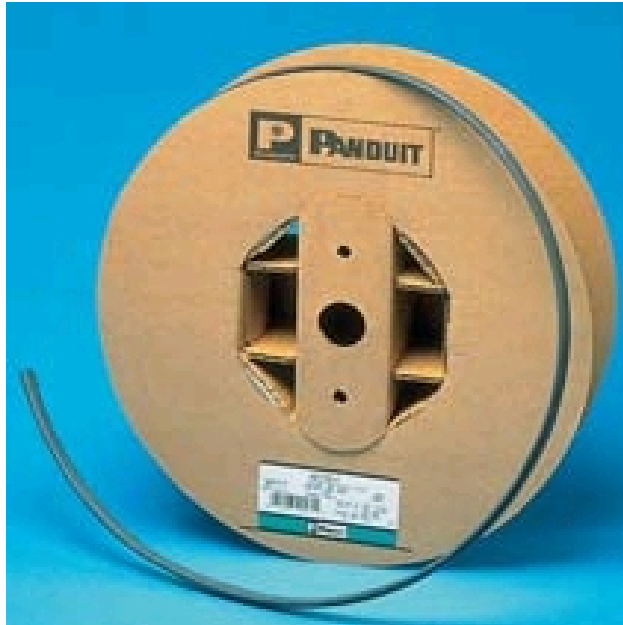

Flexible Polyolefin VW1 DRY-SHRINK™ Heat Shrink Tubing on Small Reels

- For dry locations
- Highly flame retardant
- Fast Shrink Time
- Material Type: Highly Flexible Crosslinked Polyolefin
- Shrink Ratio: 2:1
- Temperature Range:-67°F to 257°F (-55°C to 125°C)
- Voltage: 600V
- UL VW-1 Recognized, CSA Certified
- Mil Spec: AMSDTL-23053/5 Class 3

Part Number:	HSTTV19C
RoHS Compliancy Status:	Compliant
Part Description:	Thin Wall Polyolefin Heat Shrink (UL224 VW1)
Material:	Polyolefin cross-linked
Color:	Black
CSA Certified:	Yes
Military Specification:	AMS-DTL-23053/5 Class 3
UL Recognized:	E122770
Length (m):	30.5
Flammability Rating:	UL224 VW-1
Length Per Reel (ft.):	100
Length Per Reel (m):	30.5
Max. Recovered I.D. (In.):	.093
Max. Recovered I.D. (mm):	2.4
Min. Expanded I.D. (In.):	.187
Min. Expanded I.D. (mm):	4.8
Nominal Diameter (In.):	.187
Nominal Diameter (mm):	4.8
Nominal Recovered Wall Thickness (In.):	.020
Nominal Recovered Wall Thickness (mm):	0.5
Shrink Ratio:	2:1
Temperature Range:	-67°F to 257°F (-55°C to 135°C)
Min. Order UOM:	RL
Min. Order Qty.:	1
BOM Qty. (# of Pkgs.)	<input type="text" value="0"/>

Add to My Catalog

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'My Catalog' features.