


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	7/16 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	RED
Panduit Die Index No. on Barrel	P21

WIRE SIZE/COMBINATIONS	
(1) #12 str w/ (1) #14 str	(4) #14 str
(3) #14 str	(1) #10 str w/ (1) #12 str
(2) #12 str	(2) #12 str w/ (1) #14 str
(1) #10 str w/ (1) #14 str	(1) #10 str w/ (2) #14 str
(1) #12 str w/ (2) #14 str	(1) #12 str w/ (3) #14 str

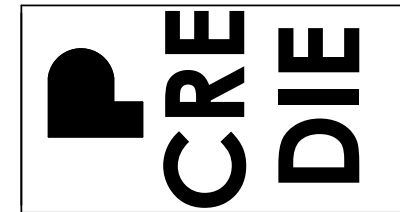



Color coded barrel markings



CERTIFIED



LISTED Wire Connector

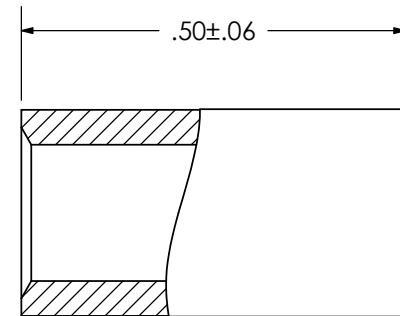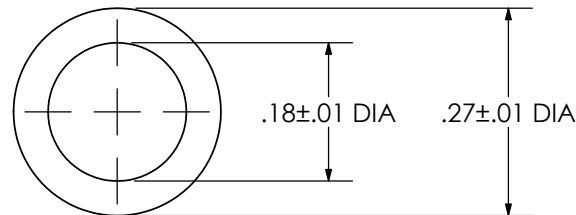

00	4/07	JHNU	TLCO	RELEASED	PC00728
REV	DATE	BY	CHK	DESCRIPTION	ECN

**PANDUIT CORP.** TINLEY PARK, ILLINOIS

PSCRED-L  
Parallel Splice

SCALE N/A

DRAWING NO / CAD FILE

PSCRED-CUST