

Search Results

- Evaluate
 - FAQ's
- Design a Solution
 - Part Drawings
 - PDF Tie Mounts M ..
- How to Buy
 - Bill of Material
 - Favorite Products List
 - Locate Distributor


Home > Products Overview > Search Results >

Current refinements (click  to remove) Search Tips


 Text Search: 'TM3S2510-M39'

Your search criteria matched only one product, shown below

TM3S2510-M39

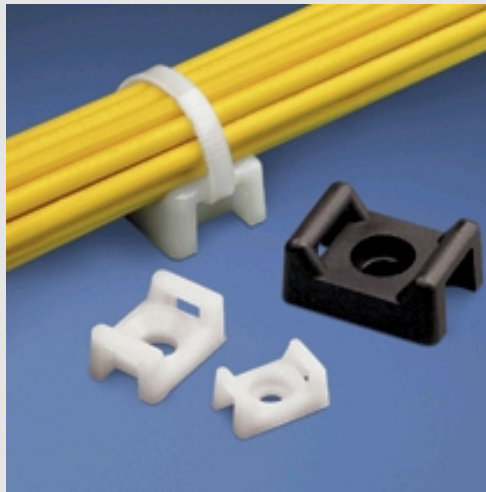

- Unique cradle design provides maximum stability for cable bundle
 - Low profile design keeps bundle close to mounting surface where overhead space is limited
- ‡Cable tie cross section sizes: M = Miniature, I = Intermediate, S = Standard, HS = Heavy Standard, LH = Light-Heavy

Part Number	TM3S2510-M39
RoHS Compliancy Status	Compliant
Part Description	Cable Tie Mount- Screw Applied
Material	Heat Stabilized Nylon 6.6
Color	Ivory
Height (In.)	.38
Height (mm)	9.5
Length (In.)	.86
Length (mm)	21.8
Width (In.)	.62
Width (mm)	15.8
CE Compliant	No
CE Marking	No
Environment	Indoors
Flammability Rating	UL 94 V-2
Mounting Method	#10 (M5) screw
Pricing Description	Cable Tie Mount, .62" (15.8mm)W, #10 Screw (M5), Flame Ret.
Screw Size	#10 (M5)
Screw Size Metric	M5
Used With Cable Ties	M, I, S, LH
Min. Order UOM	PC
Min. Order Qty.	1000
BOM Qty. (# of Pkgs.)	<input type="text" value="0"/>
Add to Favorite Product List	

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.