




MAILING ADDRESS:
 P.O. Box 115
 SHIPPING ADDRESS:
 100 Interpower Avenue
 Oskaloosa, IA 52577 (USA)
 E-MAIL: info@interpower.com

US, CAN, PR, VI:
 Call Toll-free: (800) 662-2290
 Fax Toll-free: (800) 645-5360
 INTERNATIONAL:
 Phone: (641) 673-5000
 Fax: (641) 673-5100

IEC 60320 Plug - Straight Entry

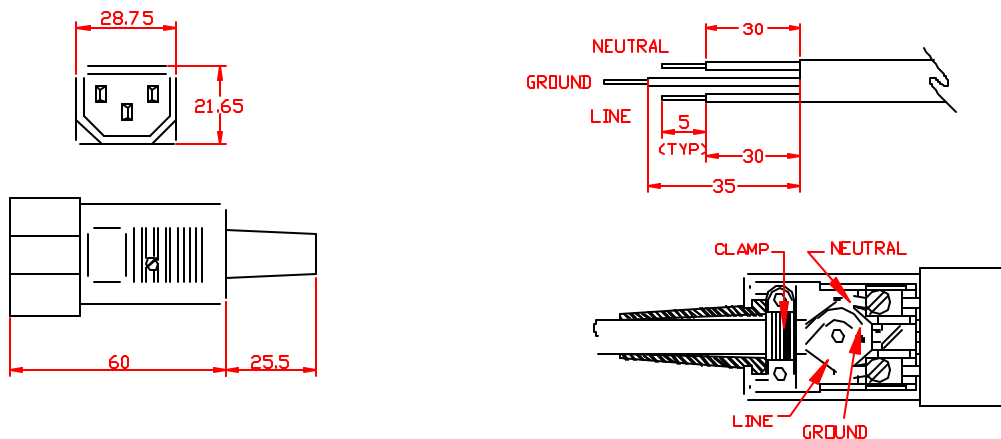

Types of cable		Torque Values (N/m)		
AWG 18-14	EN4, EN7	Terminal Screws	Cable Clamp Screws	Cover Screw
*SCF-A-2LF Types 9.8mm OD	0.75 L/L, 1.5mm up to 9.8mm OD	0.4-0.5	0.25-0.3	0.25-0.3

Note: The screws should be tightened securely without overtightening;
 suitable torque values are shown in the table.

Specifications (Note: dimensions in mm)	General Material: Noryl VO 150B
Part Number: 83011060	Color: Black
Current Rating: NA 15/Intl 10	CE Marked: yes
Voltage Rating: 250	
Temperature Rating: 65 °C	
Flammability Rating: UL 94V-0	
Class: 1	
Number of Contacts: 3	
Contact Style: Screw terminal	
Contact Material: Nickel-plated brass	
Sheet Style: E	
Mounting Style: Cable Mount	
Panel Thickness:	
Approvals: CSA UL VDE	
Remarks:	
Last Modification: 08/09/02 • 13:16:22 • jcaligiu	*Specifications subject to change without notice