

DVI KIT & D - SUB BACK COVERS



FITTING TABLE FOR D-SUB HOODS DVI HOODS

HOOD SIZE	FITS REGULAR D-SUB	FITS HIGH-DENSITY D-SUB
9	DB 9	HD 15
15	DB 15	HD 26
25	DB 25	HD 44
37	DB 37	HD 62
50	DB 50	HD 78

- Plastic Outer with Inner Metal Funnel
- Exit Inside Diameter Marked
- With Thumb Screw
- Fits DVI Connectors (See Page 103)



DVI-HDKIT85 8.5mm
DVI-HDKIT95 9.5mm

GRAY PLASTIC HOODS (Metal SR)

- Metal Clamp Strain Relief
- Includes Necessary Hardware for Assembly

Gray Color Hood **DP-09C** **DP-25C**
Black Color Hood **DP-09C-BK** **DP-25C-BK**



METALIZED PLASTIC HOODS

- Light Weight Alternative for Die Cast Metal Hoods
- Includes Necessary Hardware for Assembly
- Metal Clamp Strain Relief



DN-09C DN-25C
DN-15C DN-37C
DN-19C DN-50C

PLASTIC WITH THUMB SCREWS

- Gray Plastic
- Includes Necessary Hardware for Assembly
- Metal Clamp Strain Relief
- Thumb Screw w/ Knurl



DDP-(XX)CT

XX= Pins: 9, 15, 25, 37, 50.

DDP-25CT

METALIZED WITH THUMB SCREWS

- Metalized Plastic
- Includes Necessary Hardware for Assembly
- Metal Clamp Strain Relief
- Thumb Screw w/ Knurl



DDN-(XX)CT

XX= Pins: 9, 15, 19, 25, 37, 50.

DDN-25CT

GRAY PLASTIC HOODS (Nylon SR)


- Nylon Screw Strain Relief
- Includes Necessary Hardware for Assembly
- Hex Hole for Allen Wrench

DP-09C/S
DP-15C/S
DP-25C/S



THUMB SCREWS

- Machined Metal Screw
- 4-40 Thread
- Special Replacement for Regular Size Screw on DP-(XX) Hoods

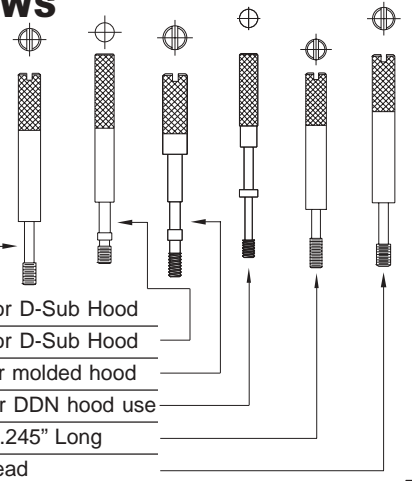

H-TS 4/40 Thread, for D-Sub Hood
H-TS-1 4/40 Thread, for D-Sub Hood
H-TS-2 4/40 Thread for molded hood
H-TS-3 4/40 Thread for DDN hood use
H-TS-4 4/40 Thread, 2.245" Long
H-TS-M3 M3 Metric Thread

PLASTIC WITH THUMB SCREWS

- Gray Plastic
- Includes Necessary Hardware for Assembly
- Metal Clamp Strain Relief
- Thumb Screw w/ Knurl

DP-SPT-09C
DP-SPT-25C

