




## MATV DROP TAPS

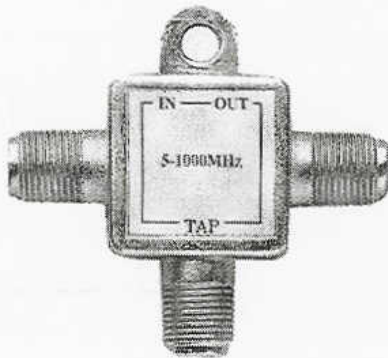

VTP-1106	6 DB
VTP-1109	9 DB
VTP-1112	12 DB
VTP-1116	16 DB
VTP-1120	20 DB
VTP-1124	24 DG
VTP-1127	27 DB
VTP-1130	30 DB

### FEATURES:

- PROVIDES HIGH ISOLATION OF REFLECTED SIGNALS TO REDUCE
- MAINTAINS CONSTANT 75 Ohm IMPEDANCE ON TRUNK WITH-TAP VARIATIONS(CATV SPECIFICATIONS COMPATIBILITY ASSURED)
- INDOOR/OUTDOOR HIGH QUALITY ZINC DIECAST HOUSING
- RF SHIELDING EXCEEDS FCC SPECIFICATIONS
- FULL 5 - 1000 MHz FREQUENCY RANGE
- TWO-WAY SYSTEM COMPATIBLE

VALUES		6	9	12	16	20	24	27	30
INSERTION LOSS (IN-OUT) MAX.(dB)	5MHz	3.0	1.7	2.5	0.8	0.7	0.8	0.9	0.8
	50MHz	2.6	1.4	0.5	0.6	0.6	0.6	0.7	0.6
	300MHz	2.5	1.3	0.5	0.6	0.6	0.6	0.7	0.5
	500MHz	2.5	1.3	0.7	2.5	0.5	0.6	0.6	0.9
	750MHz	3.0	1.8	1.5	1.1	1.1	1.0	1.3	0.9
	1000MHz	3.2	2.0	1.8	1.5	1.5	1.5	1.6	1.1
INSOLATION (TAP-OUT) MIN.(dB)	5MHz	23	30	36	32	36	55	55	60
	50MHz	31	30	36	32	36	55	55	60
	300MHz	25	33	33	32	33	45	52	50
	500MHz	27	33	30	29	31	43	43	43
	750MHz	28	30	25	27	28	39	40	40
	1000MHz	27	28	23	28	27	38	38	38
TAP LOSS (TOLERANCE IN-TAP) MAX.(+/-dB)	5MHz	0.5	0.5	0.5	0.5	0.5	0.5	0.5	0.5
	50MHz	0.5	0.5	0.5	0.5	0.5	0.5	0.5	0.5
	300MHz	0.5	0.5	0.5	0.5	0.5	0.5	0.5	0.5
	500MHz	0.5	0.5	0.5	1.0	1.0	1.0	1.5	1.5
	750MHz	0.5	1.0	0.5	1.5	2.0	1.5	2.5	1.5
	1000MHz	0.5	1.0	0.5	1.5	2.0	2.5	2.5	2.5