




Home > M0124-SS

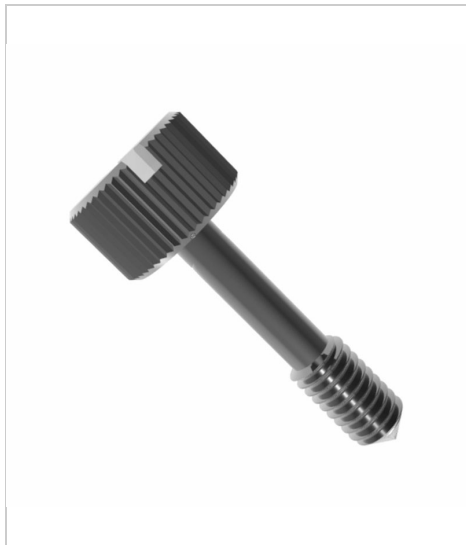

## Metric Captive Panel Screws - Style 1

**Model: M0124-SS**

### Select Finish

-0 No Plate

**Request Quote**

[Request Custom Part](#)

RFQ

Choose a CAD format

Download CAD

View 3D Model

View 2D Drawing

### Product Details

These screws are made from Stainless Steel. Length is 30.5 mm which is measured from under the head. Thread size is M4x0.7 and Head Diameter is 11 mm

### PDF Catalog

[RAF\\_catalog\\_0267.pdf](#)

Thread	M4x0.7
Material	Stainless Steel
RoHS	Yes
Head Diameter (HD)	11 mm
Head Length (HL)	6.5 mm

Length Under Head (L)	30.5 mm
Thread Length (TL)	9.5 mm
Shank Diameter (SD)	3 mm
Shank Length (SL)	21 mm
Width Of Slot(W)	1.5 mm
Depth Of Slot (D)	1.5 mm
Knurl TPI	2
Finish	-0 No Plate



RAF ELECTRONIC  
HARDWARE

## TECHNICAL INFORMATION

Electronic Hardware Components  
Engineering Data

## COMPANY

RAF Quality Management  
Industry Links