




RAF ELECTRONIC
HARDWARE
a Division of MW Industries, Inc.



[ABOUT US](#) [WHAT'S NEW](#) [CONTACT US](#) [SERVICES](#) [QUALITY](#) [SITE MAP](#)

[HOME](#)
[PRODUCTS](#)
[ONLINE CATALOG](#)
[REQUEST QUOTE](#)
[ORDER ONLINE](#)
[CHECK STOCK](#)
[REQUEST PRINT CATALOG](#)
[REQUEST SAMPLES](#)
[ENGINEERING DATA](#)
[DISTRIBUTORS](#)
[CAPABILITIES BROCHURE](#)

3/8 Hex Male-Female Standoffs

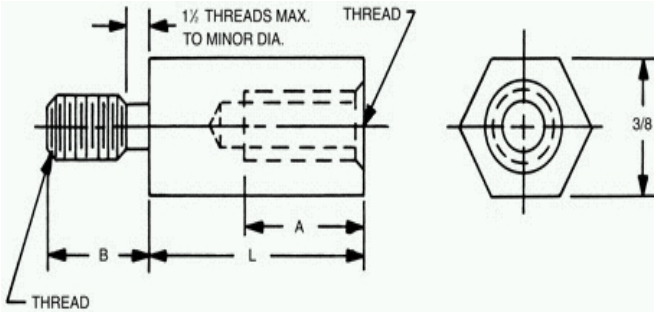

[Home](#) [Previous](#) [Next](#) [Related Me](#)

Ordering Code			
xxxx	xxx	x	x
Length	Thread	Material	Finis

PART: ????-??-??

Red ?'s show missing selections. [H](#)

**CALL NOW:
203 888-2133**



NEFDA
New England Fastener
Distributor Association



Select	Part No.	Length	Select	Part No.	Length	Select	Part No.	Length	Select	Code	Thread	Select	Code	Material	RoHS																					
<input type="radio"/>	4620A	7/32	<input type="radio"/>	4631	15/16	<input type="radio"/>	4644	1-3/4	<input type="radio"/>	440	4-40	<input type="radio"/>	AL	Aluminum	YES																					
<input type="radio"/>	4620	1/4	<input type="radio"/>	4631T	31/32	<input type="radio"/>	4645	1-13/16	<input type="radio"/>	632	6-32	<input type="radio"/>	B	Brass	YES																					
<input type="radio"/>	4620T	9/32	<input type="radio"/>	4632	1"	<input type="radio"/>	4646	1-7/8	<input type="radio"/>	832	8-32	<input type="radio"/>	SS	Stainless Steel	YES																					
<input type="radio"/>	4621	5/16	<input type="radio"/>	4633	1-1/16	<input type="radio"/>	4647	1-15/16	<input type="radio"/>	1032	10-32	<input type="radio"/>	S	Steel	YES																					
<input type="radio"/>	4621T	11/32	<input type="radio"/>	4634	1-1/8	<input type="radio"/>	4648	2"	<input type="radio"/>	1224	12-24	<input type="radio"/>	N	Nylon	YES																					
<input type="radio"/>	4622	3/8	<input type="radio"/>	4635	1-3/16	<input type="radio"/>	4649	2-1/8	<table border="1"> <thead> <tr> <th colspan="3">Thread Length Code</th> </tr> <tr> <th>Thread</th> <th>A</th> <th>B</th> </tr> </thead> <tbody> <tr><td>4-40</td><td>1/4</td><td>3/16</td></tr> <tr><td>6-32</td><td>3/8</td><td>1/4</td></tr> <tr><td>8-32</td><td>7/16</td><td>3/8</td></tr> <tr><td>10-32</td><td>1/2</td><td>3/8</td></tr> <tr><td>12-24</td><td>1/2</td><td>3/8</td></tr> </tbody> </table>				Thread Length Code			Thread	A	B	4-40	1/4	3/16	6-32	3/8	1/4	8-32	7/16	3/8	10-32	1/2	3/8	12-24	1/2	3/8	Material Specifications SELECT FINISH: <input type="text" value="select a material first"/>		
Thread Length Code																																				
Thread	A	B																																		
4-40	1/4	3/16																																		
6-32	3/8	1/4																																		
8-32	7/16	3/8																																		
10-32	1/2	3/8																																		
12-24	1/2	3/8																																		
<input type="radio"/>	4622T	13/32	<input type="radio"/>	4636	1-1/4	<input type="radio"/>	4650	2-1/4	<p>In short lengths, 'A' will be tapped to maximum depth</p>			<p>* Finishes ending with an asterisk are not RoHS Compliant Ordering non-standard items</p>																								
<input type="radio"/>	4623	7/16	<input type="radio"/>	4637	1-5/16	<input type="radio"/>	4651	2-3/8																												
<input type="radio"/>	4623T	15/32	<input type="radio"/>	4638	1-3/8	<input type="radio"/>	4652	2-1/2																												
<input type="radio"/>	4624	1/2	<input type="radio"/>	4639	1-7/16	<input type="radio"/>	4653	2-5/8																												
<input type="radio"/>	4624T	17/32	<input type="radio"/>	4640	1-1/2	<input type="radio"/>	4654	2-3/4																												
<input type="radio"/>	4625	9/16	<input type="radio"/>	4641	1-9/16	<input type="radio"/>	4655	2-7/8																												
<input type="radio"/>	4625T	19/32	<input type="radio"/>	4642	1-5/8	<input type="radio"/>	4656	3"																												
<input type="radio"/>	4626	5/8	<input type="radio"/>	4643	1-11/16	<input type="radio"/>	4657	3-1/4																												
<input type="radio"/>	4626T	21/32							<input type="radio"/>	4658	3-1/2																									
<input type="radio"/>	4627	11/16							<input type="radio"/>	4659	3-3/4																									
<input type="radio"/>	4627T	23/32							<input type="radio"/>	4660	4"																									
<input type="radio"/>	4628	3/4							<input type="radio"/>	4661	4-1/4																									
<input type="radio"/>	4628T	25/32							<input type="radio"/>	4662	4-1/2																									
<input type="radio"/>	4629	13/16							<input type="radio"/>	4663	4-3/4																									
<input type="radio"/>	4629T	27/32							<input type="radio"/>	4664	5"																									
<input type="radio"/>	4630	7/8							<input type="radio"/>	4665	5-1/4																									
<input type="radio"/>	4630T	29/32							<input type="radio"/>	4666	5-1/2																									
<input type="radio"/>									<input type="radio"/>	4667	5-3/4																									
<input type="radio"/>									<input type="radio"/>	4668	6"																									

[HOME](#) | [PRODUCTS](#) | [ONLINE CATALOG](#) | [REQUEST QUOTE](#) | [ORDER ONLINE](#) | [CHECK STOCK](#) | [CONTACT US](#) | [SITE MAP](#)

© RAF Electronic Hardware, a Division of MW Industries | 95 Silvermine Rd., Seymour CT 06483 | Tel 203-888-2133 | Fax 203-888-9860