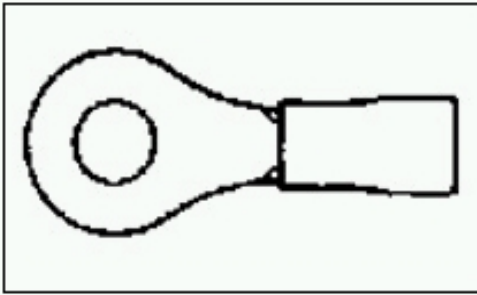


138601-000 Product Details

 [Live Product Chat](#)

138601-000

TE Part Number: 138601-000

 [Active](#)
 [Add to Part List](#)

Ring and Spade Tongue Terminals

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Terminal Shape = Ring Tongue
- Receptacle Style = Straight
- Body Style = DuraSeal
- Barrel Type = Closed Barrel
- Wire/Cable Type = Regular Wire

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)



Documentation & Additional Information

Product Drawings:

- [Duraseal Ring Terminal](#) (PDF, English)

Catalog Pages/Data Sheets:

- [Wire and Cable, Harnessing and Protection Products](#) (PDF, English)

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Terminal Shape](#) = Ring Tongue
- [Receptacle Style](#) = Straight
- Body Style = DuraSeal
- [Barrel Type](#) = Closed Barrel
- [Wire/Cable Type](#) = Regular Wire
- [Insulation](#) = Yes
- [Insulation Support](#) = Insulation Support
- [Insulation Diameter \(mm \[in\]\)](#) = 4.3 [.169] Max.
- Stud Size = 8 [M4]
- [Stud Diameter \(mm \[in\]\)](#) = 4.30 [0.169]
- Shape = RING-088
- [Heavy Duty](#) = No
- [Material](#) = Copper
- [Finish](#) = Tin
- Proprietary Name = DuraSeal
- Color = Red
- Insulation Material = Heat-Shrinkable Nylon
- Comment = Crimp Termination

Body Related Features:

- [Wire Range \(mm \[AWG\]\)](#) = 0.30-0.90² [22-18]
- Wire Range (CMA) = 509 - 1,900

Industry Standards:

- Government/Industry Qualification = No
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- Temperature Range (°C) = 125

Packaging Related Features:

- Packaging Method = Box

Other:

- Brand = Raychem

 [Provide Website Feedback](#) | [Need Help?](#)